

Pan Head Pozidriv[®] Machine Screws - Packs of 100



DESCRIPTION

Pan Head Pozidriv Machine Screws with bright zinc-plated, passivated finish.

DISTINCTIVE FEATURES

- Pozidriv[®]
- Zinc & Clear Cr3 Finish
- Steel Grade 4.8
- Dome head style
- M2, M2.5, M3, M4, M5 and M6 options
- Supplied in packs of 100

APPLICATIONS

Suitable for general use. Typical applications include use in electrical, electronic and domestic equipment, general repair and maintenance, circuit board mounting, prototyping, etc.

**Pan
Head**

**Grade
4.8
Steel**

**Zinc
& Clear
Cr3**





GENERAL SPECIFICATION

Series	Machine Screws
Type	PoziDrive®



MATERIALS

Material	Grade 4.8 Steel
Finish	Zinc & Black Cr3



CERTIFICATION AND STANDARDS

Material Specification	DIN 7985Z ~ISO 7045
------------------------	---------------------





OPTIONS (MOQ may apply)

Lengths	Various
Thread Sizes	M1.6 to M12
Thread Type	Coarse and Fine
Material	Steel
Head Styles	e.g. Button, Countersunk, Cheese



DIMENSIONS/DRAWINGS

Units	mm - unless stated otherwise
-------	------------------------------

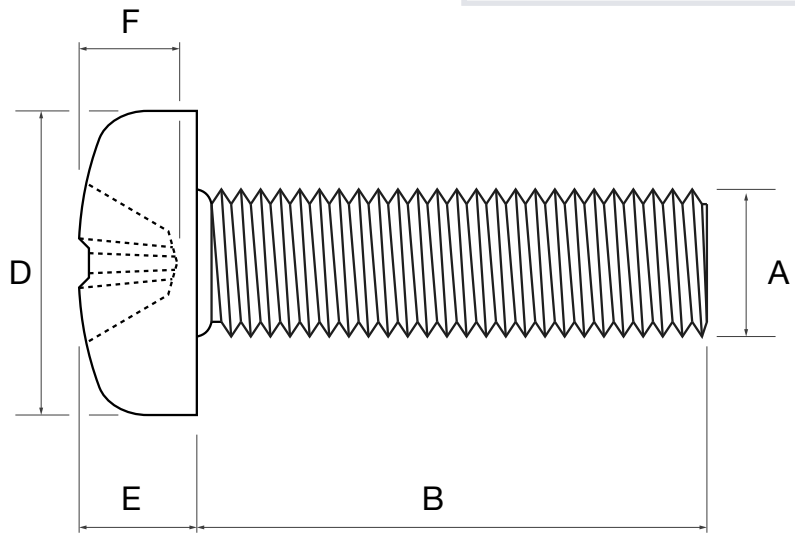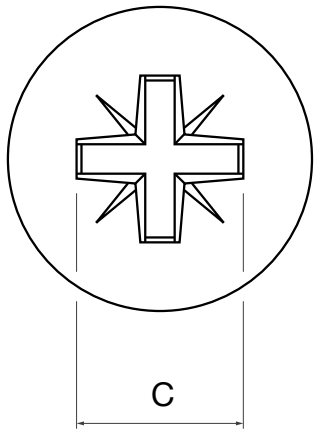



PART NUMBER TABLE

Part number	A Thread size	B Length	C Screwdriver size	D Head width	F Screwdriver depth	E Head depth	UNSPSC	EAN	Country of Origin
33-7197	M2	6	PZ1 - 2.4	4.0	1.1-1.35	1.72	73181900	5053556011100	China
33-7032		10					73181900	5053556009459	China
33-7198		12					73181900	5053556011117	China
33-7028	M2.5	6	PZ1 - 2.6	5.0	1.27-1.52	2.12	73181900	5053556009411	China
33-7029		10					73181900	5053556009428	China
33-7030		12					73181900	5053556009435	China
33-7031		20					73181900	5053556009442	China
33-7033	M3	6	PZ1 - 3.0	6.0	1.68-1.93	2.52	73181900	5053556009466	China
33-7034		8					73181900	5053556009473	China
33-7035		10					73181900	5053556009480	China
33-7036		12					73181900	5053556009497	China
33-7037		16					73181900	5053556009503	China
33-7038		20					73181900	5053556009510	China
33-7039		25					73181900	5053556009527	China
33-7040		30					73181900	5053556009534	China
33-7041	M4	6	PZ2 - 4.3	8.0	1.9-2.36	3.25	73181900	5053556009541	China
33-7199		8					73181900	5053556011124	China
33-7042		10					73181900	5053556009558	China
33-7043		12					73181900	5053556009565	China
33-7044		16					73181900	5053556009572	China
33-7045		20					73181900	5053556009589	China
33-7046		25					73181900	5053556009596	China
33-7047		30					73181900	5053556009602	China
33-7200		40					73181900	5053556011131	China
33-7201		50					73181900	5053556011148	China
33-7048	M5	6	PZ2 - 5.0	10.0	2.64-3.1	3.95	73181900	5053556009619	China
33-7202		8					73181900	5053556011155	China
33-7049		10					73181900	5053556009626	China
33-7050		12					73181900	5053556009633	China
33-7051		16					73181900	5053556009640	China
33-7052		20					73181900	5053556009657	China
33-7053		25					73181900	5053556009664	China
33-7203		40					73181900	5053556011162	China
33-7204	50	73181900	5053556011179	China					

Part number	A Thread size	B Length	C Screwdriver size	D Head width	F Screwdriver depth	E Head depth	UNSPSC	EAN	Country of Origin
33-7205	M6	10	1.6	12	1.4	3.6	73181900	5053556011186	China
33-7206		12					73181900	5053556011193	China
33-7207		16					73181900	5053556011209	China
33-7208		20					73181900	5053556011216	China
33-7209		25					73181900	5053556011223	China
33-7210		40					73181900	5053556011230	China
33-7211		50					73181900	5053556011247	China

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact, telephone our main office on **01206 838000** or email **Sales@Rapidonline.com**.



Important Notice: This data sheet and its contents (the "Information") belong to Rapid Electronics Limited or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but Rapid Electronics Limited assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where Rapid Electronics Limited were aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict Rapid Electronics Limited's liability for death or personal injury resulting from its negligence.