

Countersunk Head Pozidriv® Machine Screw - Packs of 100



DESCRIPTION

Countersunk Head Pozidriv® Stainless Steel Machine Screws with good corrosion resistance.

Designed for use where a flush surface finish is required. Ideal for use when a low profile screw is required or when you need the screw to sit flush or below the surface.

Suitable for general and outdoor use. Their anti-corrosive properties make them ideal for use outdoors or in damp conditions.

DISTINCTIVE FEATURES

- Pozidriv®
- Flat, Countersunk head style
- Self-coloured Finish
- Stainless Steel Grade A2 (304)
- Corrosion Resistant
- Non-magnetic
- M3 option
- Supplied in packs of 100

APPLICATIONS

Designed for use where a flush surface finish is required.

Typical applications include use in electrical, electronic and domestic equipment, general repair and maintenance, circuit board mounting, prototyping, etc.

Suitable for outdoor use, in damp conditions and where improved corrosion resistance is required.

Suitable for use in food, medical and non-severe chemical environments, and in both low and high temperature applications.

Note: Not suitable for use with non-oxidising acids and agents or in chloride rich environments.

Countersunk Head

Stainless Steel

Self Colour





GENERAL SPECIFICATION

Series	Machine Screw
Type	PoziDriv®



MATERIALS

Material	A2 Stainless Steel
Finish	Self Colour



CERTIFICATION AND STANDARDS

Material Specification	DIN 965Z ~ISO 7046
------------------------	--------------------





OPTIONS (MOQ may apply)

Lengths	Various
Thread Sizes	M1.6 to M12
Thread Type	Coarse and Fine
Material	Steel
Head Styles	e.g. Button, Pan, Cheese



DIMENSIONS/DRAWINGS

Units	mm - unless stated otherwise
-------	------------------------------

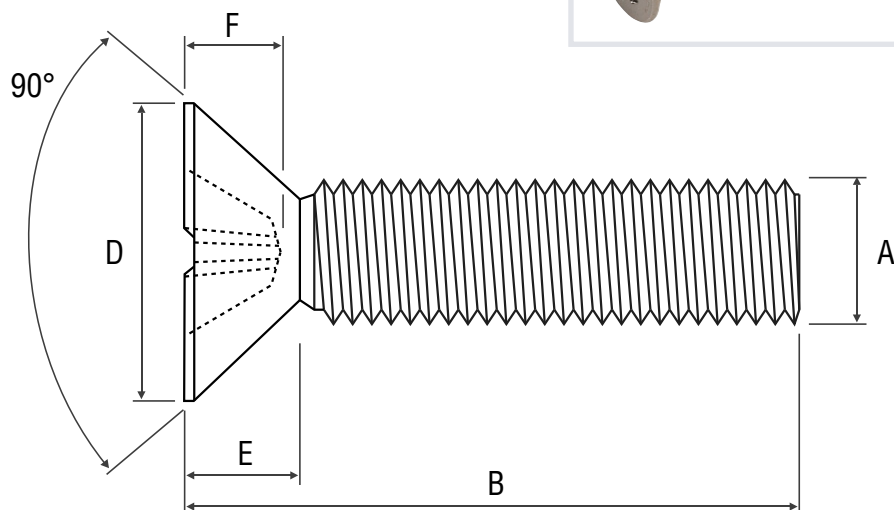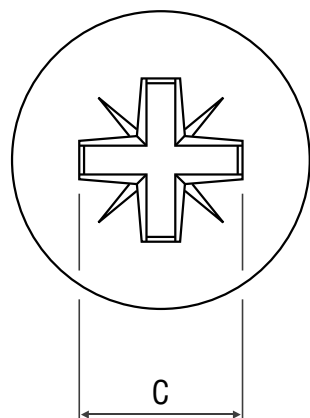

PART NUMBER TABLE

Part number	A Thread size	B Length	C Screwdriver size	D Head width	E Head depth	F Screwdriver depth	UNSPSC	EAN	Country of Origin
33-7094	M3	6.0	PZ1- 2.8	5.6	1.65	1.48-1.73	73181900	5053556010073	China
33-7095		12.0					73181900	5053556010080	China
33-7096		20.0					73181900	5053556010097	China

For further information on pricing, delivery, and long-term stock agreements please get in touch with your local business development contact, telephone our main office on **01206 838000** or email **Sales@Rapidonline.com**.

R-TECH[®]
Tried & trusted technology

Important Notice: This data sheet and its contents (the "Information") belong to Rapid Electronics Limited or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but Rapid Electronics Limited assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where Rapid Electronics Limited were aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict Rapid Electronics Limited's liability for death or personal injury resulting from its negligence.