


Order code	Manufacturer code	Description
35-0047	n/a	MINIATURE PIEZO TRANSDUCER 29.5MM RC

	Page 1 of 2
The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 20/02/2007

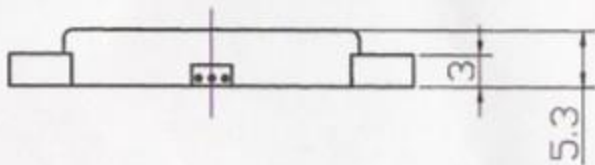

## SPECIFICATION

1. Rated Voltage .....12Vp-p Square Wave
2. Max. Allwable Voltage .....30Vp-p Square Wave
3. Max. Rated Current .....8mA at 3.6KHz/12Vp-p Square Wave
4. Min. Sound Pressure Level.....80dB at 3.6KHz/12Vp-p Square Wave/30cm
5. Capacitance at 120Hz .....18000pF±30%
6. Resonant Frequency .....3.6±0.5KHz
7. Case Material.....ABS
8. Operating Temperature .....-20~+60°C
9. Store Temperature .....-30~+70°C
10. Weight .....3g

