
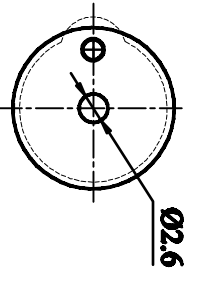
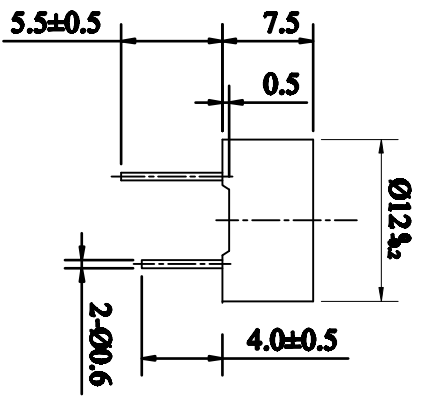


1 2 3 4 5 6 7 8

# SPECIFICATION

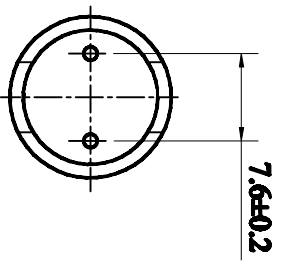

- 1. Rated Voltage ..... 12VDC
- 2. Operating Voltage ..... 8~15VDC
- 3. Max. Rated Current ..... 30mA/5VDC
- 4. Min. Sound Pressure Level ..... 85dB/10cm
- 5. Resonant Frequency ..... 3100±300Hz
- 6. Response Time ..... 50ms
- 6. Case Material ..... PBT
- 7. Operating Temperature ..... -20~+85
- 8. Store Temperature ..... -20~+88
- 9. Weight ..... 2g

Magnetic Buzzer							
EFK1212B							
Compliance with RoHS							
DATE	APPROVED	DATE					
DATE	APPROVALS	DATE					
DATE	APPROVALS	DATE					
DATE	APPROVALS	DATE					

Magnetic Buzzer							
EFK1212B							
Compliance with RoHS							
DATE	APPROVED	DATE					
DATE	APPROVALS	DATE					
DATE	APPROVALS	DATE					
DATE	APPROVALS	DATE					

1 2 3 4 5 6 7 8