

<b>Order code</b>	<b>Manufacturer code</b>	<b>Description</b>
35-6307	n/a	COMPACT LAMP WITH 135MM UV TUBE RC



	Page 1 of 2
The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 20/02/2007

# T5 Blacklight Blue Fluorescent Lamps



## Key Specifications

- Watt: 4W/6W/8W/13W
- Bulb Type: T5
- Base: G5
- Wave Length: 365nm
- The lamps produce ultra-violet rays that make white fabrics fluorescence.
- These lamps are suitable for medical and pharmaceutical industries, photochemical reaction, jewelry and historical relics verification, special stage effect, note detector etc.
- CE approved.

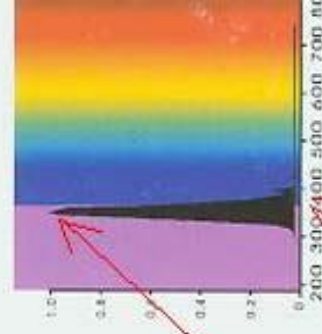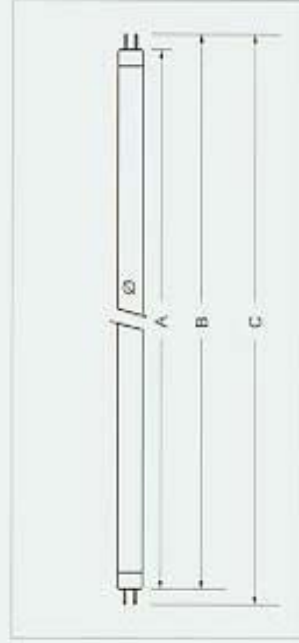

**PEAK OF WAVE LENGTH:365nm**  
**RANGE OF WAVE LENGTH:300nm - 400nm**

Type	A Max(mm)	B Max(mm)	B Min(mm)	C Max(mm)	Ø Max(mm)	Measurement of Carton(cm)	Pcs	G.W. (kg)	N.W. (kg)
4W	135.9	143.0	140.6	150.1	1.6	48X18X40.5	500	11.4	8
6W	212.1	219.2	216.8	226.3	1.6	48X25X40.5	500	16.4	11.7
8W	288.3	295.4	293.0	302.5	1.6	48X33X40.5	500	21.6	15.4
13W	516.9	524.0	521.6	531.1	1.6	55.5X21.5X39	200	14.5	10.5

Type	Watt (W)	Current (A)	Lamp Voltage Min(V) Rating Max(V)	Wave Length (nm)	Life Span (h)	Socket
4W/BLB	4	0.170	24 20 34	365	5000	G5
6W/BLB	6	0.160	36 42 48	365	5000	G5
8W/BLB	8	0.145	48 56 64	365	5000	G5
13W/BLB	13	0.165	85 95 105	365	5000	G5