



AmpFlow A28-150 24V

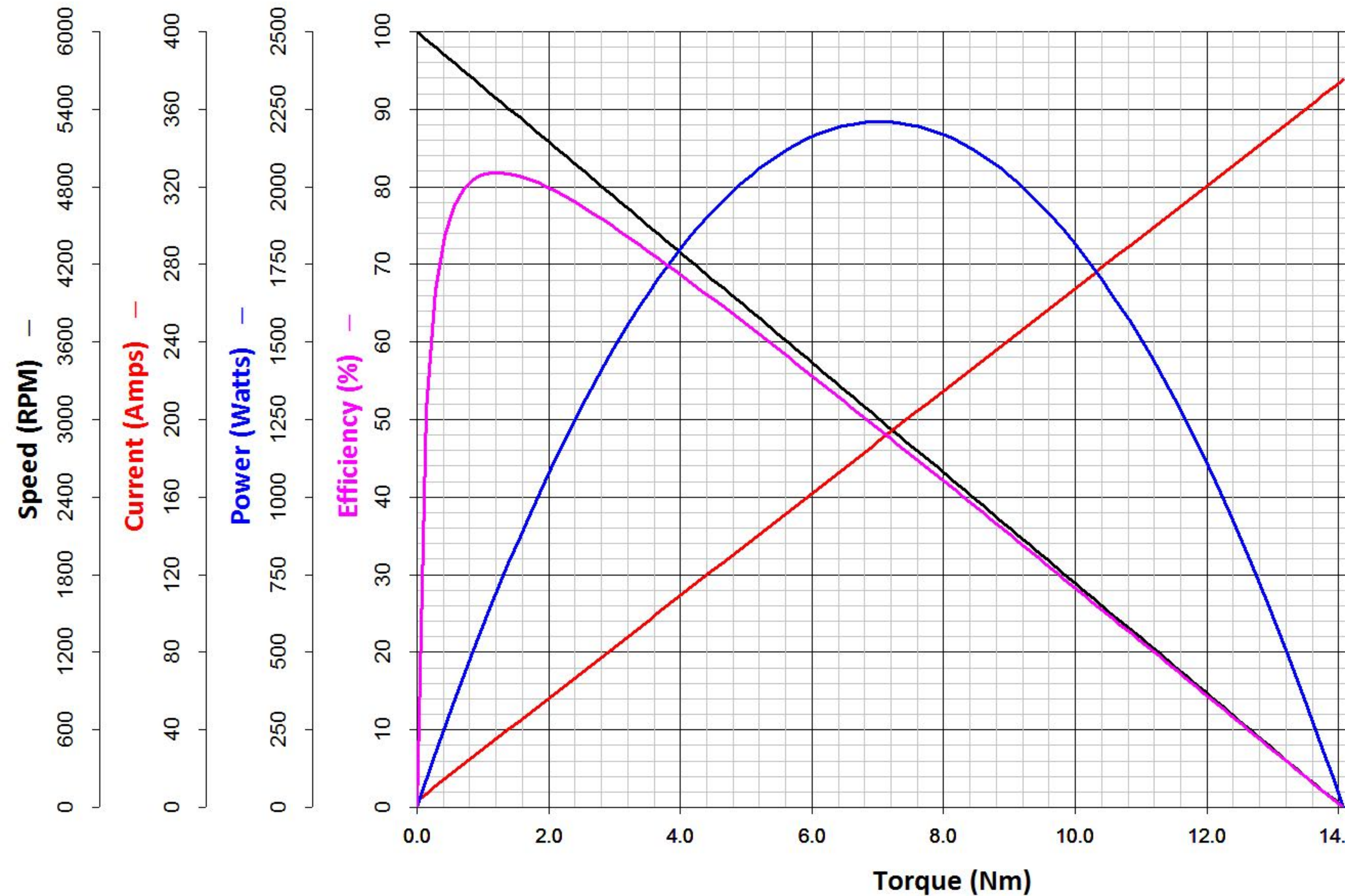

REVISIONS				
ECO	REV	DESCRIPTION	DATE	APPROVED

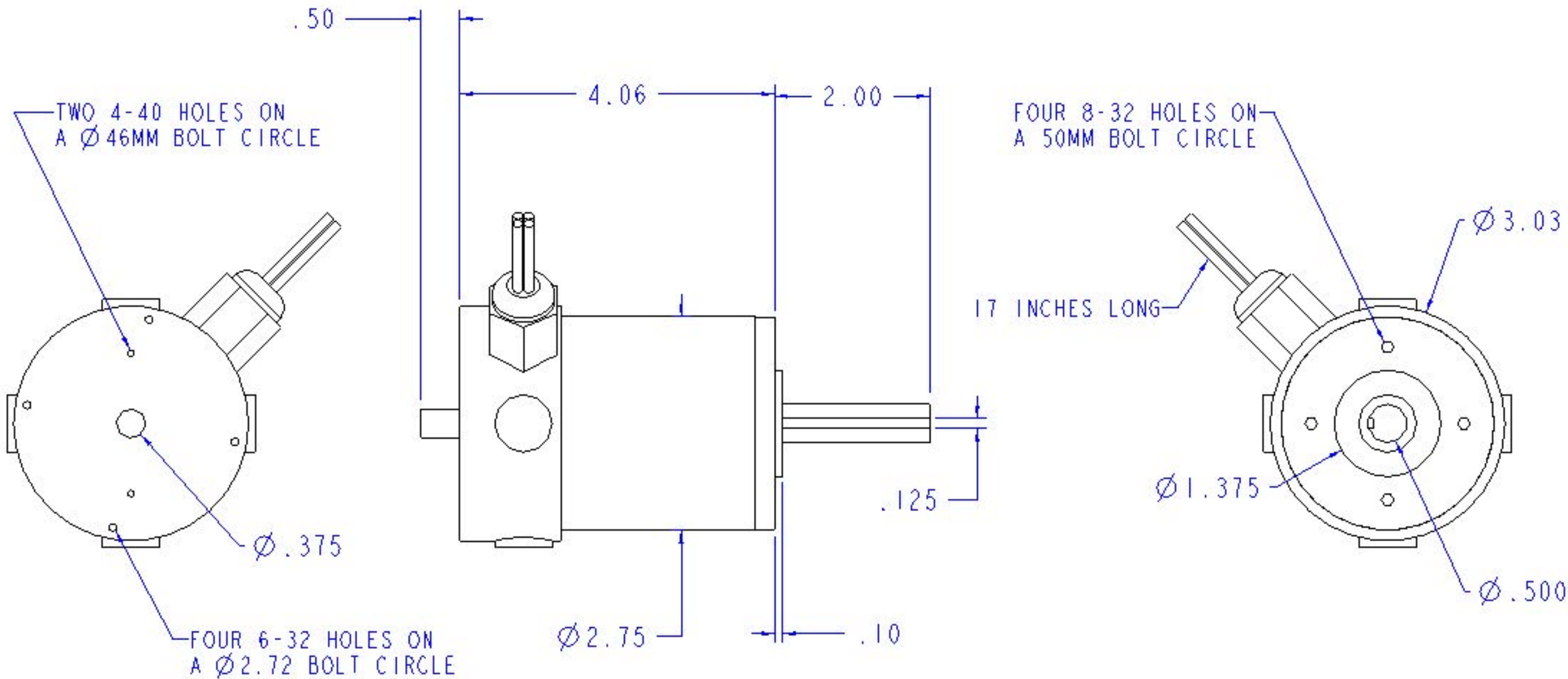

NOMINAL VOLTAGE: 24
 NO-LOAD RPM: 6000
 MOTOR WEIGHT: 3.8 LBS
 MAGNETS: NEODYMIUM

ITEM	PART NUMBER	DESCRIPTION	QTY
BILL OF MATERIAL			

POLYMERES UNLESS OTHERWISE NOTED			SIGNATURE	DATE
2 PL	3 PL	ANGLE	DETAIL	
±	±	±	APP'D	
REMOVE RIBS & SHARP EDGES			APP'D	
SURFACE FINISH			THIRD ANGLE PROJECTION	
DO NOT SCALE THIS DRAWING			DIMENSIONS ARE IN INCHES	
MATERIAL			FINISH	

Powerhouse Engineering		
A28-150		
SIZE C	DRAWING NUMBER	REV
SCALE	1.000	SHEET 1 OF 1