
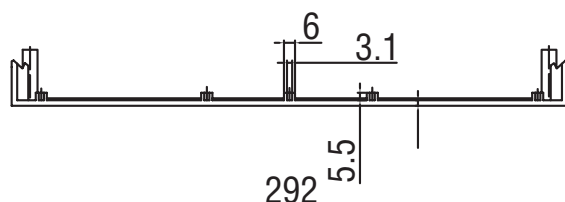


Features:

Attractively styled ABS instrument case, 300 x 200 x 75mm with aluminium end panel (**30-4159**) and with aluminium end panel and venting holes (**30-4160**). These cases have been manufactured to professional standards with moulded PCB stand offs, vertical card guides and brass inserts for repetitive assembly and disassembly.

- Four M3 screws and rubber feet are provided
- **UL94-HB**

Order code	Length	Width	Height	I.H.	Venting holes
30-4159	300	200	75	68	NO
30-4160	300	200	75	68	YES

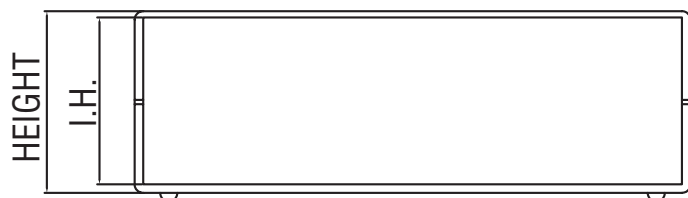

According to ISO 2768-m	
Measuring DIM=L	Tolerances
0.5<L<=3.0mm	±0.1mm
3.0<L<=6.0 mm	±0.1mm
6.0<L<=30.0 mm	±0.2mm
30.0<L<=120.0 mm	±0.3mm
120.0<L<=400.0 mm	±0.5mm
400.0<L<=1000.0 mm	±0.8mm

