


Part Number: 1512145XX

Type	Size	Rating	Description
LED	6mm	28VAC/DC	T-1 $\frac{3}{4}$ Midget Groove Lamp

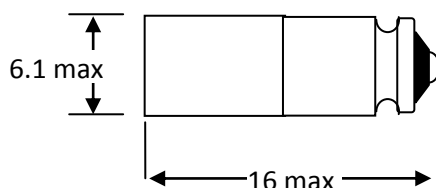

Part #	Colour	Dominant λ (nm)	Current (mA)	Intensity (mcd)
1512145UR3	Red	630	15	900 (dc)
1512145UG3	Green	525	14	1800 (dc)
1512145UY3	Yellow	589	15	600 (dc)
1512145B3	Blue	470	14	700 (dc)
1512145W3A	Cool White clear	x=0.31, y=0.32	14	4900 (dc)
1512145W3DA	Cool White diffuse	x=0.31, y=0.32	14	2300 (dc)

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Storage temperature -25 °C to +80°C
- 3 Application temperature -20 °C to +60°C
- 4 Voltage tolerance $\pm 10\%$
- 5 Due to component tolerances, colour temperature variations may be observed
- 6 The plastic(polycarbonate) has limited chemical resistance
- 7 RoHS & REACH SVHC compliant