


Part Number:

TB00XXXX

Type	Size	Rating	Description
LED	8mm	Various	Prominent Bezel LED with flying leads

All dimensions in mm.

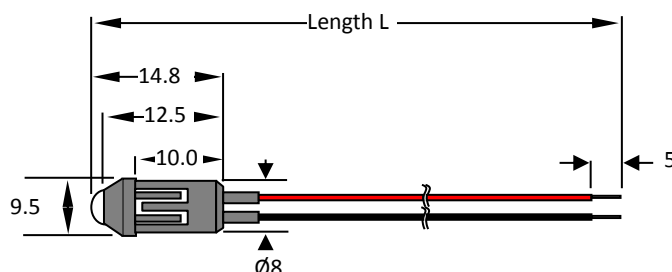

Part no.	Length L	Colour	Volts	Current mA	Intensity mcd	LED
TB000002	200	red	$V_f=2.0$	20	50	standard
TB000005	500	red	$V_f=2.0$	20	50	standard
TB000009	900	red	$V_f=2.0$	20	50	standard
TB000012	200	green	$V_f=2.0$	20	40	standard
TB000015	500	green	$V_f=2.0$	20	40	standard
TB000019	900	green	$V_f=2.0$	20	40	standard
TB000022	200	yellow	$V_f=2.1$	20	40	standard
TB000025	500	yellow	$V_f=2.1$	20	40	standard
TB000029	900	yellow	$V_f=2.1$	20	40	standard
TB000102	200	red	6DC	16	40	standard
TB000105	500	red	6DC	16	40	standard
TB000112	200	green	6DC	16	32	standard
TB000115	500	green	6DC	16	32	standard
TB000122	200	yellow	6DC	16	32	standard
TB000125	500	yellow	6DC	16	32	standard
TB000202	200	red	12DC	16	40	standard
TB000205	500	red	12DC	16	40	standard
TB000209	900	red	12DC	16	40	standard
TB000212	200	green	12DC	16	32	standard
TB000215	500	green	12DC	16	32	standard
TB000219	900	green	12DC	16	32	standard
TB000222	200	yellow	12DC	16	32	standard
TB000225	500	yellow	12DC	16	32	standard
TB000229	900	yellow	12DC	16	32	standard
TB000302	200	red	24DC	10	25	standard
TB000305	500	red	24DC	10	25	standard
TB000309	900	red	24DC	10	25	standard
TB000312	200	green	24DC	10	20	standard
TB000315	500	green	24DC	10	20	standard
TB000319	900	green	24DC	10	20	standard
TB000322	200	yellow	24DC	10	20	standard
TB000325	500	yellow	24DC	10	20	standard
TB000329	900	yellow	24DC	10	20	standard
TB001002	200	red	3.5-13DC	22@9V	40@9V	flashing
TB001005	500	red	3.5-13DC	22@9V	40@9V	flashing

PRODUCT DATA SHEET

Part Number:

TB00XXXX

Type	Size	Rating	Description
LED	8mm	Various	Prominent Bezel LED with flying leads

TB001009	900	red	3.5-13DC	22@9V	40@9V	flashing
TB001012	200	green	3.5-13DC	22@9V	40@9V	flashing
TB001015	500	green	3.5-13DC	22@9V	40@9V	flashing
TB001019	900	green	3.5-13DC	22@9V	40@9V	flashing
TB001022	200	yellow	3.5-13DC	22@9V	40@9V	flashing
TB001025	500	yellow	3.5-13DC	22@9V	40@9V	flashing
TB001029	900	yellow	3.5-13DC	22@9V	40@9V	flashing
TB001302	200	red	24DC	22	40	flashing
TB001305	500	red	24DC	22	40	flashing
TB001309	900	red	24DC	22	40	flashing
TB001312	200	green	24DC	22	40	flashing
TB001315	500	green	24DC	22	40	flashing
TB001319	900	green	24DC	22	40	flashing
TB001322	200	yellow	24DC	22	40	flashing
TB001325	500	yellow	24DC	22	40	flashing
TB001329	900	yellow	24DC	22	40	flashing