


Part Number: TB01XXXX

Type	Size	Rating	Description
LED	8mm	Various	Recessed Bezel LED with flying leads

All dimensions in mm.

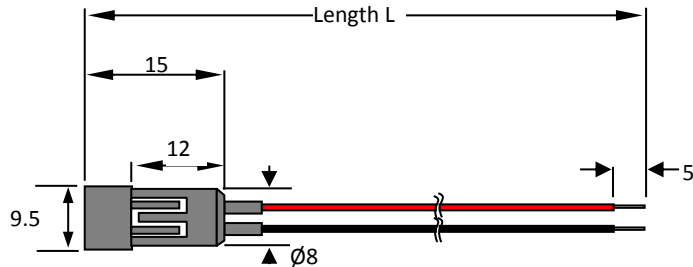

Part no.	Length L	Colour	Volts	Current mA	Intensity mcd	LED
TB010005	500	red	$V_f=2.0$	20	50	standard
TB010009	900	red	$V_f=2.0$	20	50	standard
TB010015	500	green	$V_f=2.0$	20	40	standard
TB010019	900	green	$V_f=2.0$	20	40	standard
TB010025	500	yellow	$V_f=2.1$	20	40	standard
TB010029	900	yellow	$V_f=2.1$	20	40	standard
TB010105	500	red	6DC	16	40	standard
TB010115	500	green	6DC	16	32	standard
TB010125	500	yellow	6DC	16	32	standard
TB010205	500	red	12DC	16	40	standard
TB010209	900	red	12DC	16	40	standard
TB010215	500	green	12DC	16	32	standard
TB010219	900	green	12DC	16	32	standard
TB010225	500	yellow	12DC	16	32	standard
TB010229	900	yellow	12DC	16	32	standard
TB010305	500	red	24DC	10	25	standard
TB010309	900	red	24DC	10	25	standard
TB010315	500	green	24DC	10	20	standard
TB010319	900	green	24DC	10	20	standard
TB010325	500	yellow	24DC	10	20	standard
TB010329	900	yellow	24DC	10	20	standard
TB011005	500	red	3.5-13DC	22@9V	40@9V	flashing
TB011009	900	red	3.5-13DC	22@9V	40@9V	flashing
TB011015	500	green	3.5-13DC	22@9V	40@9V	flashing
TB011019	900	green	3.5-13DC	22@9V	40@9V	flashing
TB011025	500	yellow	3.5-13DC	22@9V	40@9V	flashing
TB011029	900	yellow	3.5-13DC	22@9V	40@9V	flashing
TB011305	500	red	24DC	22	40	flashing
TB011309	900	red	24DC	22	40	flashing
TB011315	500	green	24DC	22	40	flashing
TB011319	900	green	24DC	22	40	flashing
TB011325	500	yellow	24DC	22	40	flashing
TB011329	900	yellow	24DC	22	40	flashing