


PRODUCT DATA SHEET

Part Number: TB10XXXX

Type	Size	Rating	Description
LED	12mm	Various	Prominent Bezel LED with flying leads

All dimensions in mm.

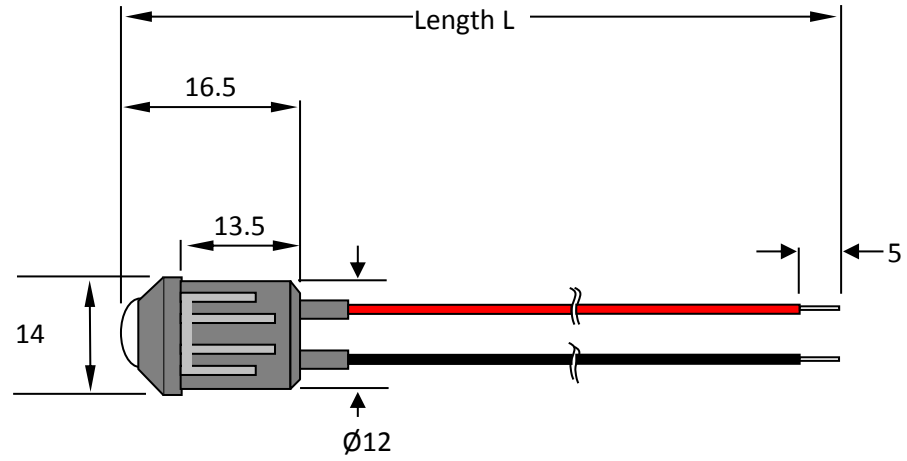

Part no.	Length L	Colour	Volts	Current mA	Intensity mcd	LED
TB100005	500	red	$V_f=2.0$	20	100	standard
TB100015	500	green	$V_f=2.0$	20	60	standard
TB100025	500	yellow	$V_f=2.1$	20	50	standard
TB100205	500	red	12Vdc	16	80	standard
TB100215	500	green	12Vdc	16	48	standard
TB100225	500	yellow	12Vdc	16	40	standard
TB100305	500	red	24Vdc	10	50	standard
TB100315	500	green	24Vdc	10	30	standard
TB100325	500	yellow	24Vdc	10	25	standard
TB101005	500	red	3.5-14Vdc	22@5V	60@9V	flashing
TB101015	500	green	3.5-14Vdc	20@5V	50@9V	flashing
TB101025	500	yellow	3.5-14Vdc	21@5V	40@9V	flashing
TB101305	500	red	24Vdc	40	60	flashing
TB101315	500	green	24Vdc	36	50	flashing
TB101325	500	yellow	24Vdc	38	40	flashing

Notes

- 1 Blink Frequency 3 – 1.5Hz, $V_f = 3.5V - 14V$
- 2 Viewing Angle 60°
- 3 LED Lens Diffuse