

Actuator

46-
2Y50.101C.000



[https://www.eao.com/component/46-
2Y50.101C.00...](https://www.eao.com/component/46-2Y50.101C.00...)

Your product:



46-2Y50.101C.000 Actuator

FRONT

Front dimension:	Ø 29 mm
Front form:	Round
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	Raised
Mounting cut-out:	Ø 22.3 mm
Mounting type:	Panel mounting

ELECTRICAL CHARACTERISTICS

Contact resistance:	<30mOhm
Insulation voltage:	>100MOhm
Electrical lifetime:	>50 000 h

MECHANICAL CHARACTERISTICS

Terminal:	USB 3.0 socket type C-A
Mechanical lifetime:	>15 000 insertion cycles
Tightening torque:	1 ... 2.5 Nm (8.8 ... 22.1 Lb-in)
Weight:	0.022 kg

AMBIENT CONDITION

IP front protection: IP20 / IP66 with cap closed (IEC-EN60529)

Operating temperature: - 25 °C ... + 55 °C

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

Climate resistance: +40°C-92%RH

CERTIFICATE

Conformities: CE

REACH: REACH compliant

RoHS: RoHS compliant

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508


OTHER

Short Description: Actuator, Ø 22.3 mm, Ø 29 mm, Round, Black, Plastic, USB 3.0 socket type C-A, IP20 / IP66 with cap closed (IEC-EN60529)

Housing colour: Black

Housing material: Plastic

Mounting cut-outs:

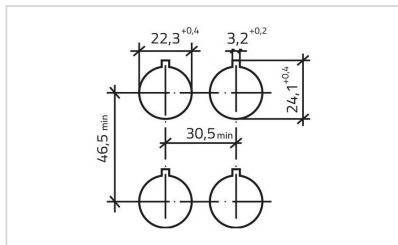

Dimension drawings:

