


U.I. Lapp GmbH	<b>PRODUCT INFORMATION</b>	
	<b>SKINTOP® DIX-M</b>	12.09.2012

Easy insertion of several cables into one gland  
Higher packing density allows smaller part construction




### Application range

For use in SKINTOP® cable glands.

A sealing ring with several holes is used in place of the inner sealing insert.

### Design

SKINTOP® DIX-M VITON® is resistant to oil, water, alkaline solutions, acids, solvents etc.

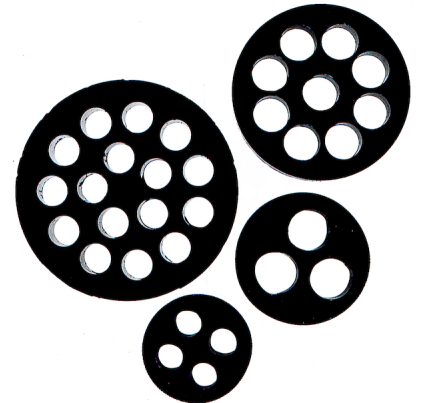

### Note

IP 68 can be achieved when all openings are closed and all bores are optimally occupied, i.e. when using cables with nominal diameter and/or SKINTOP® DIX-DV sealing plugs

### Remark

Viton® is a registered trademark of DuPont de Nemours

Photographs are not to scale and do not represent detailed images of the respective products.

### Technical Data

On request:	Special shapes
Colour delivered:	Black (RAL 9005)
Material:	NBR VITON®
Protection rating:	IP 54
Temperature range:	-40°C to +100°C

Product Management	Document: LAPP_PRO999EN.pdf	1 / 3
--------------------	-----------------------------	-------

## SKINTOP® DIX-M

12.09.2012

Part number	Article designation / size	Size M	Number of cables x cable Ø	Pieces / PU
SKINTOP® DIX-M				
53316220	16220	M 16	2 x 2	100
53316230	16230	M 16	2 x 3	100
53316240	16240	M 16	2 x 4	100
53316420	16420	M 16	2 x 4	100
53320250	20250	M 20	2 x 5	100
53320260	20260	M 20	2 x 6	100
53320340	20340	M 20	3 x 4	100
53320353	20353	M 20	3 x 5,3	100
53320440	20440	M 20	4 x 4	100
53320920	20920	M 20	9 x 2	100
53320430	20430	M 20	4 x 3	100
53325260	25260	M 25	2 x 6	50
53325350	25350	M 25	3 x 5	50
53325360	25360	M 25	3 x 6	50
53325370	25370	M 25	3 x 7	50
53325450	25450	M 25	4 x 5	50
53325540	25540	M 25	5 x 4	50
53325640	25640	M 25	6 x 4	50
53332270	32270	M 32	2 x 7	50
53332280	32280	M 32	2 x 8	50
53332290	32290	M 32	2 x 9	50
53332370	32370	M 32	3 x 7	50
53332380	32380	M 32	3 x 8	50
53332460	32460	M 32	4 x 6	50
53332470	32470	M 32	4 x 7	50
53332560	32560	M 32	5 x 6	50
53332650	32650	M 32	6 x 5	50
53332840	32840	M 32	8 x 4	50
53332850	32850	M 32	8 x 5	50
53332940	32940	M 32	9 x 4	50
53340290	40290	M 40	2 x 9	25
53340310	40310	M 40	3 x 10	25
53340480	40480	M 40	4 x 8	25

**SKINTOP® DIX-M**

12.09.2012

Part number	Article designation / size	Size M	Number of cables x cable Ø	Pieces / PU
53340490	40490	M 40	4 x 9	25
53340580	40580	M 40	5 x 8	25
53340590	40590	M 40	5 x 9	25
53340670	40670	M 40	6 x 7	25
53340860	40860	M 40	8 x 6	25
53340969	40969	M 40	9 x 6,9	25
53350118	50118	M 50	11 x 8	10
53350680	50680	M 50	6 x 8	10
53350780	50780	M 50	7 x 8	10
53350870	50870	M 50	8 x 7	10
53350147	50147	M 50	14 x 7	10
53350164	50164	M 50	16 x 4	10
53350166	50166	M 50	16 x 6	10
SKINTOP® DIX-M VITON®				
53420250	20250	M 20	2 x 5	100
53420260	20260	M 20	2 x 6	100
53440969	40969	M 40	9 x 6,9	25