


|                   |                            |  |
|-------------------|----------------------------|--|
| U.I. Lapp<br>GmbH | <b>PRODUCT INFORMATION</b> |  |
|                   | <b>SKINTOP® DIX-M</b>      | 12.09.2012   |

Easy insertion of several cables into one gland  
Higher packing density allows smaller part construction




### Application range

For use in SKINTOP® cable glands.

A sealing ring with several holes is used in place of the inner sealing insert.

### Design

SKINTOP® DIX-M VITON® is resistant to oil, water, alkaline solutions, acids, solvents etc.

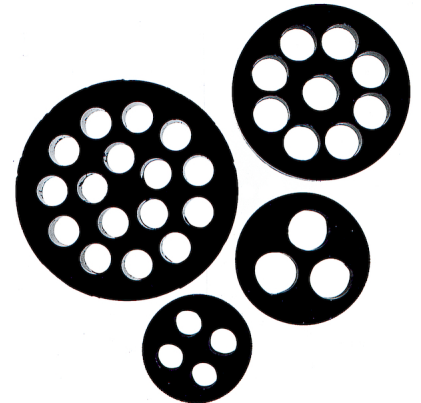

### Note

IP 68 can be achieved when all openings are closed and all bores are optimally occupied, i.e. when using cables with nominal diameter and/or SKINTOP® DIX-DV sealing plugs

### Remark

Viton® is a registered trademark of DuPont de Nemours

Photographs are not to scale and do not represent detailed images of the respective products.

### Technical Data

|                    |                  |
|--------------------|------------------|
| On request:        | Special shapes   |
| Colour delivered:  | Black (RAL 9005) |
| Material:          | NBR<br>VITON®    |
| Protection rating: | IP 54            |
| Temperature range: | -40°C to +100°C  |

|                    |                             |       |
|--------------------|-----------------------------|-------|
| Product Management | Document: LAPP_PRO999EN.pdf | 1 / 3 |
|--------------------|-----------------------------|-------|

## SKINTOP® DIX-M

12.09.2012

| Part number    | Article designation / size | Size M | Number of cables x cable Ø | Pieces / PU |
|----------------|----------------------------|--------|----------------------------|-------------|
| SKINTOP® DIX-M |                            |        |                            |             |
| 53316220       | 16220                      | M 16   | 2 x 2                      | 100         |
| 53316230       | 16230                      | M 16   | 2 x 3                      | 100         |
| 53316240       | 16240                      | M 16   | 2 x 4                      | 100         |
| 53316420       | 16420                      | M 16   | 2 x 4                      | 100         |
| 53320250       | 20250                      | M 20   | 2 x 5                      | 100         |
| 53320260       | 20260                      | M 20   | 2 x 6                      | 100         |
| 53320340       | 20340                      | M 20   | 3 x 4                      | 100         |
| 53320353       | 20353                      | M 20   | 3 x 5,3                    | 100         |
| 53320440       | 20440                      | M 20   | 4 x 4                      | 100         |
| 53320920       | 20920                      | M 20   | 9 x 2                      | 100         |
| 53320430       | 20430                      | M 20   | 4 x 3                      | 100         |
| 53325260       | 25260                      | M 25   | 2 x 6                      | 50          |
| 53325350       | 25350                      | M 25   | 3 x 5                      | 50          |
| 53325360       | 25360                      | M 25   | 3 x 6                      | 50          |
| 53325370       | 25370                      | M 25   | 3 x 7                      | 50          |
| 53325450       | 25450                      | M 25   | 4 x 5                      | 50          |
| 53325540       | 25540                      | M 25   | 5 x 4                      | 50          |
| 53325640       | 25640                      | M 25   | 6 x 4                      | 50          |
| 53332270       | 32270                      | M 32   | 2 x 7                      | 50          |
| 53332280       | 32280                      | M 32   | 2 x 8                      | 50          |
| 53332290       | 32290                      | M 32   | 2 x 9                      | 50          |
| 53332370       | 32370                      | M 32   | 3 x 7                      | 50          |
| 53332380       | 32380                      | M 32   | 3 x 8                      | 50          |
| 53332460       | 32460                      | M 32   | 4 x 6                      | 50          |
| 53332470       | 32470                      | M 32   | 4 x 7                      | 50          |
| 53332560       | 32560                      | M 32   | 5 x 6                      | 50          |
| 53332650       | 32650                      | M 32   | 6 x 5                      | 50          |
| 53332840       | 32840                      | M 32   | 8 x 4                      | 50          |
| 53332850       | 32850                      | M 32   | 8 x 5                      | 50          |
| 53332940       | 32940                      | M 32   | 9 x 4                      | 50          |
| 53340290       | 40290                      | M 40   | 2 x 9                      | 25          |
| 53340310       | 40310                      | M 40   | 3 x 10                     | 25          |
| 53340480       | 40480                      | M 40   | 4 x 8                      | 25          |

**SKINTOP® DIX-M**

12.09.2012

| Part number           | Article designation / size | Size M | Number of cables x cable Ø | Pieces / PU |
|-----------------------|----------------------------|--------|----------------------------|-------------|
| 53340490              | 40490                      | M 40   | 4 x 9                      | 25          |
| 53340580              | 40580                      | M 40   | 5 x 8                      | 25          |
| 53340590              | 40590                      | M 40   | 5 x 9                      | 25          |
| 53340670              | 40670                      | M 40   | 6 x 7                      | 25          |
| 53340860              | 40860                      | M 40   | 8 x 6                      | 25          |
| 53340969              | 40969                      | M 40   | 9 x 6,9                    | 25          |
| 53350118              | 50118                      | M 50   | 11 x 8                     | 10          |
| 53350680              | 50680                      | M 50   | 6 x 8                      | 10          |
| 53350780              | 50780                      | M 50   | 7 x 8                      | 10          |
| 53350870              | 50870                      | M 50   | 8 x 7                      | 10          |
| 53350147              | 50147                      | M 50   | 14 x 7                     | 10          |
| 53350164              | 50164                      | M 50   | 16 x 4                     | 10          |
| 53350166              | 50166                      | M 50   | 16 x 6                     | 10          |
| SKINTOP® DIX-M VITON® |                            |        |                            |             |
| 53420250              | 20250                      | M 20   | 2 x 5                      | 100         |
| 53420260              | 20260                      | M 20   | 2 x 6                      | 100         |
| 53440969              | 40969                      | M 40   | 9 x 6,9                    | 25          |