

|                   |                            |                                                                                    |
|-------------------|----------------------------|------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | <b>PRODUCT INFORMATION</b> |  |
|                   | <b>SKINTOP® MS-M-XL</b>    | <b>12.09.2012</b>                                                                  |

Especially for thick walls  
Maximum reliability  
Optimum strain relief  
Wide, variable clamping ranges



### Application range

With long connection thread for applications involving a thicker wall.

### Design

Metric connection thread acc. to EN 50262

### Approvals (Norm references)

UL File Nr. E79903

### Note

Counter nut to be used: SKINDICHT® SM-M

Refer to SKINTOP® metric accessories for suitable accessories

### Remark

Photographs are not to scale and do not represent detailed images of the respective products.

### Technical Data

Caution:

Refer to Appendix T21 for the installation dimensions and torques

Material:

Body: nickel-plated brass  
Insert: polyamide  
Sealing ring: CR  
O-ring: NBR

Protection rating:

Remark: A RoHS-non-compliant version is marketed under ÖLFLEX® 110 with VDE-REG.-Nr. 8067. To order this, please add appendix <1> to the below stated part numbers. This does not affect the above given further technical data or description.  
IP 69 K  
IP 68 - 10 bar

Temperature range:


Dynamic: -30 °C to +100 °C  
Fixed: -40 °C to +100 °C



|                    |                             |       |
|--------------------|-----------------------------|-------|
| Product Management | Document: LAPP_PRO988EN.pdf | 1 / 3 |
|--------------------|-----------------------------|-------|

| Part number      | Article designation / size | Clamping range ØF (mm) | SW (mm) | Overall length/ C (mm) | Thread length inner mm | Pieces / PU |
|------------------|----------------------------|------------------------|---------|------------------------|------------------------|-------------|
| SKINTOP® MS-M-XL |                            |                        |         |                        |                        |             |
| 53112005         | 12 x 1,5                   | 3-7                    | 16      | 32,8                   | 12.0                   | 100         |
| 53112015         | 16 x 1,5                   | 4,5-10                 | 20      | 37.0                   | 12.0                   | 50          |
| 53112025         | 20 x 1,5                   | 7-13                   | 24      | 39,5                   | 12.0                   | 50          |
| 53112035         | 25 x 1,5                   | 9-17                   | 29      | 41,5                   | 12.0                   | 25          |
| 53112045         | 32 x 1,5                   | 11-21                  | 36      | 48,2                   | 15.0                   | 25          |
| 53112055         | 40 x 1,5                   | 19-28                  | 45      | 53,5                   | 15.0                   | 10          |
| 53112065         | 50 x 1,5                   | 27-35                  | 54      | 57.0                   | 15.0                   | 5           |

|                   |                         |                                                                                                      |
|-------------------|-------------------------|------------------------------------------------------------------------------------------------------|
| U.I. Lapp<br>GmbH | PRODUCT INFORMATION     |  <b>LAPP GROUP</b> |
|                   | <b>SKINTOP® MS-M-XL</b> | <b>12.09.2012</b>                                                                                    |

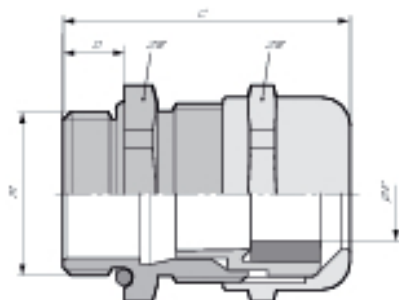

|                    |                             |       |
|--------------------|-----------------------------|-------|
| Product Management | Document: LAPP_PRO988EN.pdf | 3 / 3 |
|--------------------|-----------------------------|-------|