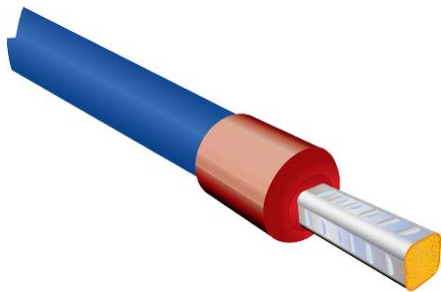


985895 Wire end crimping pliers**Description:**

- Stainless steel 5-cavity dies:
 - 0.5 to 0.75 mm².
 - 1 to 1.5 mm².
 - 2.5 mm².
 - 4 mm².
 - 6 mm².
 - Unlocking accessible at all times.
 - Reversed crimping: terminal positioned on the fixed part for more effectiveness and precision.
 - Capacity 0.5 to 6 mm².
 - Shape allowing hand setting.
 - Soft touch.
 - Length: 230 mm.
- Weight: 490 g.

Width I [mm]:	230
------------------	-----
