


Datasheet

Art.No. 56.404.9555.0

Installation terminal WKI 4 NT -D-SL /V0

Installation terminal block with screw connection for mounting on TS 35, nominal cross section 4 mm², width 6 mm, color gray

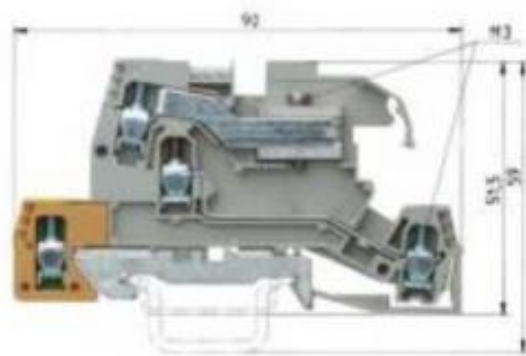

Art.No.	56.404.9555.0
EAN	4015573501195
Order unit	50 pieces

Approvals



Technical data

General

Nominal cross section	4 mm ²
Basic colour	Grey
Number of levels	3
Number of clamp positions per level	2
Width/grid dimension	6 mm
Insulating housing	PA666
Inflammability class of insulation material acc. with UL94	V0
Mounting method	DIN rail (top hat rail) 35/7.5 mm
Terminal blocks for electrical installations	Yes

Technical data

Rated current	26 A
Rated voltage	400 V
Rated impulse voltage	6 kV
Pollution degree	3
Closing plate required	Yes
Length	90 mm
Type of insulation material	Thermoplastic

Connection Data

Connection type 1	Screw connection
Connection type 2	Screw connection
Minimum cross section solid	0.5 mm ²

Maximum cross section solid	6 mm ²
Minimum cross section fine stranded	0.5 mm ²
Maximum cross section fine stranded	4 mm ²
Wire strip length	7 mm
Torque conductor mounting	0.5 Nm

Technical Data UL/CSA

Cross section UL	22-10 AWG
Voltage UL	300 V
Current factory wiring	24 A
Current field wiring	24 A
Cross section CSA	22-10 AWG
Voltage CSA	300 V
Current CSA	25 A

Accessories

N-function	No
------------	----

Drawings

