


D-SUB STANDARD – IP67 SOLID BODY

Solder cup – Precision machined contacts – For wire size AWG 20





RoHS compliant

SOCKET CONNECTOR

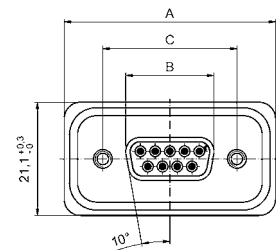


No. of pos.	A ^{+0.2} ₋₀	B ⁺⁰ _{-0.25}	C
09	39.40	16.46	25.00 ^{+0.12} _{-0.13}
15	47.70	24.79	33.32 ^{+0.13} _{-0.12}
25	61.40	38.50	47.04 ^{+0.13} _{-0.13}
37	78.00	54.96	63.50 ^{+0.13} _{-0.13}

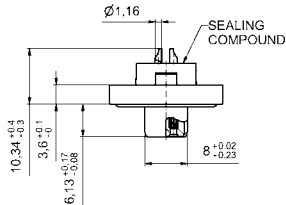 



DESCRIPTION

- Suitable for wire size **AWG 20**
- Mounting style:
4-40 UNC threaded insert including hex locking bolt
- Quality class 3 (also available in quality class 1)
- One-piece zinc die-cast nickel plated shell
- IP67 for harsh environments, pressure-proof up to 1.45 PSI
- Higher protection on request

PLUG CONNECTOR

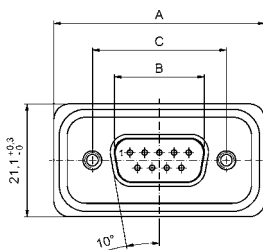

No. of pos.	A ^{+0.2} ₋₀	B ⁺⁰ _{-0.25}	C	D
09	39.40	16.81	25.00 ^{+0.12} _{-0.13}	6.00 ^{+0.12} _{-0.18}
15	47.70	25.14	33.32 ^{+0.13} _{-0.12}	6.00 ^{+0.12} _{-0.18}
25	61.40	38.86	47.04 ^{+0.13} _{-0.13}	5.99 ⁺⁰ _{-0.3}
37	78.00	55.32	63.50 ^{+0.13} _{-0.13}	5.99 ⁺⁰ _{-0.3}

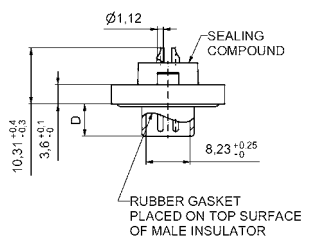 

ORDER DATA

SOCKET CONNECTOR		
No. of pos.	Mounting style 4-40 UNC	Part Number
09	Threaded insert	15-000613
15	Threaded insert	15-000623
25	Threaded insert	15-000633
37	Threaded insert	15-000643

PLUG CONNECTOR		
No. of pos.	Mounting style 4-40 UNC	Part Number
09	Threaded insert	15-000573
15	Threaded insert	15-000583
25	Threaded insert	15-000593
37	Threaded insert	15-000603