




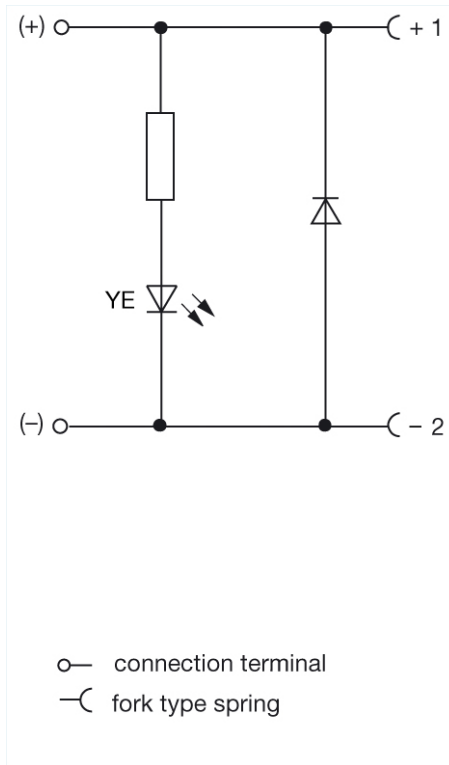
Product information GDME LED 24 HH YE

Industrial Connecting Solutions:Rectangular Connectors:Valve Connectors (Type A -B -C):Type A:Field Attachable Valve Connectors:Electronic inserts for GDME:GDME LED 24 HH YE

<https://www.e-catalog.beldensolutions.com:443/link/57078-24228-256261-256266-256270-276215-24315-35667/en/conf/uisstate>

| | |
|---------------------------------|---|
| Name | GDME LED 24 HH YE |
| |  |
| | function indicator (LED) with protective circuit |
| Delivery informations | |
| Availability | available |
| Product description | |
| Description | function indicator (LED) with protective circuit |
| Type | GDME LED 24 HH YE |
| Order No. | 831 873-001 |
| Standard | DIN EN 175 301-803-A |
| Construction type | A |
| Description of Wiring | |
| LED color | LED yellow |
| Suppressor | diode |
| Technical data | |
| Rated voltage | DC 24 V |
| Rated current | 8 A |
| Environmental conditions | |
| Temperature range | -40 °C to +110 °C |
| Packaging unit | |
| Packaging unit | 50 pieces |

Picture
Drawing



Belden Deutschland GmbH
 Im Gewerbepark 2
 58579 Schalksmühle
 Germany
 Phone: +49 7127/14-1806
 E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.