

## Product information

# 88 02 250

## KNIPEX Alligator®

### Water Pump Pliers

DIN ISO 8976

- With slim multi-component grips without collar for better handling and easier transport
- Self-locking on pipes and nuts: no slipping on the workpiece and low handforce required
- Gripping surfaces with special hardened teeth, teeth hardness approx. 61 HRC: high wear resistance and stable gripping
- Box-joint design for high stability due to double guide
- Robust construction, insensitive to dirt; particularly suitable for outdoor work
- Pinch guard prevents operators' fingers being pinched
- Chrome vanadium electric steel, forged, multi stage oil-hardened



### General

Article No.	88 02 250
EAN	4003773019282
Pliers	black atramentized
Head	polished
Handles	with slim multi-component grips
weight	347 g
Dimensions	250 x 50 x 18 mm
Standard	DIN ISO 8976
Reach	no
RohS	no



### Technical details

Adjustment positions	9
Capacity for pipes, inches (diameter)	Ø 2 Inch
Capacities for nuts	46 mm
Capacities for pipes (diameter)	Ø 50 mm

### Classification

eCl@ss 5.1.4	21040301
ETIM 5.0	EC000164
ETIM 6.0	EC000164
proficl@ss 6.0	AAA936c004
UNSPSC 13.1	27112111

*technical change and errors excepted*

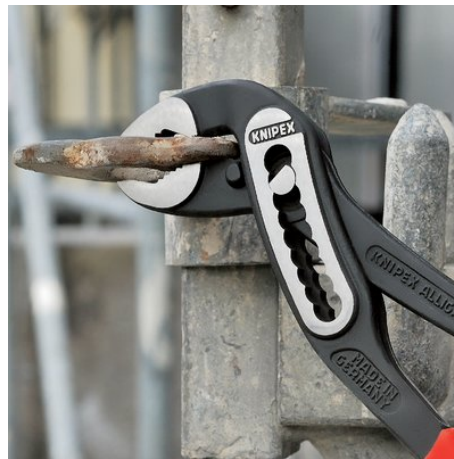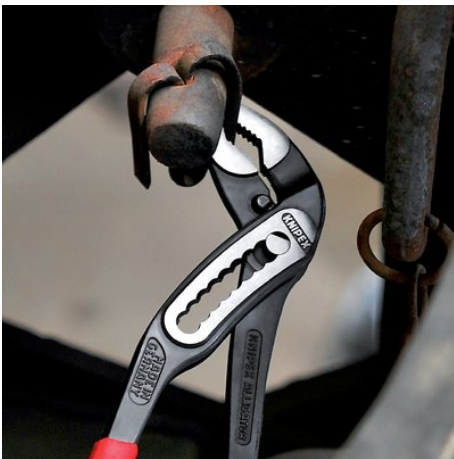



Self-locking on pipes and nuts: no slipping on the workpiece; the complete actuating force can be used to turn the workpieces; not having to squeeze the pliers handles reduces the required effort

