


Product information

97 49 15

- Application: Flag terminals and non-insulated, open plug type connectors (6.3 mm connector width) 1.25-2.5 + 3.0-6.0 mm²

Crimping dies

For plug connectors and non-insulated open plug-type connectors

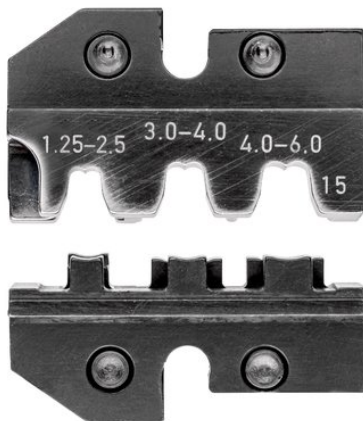

General

Article No.	97 49 15
EAN	4003773043164
weight	56 g
Dimensions	50 x 17 mm
Reach	yes
RohS	no

Technical details



Applications	for plug connectors and angled spade connectors according to DIN 46346 Form A (1.5 - 2.5 mm ²) 2 + 3 crimping die: for non-insulated, open lug connectors (straight version) according to DIN 46247 (2.5 – 6 mm ²)
Capacity in square millimetres	1.25 — 2.5 / 3 — 6 mm ²
Number of crimping positions	2
AWG	17 — 13 / 17 — 10



Classification	
eCl@ss 5.1.4	21040301
ETIM 5.0	EC000168
ETIM 6.0	EC000168
proficl@ss 6.0	AAA946c003
UNSPSC 13.1	27112820

technical change and errors excepted