

## Product information

# 97 52 06

## Crimping Pliers

Also for two-hand operation




- For solder-free electrical connections
- The ingenious lever transmission reduces the handforce up to 30% compared with regular crimping pliers
- Consistently high crimping quality thanks to precision dies and forced locking mechanism (unlockable)
- Crimping pressure has been set precisely (calibrated) in the factory, re-adjustable
- Two-hand operation for easy crimping of large conductor diameters
- Easy handling as a result of well balanced centre of gravity, angled head and ergonomically shaped handles
- Chrome vanadium electric steel in special quality, oil-hardened

### General

Article No.	97 52 06
EAN	4003773025474
Pliers	burnished
Head	burnished
Handles	with non-slip plastic grips
weight	565 g
Dimensions	250 x 70 x 25 mm
Reach	yes
RohS	no

### Technical details



Applications	insulated terminals, plug connectors + butt connectors
Capacity in square millimetres	0.5 — 6 mm <sup>2</sup>
Number of crimping positions	3
AWG	20 — 10


### Classification

eCl@ss 5.1.4	21040301
ETIM 5.0	EC000168
ETIM 6.0	EC000168
proficl@ss 6.0	AAA946c003
UNSPSC 13.1	27112147

*technical change and errors excepted*



Third step: when greater hand force is required, such as e.g. when crimping insulated connectors 6.0 mm<sup>2</sup>, two-hand operation is possible by the longer handles

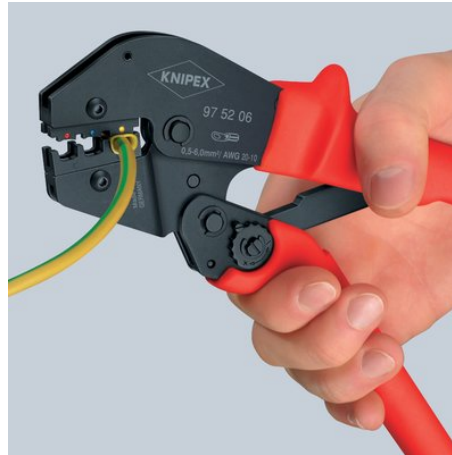

Second step: now use the whole hand for further crimping procedure



First step: move the handle with two fingers only until both jaws touch the connector to be crimped