

Product information

12 42 195

KNIPEX MultiStrip 10 Automatic Insulation Stripper



- Stripping without re-adjustment from 0.03 to 10.0 mm²
- Recessed wire cutter
- Universal blade geometry – robust and more durable
- Ideal grip design with excellent haptics
- Fully automatic adjustment to all single-, multi- and fine-stranded conductors with standard insulation throughout the entire capacity range from 0.03 to 10.0 mm²
- No manual fine adjustment necessary
- No damage to the conductors
- The clamping jaws made of steel hold the cable in a way that prevents slipping without damaging the remaining insulation
- With recessed wire cutter for Cu and Al conductors, stranded up to 10 mm² and single wire up to 6 mm²
- Particularly smooth-running mechanics and very low weight
- Replaceable blades block and length stop
- Handle with soft-plastic zone for a steady grip
- Body: plastic, fibreglass-reinforced
- Blade: special tool steel, oil-hardened

AAA



General	
Article No.	12 42 195
EAN	4003773054580
weight	136 g
Dimensions	195 x 112 x 18 mm
Reach	yes
RohS	no


Technical details	
Stripping capacities in square millimetres	0.03 — 10.0 mm ²
AWG	32 — 8

Classification	
eCl@ss 5.1.4	21040302
ETIM 5.0	EC000163
ETIM 6.0	EC000163
proficl@ss 6.0	AAA002c003
UNSPSC 13.1	27111510

technical change and errors excepted



Steel clamping jaws avoid slipping of the cable

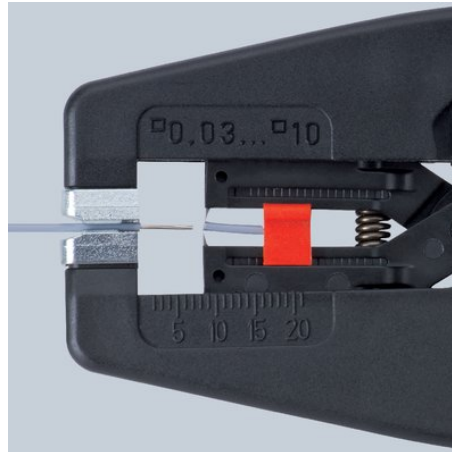

Precise stripping from 0.03 to 10 mm² without re-adjustment



Wire cutter for multiple stranded wire cables up to 10.0 mm²

