

Product information

26 11 200

Snipe Nose Side Cutting Pliers (Stork Beak Pliers)


DIN ISO 5745

- Elastic tips: dimensionally stable even when twisted
- Distortion-tolerant, elastic precision tips
- Half-round, long, tapered jaws
- With cutting edges for soft, medium-hard and hard wire
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 61 HRC
- Straight jaws
- Vanadium electric steel, forged, multi stage oil-hardened



General	
Article No.	26 11 200
EAN	4003773022824
Pliers	black atramentized
Head	polished
Handles	plastic coated
weight	170 g
Dimensions	200 x 51 x 13 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details	
	Ø 3.2 mm
	Ø 2.2 mm
	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.5 mm
	73.0 mm
Head width (W3)	18 mm
Style	1

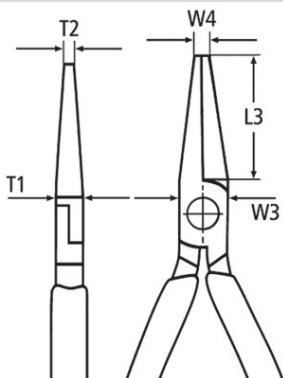

Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	EAC420c044
UNSPSC 13.1	27112134

technical change and errors excepted

