

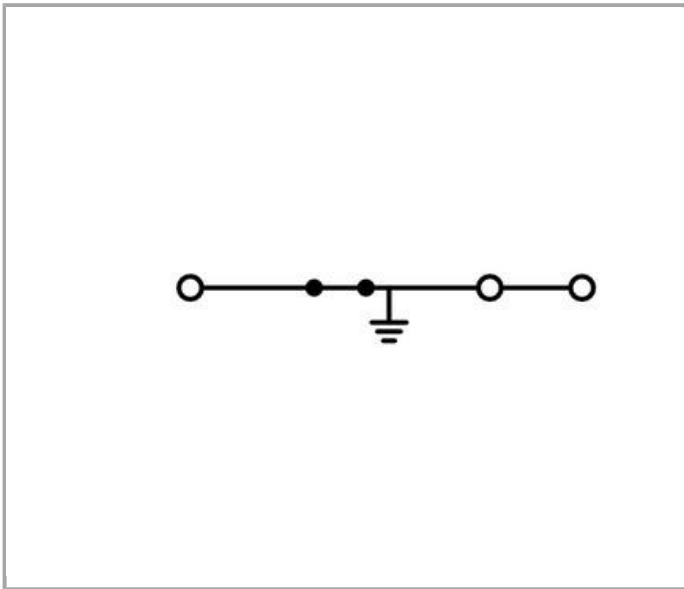


Data sheet | Item number: 2006-1307

3-conductor ground terminal block; 6 mm²; suitable for Ex e II applications;
side and center marking; for DIN-rail 35 x 15 and 35 x 7.5; Push-in CAGE
CLAMP®

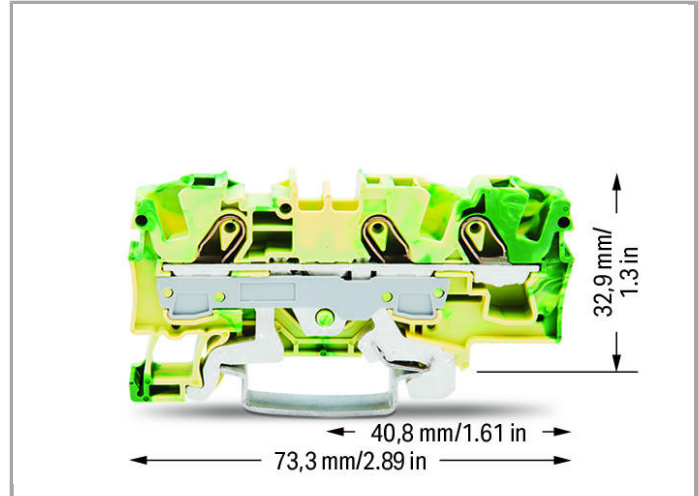

www.wago.com/2006-1307

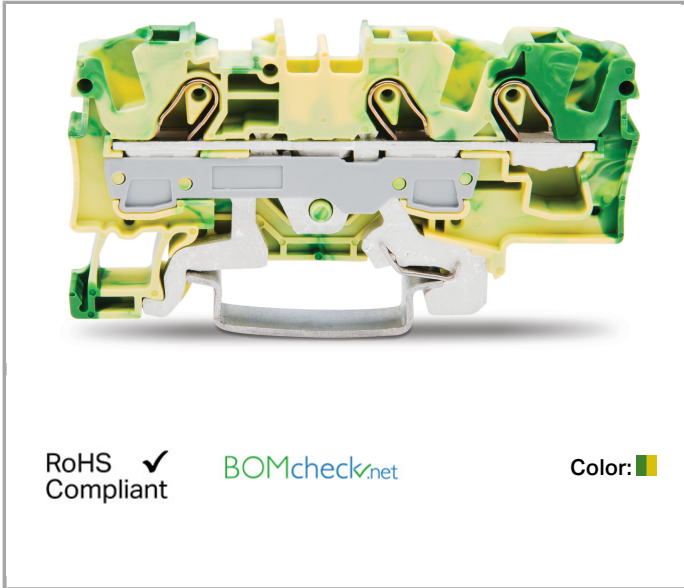

Data

Connection data

| | |
|---------------------------------|---------------------------|
| Connection technology | Push-in CAGE CLAMP® |
| Actuation type | Push-in Open Tool Slot |
| Connectable conductor materials | Copper |
| Nominal cross section | 6 mm ² |

| | |
|---|---|
| Solid conductor | 0.5 ... 10 mm ² / 20 ... 8 AWG |
| Solid conductor, push-in termination | 2.5 ... 10 mm ² / 14 ... 8 AWG |
| Fine-stranded conductor | 0.5 ... 10 mm ² / 20 ... 8 AWG |
| Fine-stranded conductor with ferrule, push-in termination, from | 2.5 mm ² / 16 AWG |
| Strip length | 13 ... 15 mm / 0.51 ... 0.59 Inch |
| Total number of connection points | 3 |
| Total number of potentials | 1 |
| Number of levels | 1 |
| Type of wiring | Front-entry wiring |

Geometrical Data

| | |
|---------------------------------------|----------------------|
| Width | 7.5 mm / 0.295 inch |
| Height from upper-edge of DIN-35 rail | 32.9 mm / 1.295 inch |
| Depth | 73.5 mm / 2.894 inch |

Mechanical data




| | |
|------------------|---------------------|
| Design | horizontal |
| Type of mounting | DIN-35 rail |
| Marking level | Center/side marking |

Material Data

| | |
|---------------------|----------------------|
| Color | green-yellow |
| Insulating material | Polyamide 66 (PA 66) |
| Fire load | 0.187 MJ |
| Weight | 20.285 g |

Approvals / Certificates





Country specific Approvals

| Logo | Approval | Certificate name |
|--|---------------------------------|------------------|
|  | CCA DEKRA Certification B.V. | NTR NL 7311 |
|  | CCA DEKRA Certification B.V. | 71-101179 |
|  | CSA DEKRA Certification B.V. | 1543858 |
| | CSA | 1543858 |




DEKRA Certification B.V.

Ship Approvals

| Logo | Approval | Certificate name |
|--|---|------------------|
|  | ABS American Bureau of Shipping | 14-HG1293677-PDA |
|  | BV Bureau Veritas S.A. | 38586/A0 BV |
|  | DNV GL Det Norske Veritas, Germanischer Lloyd | TAE00001V2 |
|  | LR Lloyds Register | 91/20112 (E9) |

UL-Approvals

| Logo | Approval | Certificate name |
|--|--|------------------|
|  | UL UL International Germany GmbH | E45172 |

Subject to changes.