

Product information

86 03 180

Pliers Wrench

Pliers and a wrench in a single tool




- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Also excellent for gripping, holding, pressing and bending workpieces
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Fast adjustment by pushing a button directly on the workpiece
- No unintentional shift of the gripping jaws and no slipping of the joint
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Lever transmission greater than 10 : 1 for strong gripping power
- Chrome vanadium electric steel, forged, oil-hardened

General

Article No.	86 03 180
EAN	4003773035466
Pliers	chrome plated
Head	chrome plated
Handles	plastic coated
weight	230 g
Dimensions	180 x 44 x 15 mm
Reach	no
RohS	no

Technical details

	8.0 mm
Joint thickness (B3)	12.0 mm
Tips thickness (B1)	5.0 mm
Adjustment positions	15
Capacities for nuts	1 1/2
Capacities for nuts	40 mm

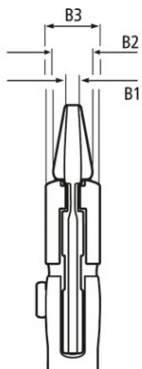

Classification

eCl@ss 5.1.4	21043826
proficl@ss 6.0	AAA936c004
UNSPSC 13.1	27112112

technical change and errors excepted

