

Product information

86 03 300

Pliers Wrench

Pliers and a wrench in a single tool




- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Also excellent for gripping, holding, pressing and bending workpieces
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Fast adjustment by pushing a button directly on the workpiece
- No unintentional shift of the gripping jaws and no slipping of the joint
- Replaces the need for sets of metric and imperial spanners
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Lever transmission greater than 10 : 1 for strong gripping power
- Chrome vanadium electric steel, forged, oil-hardened



| General | |
|-------------|------------------|
| Article No. | 86 03 300 |
| EAN | 4003773041429 |
| Pliers | chrome plated |
| Head | chrome plated |
| Handles | plastic coated |
| weight | 725 g |
| Dimensions | 300 x 75 x 20 mm |
| Reach | no |
| RohS | no |

| Technical details | |
|----------------------|---------|
| | 9.5 mm |
| Joint thickness (B3) | 15.0 mm |
| Tips thickness (B1) | 9.5 mm |
| Adjustment positions | 22 |
| Capacities for nuts | 2 3/8 |
| Capacities for nuts | 60 mm |

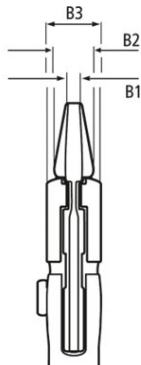

Classification

| | |
|----------------|------------|
| eCl@ss 5.1.4 | 21043826 |
| proficl@ss 6.0 | AAA936c004 |
| UNSPSC 13.1 | 27112112 |

technical change and errors excepted

