


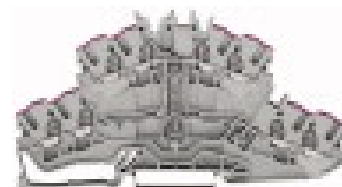

4-conductor double deck terminal block; 8-conductor through terminal block; L; without marker carrier; gray housing; internal commoning; conductor entry with violet marking; HORIZONTAL TYPE

Item No.: 2002-2408



Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	2002-2408
GTIN / EAN	4050821145011
Content	1

Notes

Technical data



Miscellaneous



Ratings per	IEC/EN 60947-7-1
Rated voltage (III / 3) [V]	800 [V]

Printview: 4-conductor double deck terminal block; 8-conductor through terminal block; L; without marker carrier; gray housing; internal commoning; conductor entry with violet marking; HORIZONTAL TYPE - Item No.: 2002-2408

Technical data	
<i>Rated impulse voltage (III / 3) [kV]</i>	<i>8 [kV]</i>
<i>Rated current [A]</i>	<i>24 [A]</i>
<i>Rated current (2) [A]</i>	<i>28 [A]</i>
<i>Legend (ratings)</i>	<i>(III / 3) Overvoltage category III / Pollution degree 3</i>
<i>Type of wiring</i>	<i>Front-entry wiring</i>
<i>Total number of connection points</i>	<i>8</i>
<i>Total number of potentials</i>	<i>1</i>
<i>Number of levels</i>	<i>2</i>
<i>Connection technology</i>	<i>Push-in CAGE CLAMP®</i>
<i>Actuation type</i>	<i>Push-in</i>
<i>Connectable conductor materials</i>	<i>Copper</i>
<i>Nominal cross section</i>	<i>2.5 mm²</i>
<i>Solid conductor</i>	<i>0.25 ... 4 mm² / 22 ... 12 AWG</i>
<i>Solid conductor, push-in termination</i>	<i>0.75 ... 4 mm² / 18 ... 12 AWG</i>
<i>Fine-stranded conductor</i>	<i>0.25 ... 4 mm² / 22 ... 12 AWG</i>
<i>Fine-stranded conductor with ferrule, push-in termination, f</i>	<i>0.75 mm² / 18 AWG</i>
<i>Strip length</i>	<i>10 ... 12 mm / 0.39 ... 0.47 Inch</i>
<i>Width</i>	<i>5.2 mm / 0.205 Inch</i>
<i>Height from upper-edge of DIN-35 rail</i>	<i>52.1 mm / 2.051 Inch</i>
<i>Depth</i>	<i>105.1 mm / 4.138 Inch</i>
<i>Design</i>	<i>horizontal</i>
<i>Type of mounting</i>	<i>Carrier rail 35 x 15</i>
<i>Potential marking</i>	<i>L</i>
<i>Marking level</i>	<i>Center/side marking</i>
<i>Color</i>	<i>gray</i>
<i>Insulating material</i>	<i>Polyamide 66 (PA 66)</i>
<i>Fire load [MJ]</i>	<i>0.291 [MJ]</i>
<i>Weight [g]</i>	<i>16.142 [g]</i>
<i>Product Family</i>	<i>TOPJOB® S</i>
<i>Main product function</i>	<i>Multilevel terminal blocks</i>
<i>Product type</i>	<i>Through rail-mount term. blocks</i>

Images & drawings

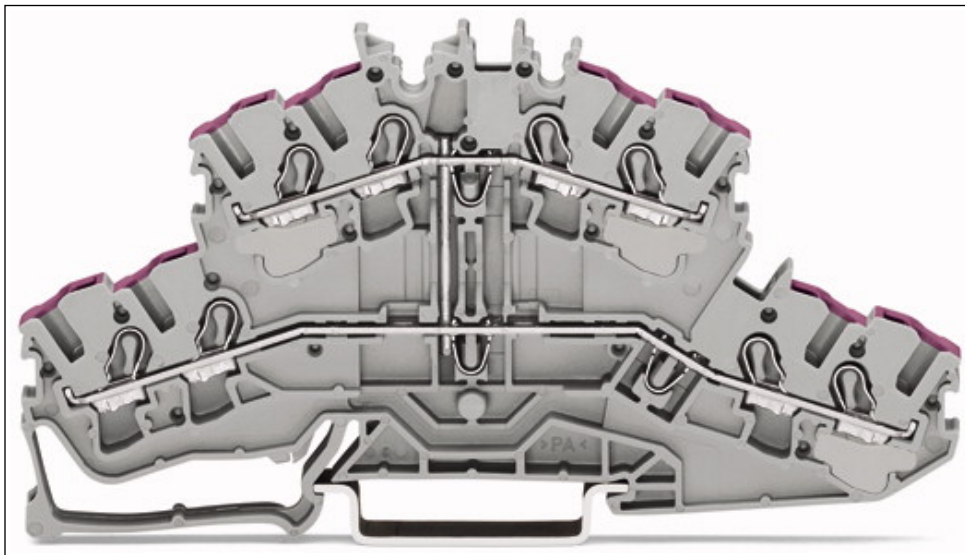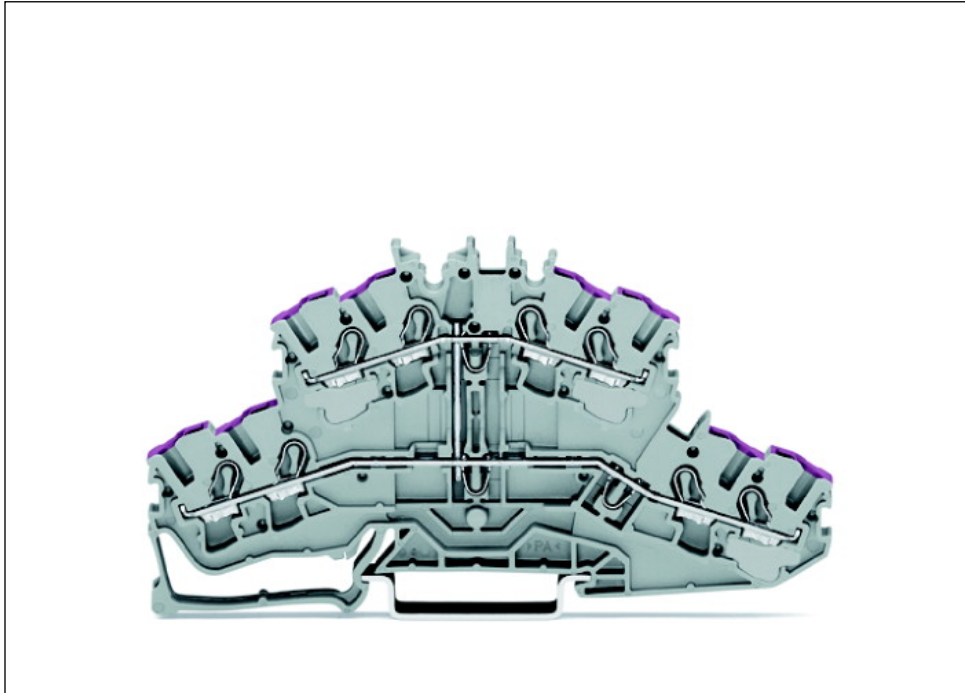

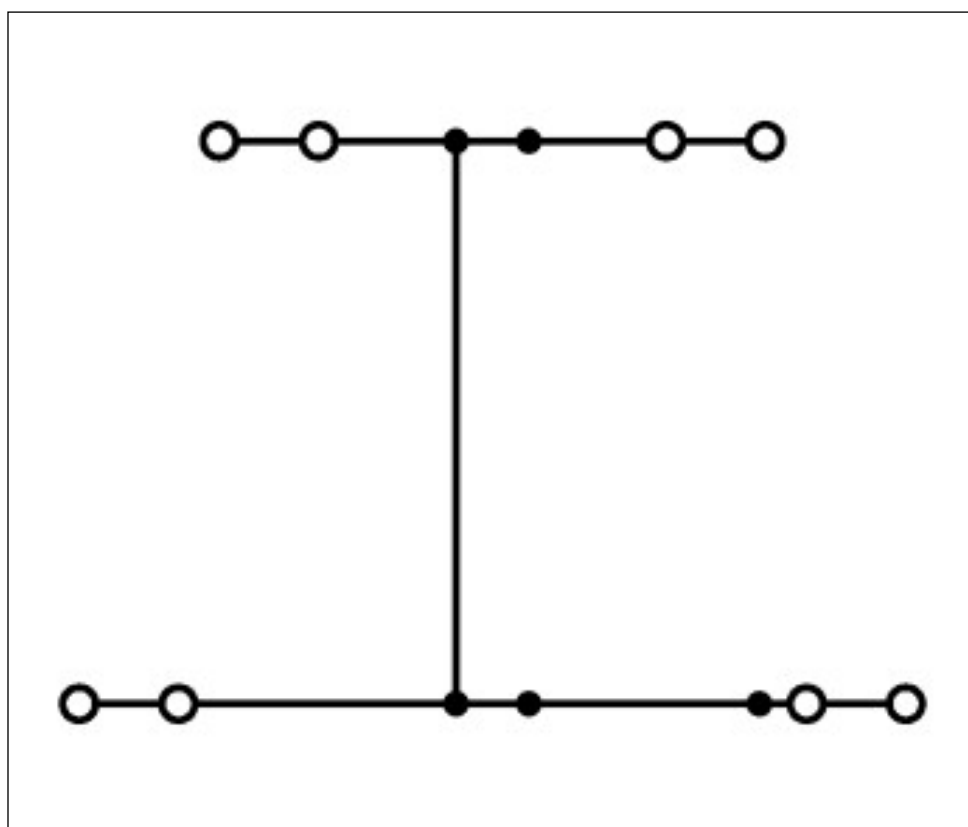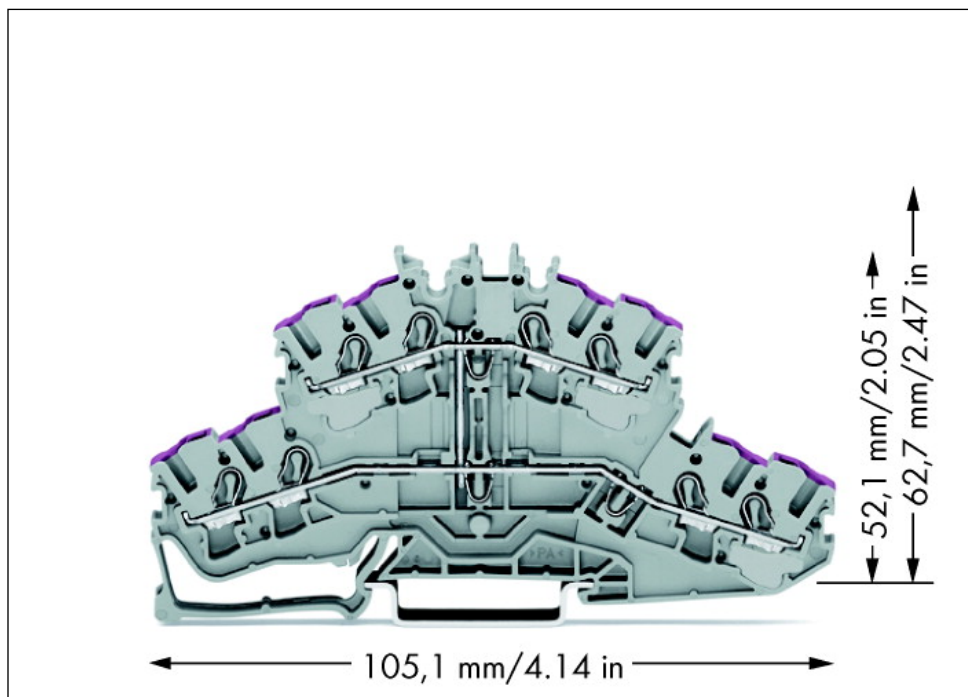

Printview: 4-conductor double deck terminal block; 8-conductor through terminal block; L; without marker carrier; gray housing; internal commoning; conductor entry with violet marking; HORIZONTAL TYPE - Item No.: 2002-2408

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.