


Data sheet | Item number: 2020-1304

2-conductor/1-pin carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5;
Push-in CAGE CLAMP®

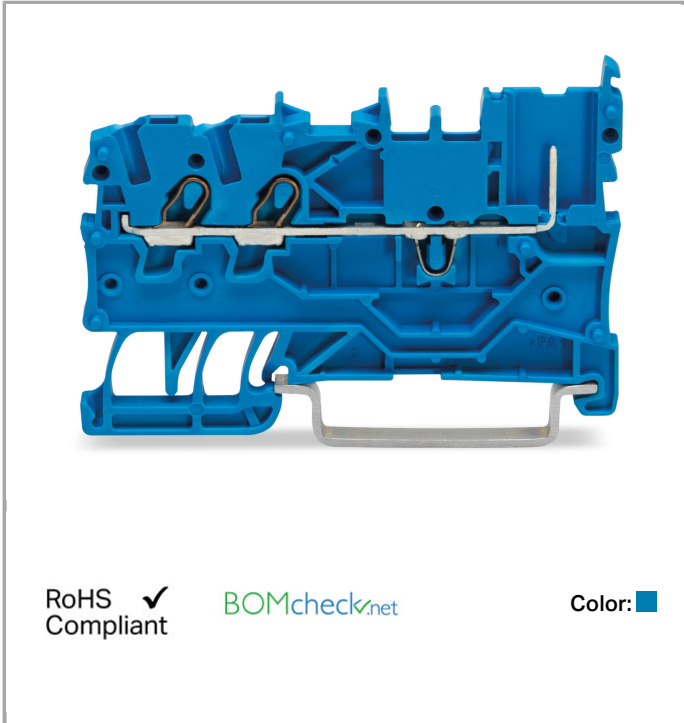

www.wago.com/2020-1304



RoHS
Compliant

BOMcheck.net

Color: ■

Data

Electrical data

Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	500 V
Rated impulse voltage (III / 3)	6 kV
Rated current	13.5 A
Legend (ratings)	(III / 3) ≙ Overvoltage category III / Pollution degree 3

Approvals per UL 1059

Rated voltage UL (Use Group B)	300 V
Rated current UL (Use Group B)	15 A
Rated voltage UL (Use Group C)	300 V
Rated current UL (Use Group C)	15 A
Rated voltage UL (Use Group D)	300 V
Rated current UL (Use Group D)	15 A



Approvals per CSA

Rated voltage CSA (Use Group B)	300 V
Rated current CSA (Use Group B)	10 A
Rated voltage CSA (Use Group C)	300 V
Rated current CSA (Use Group C)	10 A

Connection data

Connection technology	Push-in CAGE CLAMP®
Number of connection points (connection type)	2
Actuation type	Open Tool Slot Push-in
Connectable conductor materials	Copper
Nominal cross section	1 mm ²
Solid conductor	0.14 ... 1.5 mm ² / 24 ... 16 AWG
Solid conductor, push-in termination	0.5 ... 1.5 mm ² / 20 ... 16 AWG
Fine-stranded conductor	0.14 ... 1.5 mm ² / 24 ... 16 AWG
Fine-stranded conductor with ferrule, push-in termination, from	0.5 mm ² / 20 AWG
Strip length	9 ... 11 mm / 0.35 ... 0.43 Inch
Number of connection points	1
Total number of connection points	2
Total number of potentials	1
Number of levels	1
Type of wiring	Front-entry wiring

Geometrical Data

Width	3.5 mm / 0.138 inch
Height from upper-edge of DIN-35 rail	32.5 mm / 1.28 inch
Depth	58.2 mm / 2.291 inch

Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center/side marking

Material Data

Color	blue
Insulating material	Polyamide 66 (PA 66)
Fire load	0.1 MJ




Weight	4.55 g
--------	--------

Commercial data



Packaging type	BOX
Country of origin	CN
GTIN	4055143278829
Customs Tariff No.	85366990990

Approvals / Certificates

Country specific Approvals


Logo	Approval	Certificate name
	CCA	NTR NL 7617
	CSA DEKRA Certification B.V.	2516073
	KEMA/KEUR DEKRA Certification B.V.	71-100670










UL-Approvals











Logo	Approval	Certificate name
	UL UL International Germany GmbH	E45172
	UL Underwriters Laboratories Inc.	E45172

Compatible products

Female plug

	Item no.: 2020-102 1-conductor female plug; 1.5 mm ² ; 2-pole	www.wago.com/2020-102
	Item no.: 2020-102/122-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 2-pole	www.wago.com/2020-102/122-000

	Item no.: 2020-102/132-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 2-pole	www.wago.com/2020-102/132-000
	Item no.: 2020-102/142-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 2-pole	www.wago.com/2020-102/142-000
	Item no.: 2020-103 1-conductor female plug; 1.5 mm ² ; 3-pole	www.wago.com/2020-103
	Item no.: 2020-103/000-036 1-conductor female plug; 1.5 mm ² ; 3-pole	www.wago.com/2020-103/000-036
	Item no.: 2020-103/000-037 1-conductor female plug; 1.5 mm ² ; 3-pole	www.wago.com/2020-103/000-037
	Item no.: 2020-103/000-038 1-conductor female plug; 1.5 mm ² ; 3-pole	www.wago.com/2020-103/000-038
	Item no.: 2020-103/000-039 1-conductor female plug; 1.5 mm ² ; 3-pole	www.wago.com/2020-103/000-039
	Item no.: 2020-103/122-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 3-pole	www.wago.com/2020-103/122-000
	Item no.: 2020-103/132-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 3-pole	www.wago.com/2020-103/132-000
	Item no.: 2020-103/142-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 3-pole	www.wago.com/2020-103/142-000
	Item no.: 2020-104 1-conductor female plug; 1.5 mm ² ; 4-pole	www.wago.com/2020-104
	Item no.: 2020-104/000-036 1-conductor female plug; 1.5 mm ² ; 4-pole	www.wago.com/2020-104/000-036
	Item no.: 2020-104/000-037 1-conductor female plug; 1.5 mm ² ; 4-pole	www.wago.com/2020-104/000-037
	Item no.: 2020-104/000-038 1-conductor female plug; 1.5 mm ² ; 4-pole	www.wago.com/2020-104/000-038
	Item no.: 2020-104/000-039 1-conductor female plug; 1.5 mm ² ; 4-pole	www.wago.com/2020-104/000-039

	Item no.: 2020-104/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 4-pole	www.wago.com/2020-104/124-000
	Item no.: 2020-104/133-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 4-pole	www.wago.com/2020-104/133-000
	Item no.: 2020-104/143-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 4-pole	www.wago.com/2020-104/143-000
	Item no.: 2020-105 1-conductor female plug; 1.5 mm ² ; 5-pole	www.wago.com/2020-105
	Item no.: 2020-105/000-036 1-conductor female plug; 1.5 mm ² ; 5-pole	www.wago.com/2020-105/000-036
	Item no.: 2020-105/000-037 1-conductor female plug; 1.5 mm ² ; 5-pole	www.wago.com/2020-105/000-037
	Item no.: 2020-105/000-038 1-conductor female plug; 1.5 mm ² ; 5-pole	www.wago.com/2020-105/000-038
	Item no.: 2020-105/000-039 1-conductor female plug; 1.5 mm ² ; 5-pole	www.wago.com/2020-105/000-039
	Item no.: 2020-105/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 5-pole	www.wago.com/2020-105/124-000
	Item no.: 2020-105/133-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 5-pole	www.wago.com/2020-105/133-000
	Item no.: 2020-105/143-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 5-pole	www.wago.com/2020-105/143-000
	Item no.: 2020-106 1-conductor female plug; 1.5 mm ² ; 6-pole	www.wago.com/2020-106
	Item no.: 2020-106/000-036 1-conductor female plug; 1.5 mm ² ; 6-pole	www.wago.com/2020-106/000-036
	Item no.: 2020-106/000-037 1-conductor female plug; 1.5 mm ² ; 6-pole	www.wago.com/2020-106/000-037
	Item no.: 2020-106/000-038 1-conductor female plug; 1.5 mm ² ; 6-pole	www.wago.com/2020-106/000-038



Item no.: 2020-106/000-039
1-conductor female plug; 1.5 mm²; 6-pole

www.wago.com/2020-106/000-039

Item no.: 2020-106/124-000
1-conductor female plug; Locking lever; 1.5 mm²; 6-pole

www.wago.com/2020-106/124-000

Item no.: 2020-106/133-000
1-conductor female plug; Strain relief plate; 1.5 mm²; 6-pole

www.wago.com/2020-106/133-000

Item no.: 2020-106/143-000
1-conductor female plug; Strain relief plate; 1.5 mm²; 6-pole

www.wago.com/2020-106/143-000

Item no.: 2020-107
1-conductor female plug; 1.5 mm²; 7-pole

www.wago.com/2020-107



Item no.: 2020-107/000-036
1-conductor female plug; 1.5 mm²; 7-pole

www.wago.com/2020-107/000-036



Item no.: 2020-107/000-037
1-conductor female plug; 1.5 mm²; 7-pole

www.wago.com/2020-107/000-037



Item no.: 2020-107/000-038
1-conductor female plug; 1.5 mm²; 7-pole

www.wago.com/2020-107/000-038



Item no.: 2020-107/000-039
1-conductor female plug; 1.5 mm²; 7-pole

www.wago.com/2020-107/000-039

Item no.: 2020-107/124-000
1-conductor female plug; Locking lever; 1.5 mm²; 7-pole

www.wago.com/2020-107/124-000

Item no.: 2020-107/134-000
1-conductor female plug; Strain relief plate; 1.5 mm²; 7-pole

www.wago.com/2020-107/134-000

Item no.: 2020-107/144-000
1-conductor female plug; Strain relief plate; 1.5 mm²; 7-pole

www.wago.com/2020-107/144-000

Item no.: 2020-108
1-conductor female plug; 1.5 mm²; 8-pole





www.wago.com/2020-108

Item no.: 2020-108/000-036
1-conductor female plug; 1.5 mm²; 8-pole

www.wago.com/2020-108/000-036

Item no.: 2020-108/000-037
1-conductor female plug; 1.5 mm²; 8-pole

www.wago.com/2020-108/000-037

	Item no.: 2020-108/000-038 1-conductor female plug; 1.5 mm ² ; 8-pole	www.wago.com/2020-108/000-038
	Item no.: 2020-108/000-039 1-conductor female plug; 1.5 mm ² ; 8-pole	www.wago.com/2020-108/000-039
	Item no.: 2020-108/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 8-pole	www.wago.com/2020-108/124-000
	Item no.: 2020-108/134-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 8-pole	www.wago.com/2020-108/134-000
	Item no.: 2020-108/144-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 8-pole	www.wago.com/2020-108/144-000
	Item no.: 2020-109 1-conductor female plug; 1.5 mm ² ; 9-pole	www.wago.com/2020-109
	Item no.: 2020-109/000-036 1-conductor female plug; 1.5 mm ² ; 9-pole	www.wago.com/2020-109/000-036
	Item no.: 2020-109/000-037 1-conductor female plug; 1.5 mm ² ; 9-pole	www.wago.com/2020-109/000-037
	Item no.: 2020-109/000-038 1-conductor female plug; 1.5 mm ² ; 9-pole	www.wago.com/2020-109/000-038
	Item no.: 2020-109/000-039 1-conductor female plug; 1.5 mm ² ; 9-pole	www.wago.com/2020-109/000-039
	Item no.: 2020-109/124-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 9-pole	www.wago.com/2020-109/124-000
	Item no.: 2020-109/134-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 9-pole	www.wago.com/2020-109/134-000
	Item no.: 2020-109/144-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 9-pole	www.wago.com/2020-109/144-000
	Item no.: 2020-110 1-conductor female plug; 1.5 mm ² ; 10-pole	www.wago.com/2020-110
	Item no.: 2020-110/000-036 1-conductor female plug; 1.5 mm ² ; 10-pole	www.wago.com/2020-110/000-036



Item no.: 2020-110/000-037 1-conductor female plug; 1.5 mm ² ; 10-pole	www.wago.com/2020-110/000-037
Item no.: 2020-110/000-038 1-conductor female plug; 1.5 mm ² ; 10-pole	www.wago.com/2020-110/000-038
Item no.: 2020-110/000-039 1-conductor female plug; 1.5 mm ² ; 10-pole	www.wago.com/2020-110/000-039
Item no.: 2020-110/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 10-pole	www.wago.com/2020-110/125-000
Item no.: 2020-110/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 10-pole	www.wago.com/2020-110/135-000
Item no.: 2020-110/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 10-pole	www.wago.com/2020-110/145-000
Item no.: 2020-111 1-conductor female plug; 1.5 mm ² ; 11-pole	www.wago.com/2020-111
Item no.: 2020-111/000-036 1-conductor female plug; 1.5 mm ² ; 11-pole	www.wago.com/2020-111/000-036
Item no.: 2020-111/000-037 1-conductor female plug; 1.5 mm ² ; 11-pole	www.wago.com/2020-111/000-037
Item no.: 2020-111/000-038 1-conductor female plug; 1.5 mm ² ; 11-pole	www.wago.com/2020-111/000-038
Item no.: 2020-111/000-039 1-conductor female plug; 1.5 mm ² ; 11-pole	www.wago.com/2020-111/000-039
Item no.: 2020-111/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 11-pole	www.wago.com/2020-111/125-000
Item no.: 2020-111/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 11-pole	www.wago.com/2020-111/135-000
Item no.: 2020-111/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 11-pole	www.wago.com/2020-111/145-000
Item no.: 2020-112 1-conductor female plug; 1.5 mm ² ; 12-pole	www.wago.com/2020-112



Item no.: 2020-112/000-036
1-conductor female plug; 1.5 mm²; 12-pole

www.wago.com/2020-112/000-036



Item no.: 2020-112/000-037
1-conductor female plug; 1.5 mm²; 12-pole

www.wago.com/2020-112/000-037



Item no.: 2020-112/000-038
1-conductor female plug; 1.5 mm²; 12-pole

www.wago.com/2020-112/000-038



Item no.: 2020-112/000-039
1-conductor female plug; 1.5 mm²; 12-pole

www.wago.com/2020-112/000-039

Item no.: 2020-112/125-000
1-conductor female plug; Locking lever; 1.5 mm²; 12-pole

www.wago.com/2020-112/125-000

Item no.: 2020-112/135-000
1-conductor female plug; Strain relief plate; 1.5 mm²; 12-pole

www.wago.com/2020-112/135-000

Item no.: 2020-112/145-000
1-conductor female plug; Strain relief plate; 1.5 mm²; 12-pole

www.wago.com/2020-112/145-000

Item no.: 2020-113
1-conductor female plug; 1.5 mm²; 13-pole

www.wago.com/2020-113

Item no.: 2020-113/000-036
1-conductor female plug; 1.5 mm²; 13-pole

www.wago.com/2020-113/000-036

Item no.: 2020-113/000-037
1-conductor female plug; 1.5 mm²; 13-pole

www.wago.com/2020-113/000-037

Item no.: 2020-113/000-038
1-conductor female plug; 1.5 mm²; 13-pole

www.wago.com/2020-113/000-038

Item no.: 2020-113/000-039
1-conductor female plug; 1.5 mm²; 13-pole

www.wago.com/2020-113/000-039

Item no.: 2020-113/125-000
1-conductor female plug; Locking lever; 1.5 mm²; 13-pole

www.wago.com/2020-113/125-000

Item no.: 2020-113/135-000
1-conductor female plug; Strain relief plate; 1.5 mm²; 13-pole










www.wago.com/2020-113/135-000

Item no.: 2020-113/145-000
1-conductor female plug; Strain relief plate; 1.5 mm²; 13-pole

www.wago.com/2020-113/145-000



Item no.: 2020-114 1-conductor female plug; 1.5 mm ² ; 14-pole	www.wago.com/2020-114
Item no.: 2020-114/000-036 1-conductor female plug; 1.5 mm ² ; 14-pole	www.wago.com/2020-114/000-036
Item no.: 2020-114/000-037 1-conductor female plug; 1.5 mm ² ; 14-pole	www.wago.com/2020-114/000-037
Item no.: 2020-114/000-038 1-conductor female plug; 1.5 mm ² ; 14-pole	www.wago.com/2020-114/000-038
Item no.: 2020-114/000-039 1-conductor female plug; 1.5 mm ² ; 14-pole	www.wago.com/2020-114/000-039
Item no.: 2020-114/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 14-pole	www.wago.com/2020-114/125-000
Item no.: 2020-114/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 14-pole	www.wago.com/2020-114/135-000
Item no.: 2020-114/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 14-pole	www.wago.com/2020-114/145-000
Item no.: 2020-115 1-conductor female plug; 1.5 mm ² ; 15-pole	www.wago.com/2020-115
Item no.: 2020-115/000-036 1-conductor female plug; 1.5 mm ² ; 15-pole	www.wago.com/2020-115/000-036
Item no.: 2020-115/000-037 1-conductor female plug; 1.5 mm ² ; 15-pole	www.wago.com/2020-115/000-037
Item no.: 2020-115/000-038 1-conductor female plug; 1.5 mm ² ; 15-pole	www.wago.com/2020-115/000-038
Item no.: 2020-115/000-039 1-conductor female plug; 1.5 mm ² ; 15-pole	www.wago.com/2020-115/000-039
Item no.: 2020-115/125-000 1-conductor female plug; Locking lever; 1.5 mm ² ; 15-pole	www.wago.com/2020-115/125-000
Item no.: 2020-115/135-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 15-pole	www.wago.com/2020-115/135-000

	Item no.: 2020-115/145-000 1-conductor female plug; Strain relief plate; 1.5 mm ² ; 15-pole	www.wago.com/2020-115/145-000
	Item no.: 2020-202 2-conductor female connector; 1.5 mm ² ; 2-pole	www.wago.com/2020-202
	Item no.: 2020-202/122-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 2-pole	www.wago.com/2020-202/122-000
	Item no.: 2020-202/132-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 2-pole	www.wago.com/2020-202/132-000
	Item no.: 2020-202/142-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 2-pole	www.wago.com/2020-202/142-000
	Item no.: 2020-203 2-conductor female connector; 1.5 mm ² ; 3-pole	www.wago.com/2020-203
	Item no.: 2020-203/000-036 2-conductor female connector; 1.5 mm ² ; 3-pole	www.wago.com/2020-203/000-036
	Item no.: 2020-203/000-037 2-conductor female connector; 1.5 mm ² ; 3-pole	www.wago.com/2020-203/000-037
	Item no.: 2020-203/000-038 2-conductor female connector; 1.5 mm ² ; 3-pole	www.wago.com/2020-203/000-038
	Item no.: 2020-203/000-039 2-conductor female connector; 1.5 mm ² ; 3-pole	www.wago.com/2020-203/000-039
	Item no.: 2020-203/122-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 3-pole	www.wago.com/2020-203/122-000
	Item no.: 2020-203/132-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 3-pole	www.wago.com/2020-203/132-000
	Item no.: 2020-203/142-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 3-pole	www.wago.com/2020-203/142-000
	Item no.: 2020-204 2-conductor female connector; 1.5 mm ² ; 4-pole	www.wago.com/2020-204
	Item no.: 2020-204/000-036 2-conductor female connector; 1.5 mm ² ; 4-pole	www.wago.com/2020-204/000-036
	Item no.: 2020-204/000-037 2-conductor female connector; 1.5 mm ² ; 4-pole	www.wago.com/2020-204/000-037



Item no.: 2020-204/000-038
2-conductor female connector; 1.5 mm²; 4-pole

www.wago.com/2020-204/000-038

Item no.: 2020-204/000-039
2-conductor female connector; 1.5 mm²; 4-pole

www.wago.com/2020-204/000-039

Item no.: 2020-204/124-000
2-conductor female connector; Locking lever; 1.5 mm²; 4-pole

www.wago.com/2020-204/124-000

Item no.: 2020-204/133-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 4-pole

www.wago.com/2020-204/133-000

Item no.: 2020-204/143-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 4-pole

www.wago.com/2020-204/143-000

Item no.: 2020-205
2-conductor female connector; 1.5 mm²; 5-pole

www.wago.com/2020-205

Item no.: 2020-205/000-036
2-conductor female connector; 1.5 mm²; 5-pole

www.wago.com/2020-205/000-036

Item no.: 2020-205/000-037
2-conductor female connector; 1.5 mm²; 5-pole

www.wago.com/2020-205/000-037

Item no.: 2020-205/000-038
2-conductor female connector; 1.5 mm²; 5-pole

www.wago.com/2020-205/000-038

Item no.: 2020-205/000-039
2-conductor female connector; 1.5 mm²; 5-pole

www.wago.com/2020-205/000-039

Item no.: 2020-205/124-000
2-conductor female connector; Locking lever; 1.5 mm²; 5-pole

www.wago.com/2020-205/124-000

Item no.: 2020-205/133-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 5-pole

www.wago.com/2020-205/133-000

Item no.: 2020-205/143-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 5-pole

www.wago.com/2020-205/143-000

Item no.: 2020-206
2-conductor female connector; 1.5 mm²; 6-pole

www.wago.com/2020-206



Item no.: 2020-206/000-036
2-conductor female connector; 1.5 mm²; 6-pole

www.wago.com/2020-206/000-036



Item no.: 2020-206/000-037
2-conductor female connector; 1.5 mm²; 6-pole

www.wago.com/2020-206/000-037



Item no.: 2020-206/000-038
2-conductor female connector; 1.5 mm²; 6-pole

www.wago.com/2020-206/000-038



Item no.: 2020-206/000-039
2-conductor female connector; 1.5 mm²; 6-pole

www.wago.com/2020-206/000-039

Item no.: 2020-206/124-000
2-conductor female connector; Locking lever; 1.5 mm²; 6-pole

www.wago.com/2020-206/124-000

Item no.: 2020-206/133-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 6-pole

www.wago.com/2020-206/133-000



Item no.: 2020-206/143-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 6-pole

www.wago.com/2020-206/143-000

Item no.: 2020-207
2-conductor female connector; 1.5 mm²; 7-pole

www.wago.com/2020-207



Item no.: 2020-207/000-036
2-conductor female connector; 1.5 mm²; 7-pole

www.wago.com/2020-207/000-036



Item no.: 2020-207/000-037
2-conductor female connector; 1.5 mm²; 7-pole

www.wago.com/2020-207/000-037



Item no.: 2020-207/000-038
2-conductor female connector; 1.5 mm²; 7-pole

www.wago.com/2020-207/000-038



Item no.: 2020-207/000-039
2-conductor female connector; 1.5 mm²; 7-pole

www.wago.com/2020-207/000-039

Item no.: 2020-207/124-000
2-conductor female connector; Locking lever; 1.5 mm²; 7-pole

www.wago.com/2020-207/124-000





 
Item no.: 2020-207/134-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 7-pole

www.wago.com/2020-207/134-000



Item no.: 2020-207/144-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 7-pole

www.wago.com/2020-207/144-000

	Item no.: 2020-208 2-conductor female connector; 1.5 mm ² ; 8-pole	www.wago.com/2020-208
	Item no.: 2020-208/000-036 2-conductor female connector; 1.5 mm ² ; 8-pole	www.wago.com/2020-208/000-036
	Item no.: 2020-208/000-037 2-conductor female connector; 1.5 mm ² ; 8-pole	www.wago.com/2020-208/000-037
	Item no.: 2020-208/000-038 2-conductor female connector; 1.5 mm ² ; 8-pole	www.wago.com/2020-208/000-038
	Item no.: 2020-208/000-039 2-conductor female connector; 1.5 mm ² ; 8-pole	www.wago.com/2020-208/000-039
	Item no.: 2020-208/124-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 8-pole	www.wago.com/2020-208/124-000
	Item no.: 2020-208/134-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 8-pole	www.wago.com/2020-208/134-000
	Item no.: 2020-208/144-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 8-pole	www.wago.com/2020-208/144-000
	Item no.: 2020-209 2-conductor female connector; 1.5 mm ² ; 9-pole	www.wago.com/2020-209
	Item no.: 2020-209/000-036 2-conductor female connector; 1.5 mm ² ; 9-pole	www.wago.com/2020-209/000-036
	Item no.: 2020-209/000-037 2-conductor female connector; 1.5 mm ² ; 9-pole	www.wago.com/2020-209/000-037
	Item no.: 2020-209/000-038 2-conductor female connector; 1.5 mm ² ; 9-pole	www.wago.com/2020-209/000-038
	Item no.: 2020-209/000-039 2-conductor female connector; 1.5 mm ² ; 9-pole	www.wago.com/2020-209/000-039
	Item no.: 2020-209/124-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 9-pole	www.wago.com/2020-209/124-000
	Item no.: 2020-209/134-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 9-pole	www.wago.com/2020-209/134-000



Item no.: 2020-209/144-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 9-pole

www.wago.com/2020-209/144-000

Item no.: 2020-210
2-conductor female connector; 1.5 mm²; 10-pole

www.wago.com/2020-210

Item no.: 2020-210/000-036
2-conductor female connector; 1.5 mm²; 10-pole

www.wago.com/2020-210/000-036

Item no.: 2020-210/000-037
2-conductor female connector; 1.5 mm²; 10-pole

www.wago.com/2020-210/000-037

Item no.: 2020-210/000-038
2-conductor female connector; 1.5 mm²; 10-pole

www.wago.com/2020-210/000-038

Item no.: 2020-210/000-039
2-conductor female connector; 1.5 mm²; 10-pole

www.wago.com/2020-210/000-039

Item no.: 2020-210/125-000
2-conductor female connector; Locking lever; 1.5 mm²; 10-pole

www.wago.com/2020-210/125-000

Item no.: 2020-210/135-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 10-pole

www.wago.com/2020-210/135-000



Item no.: 2020-210/145-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 10-pole

www.wago.com/2020-210/145-000

Item no.: 2020-211
2-conductor female connector; 1.5 mm²; 11-pole

www.wago.com/2020-211

Item no.: 2020-211/000-036
2-conductor female connector; 1.5 mm²; 11-pole

www.wago.com/2020-211/000-036

Item no.: 2020-211/000-037
2-conductor female connector; 1.5 mm²; 11-pole

www.wago.com/2020-211/000-037

Item no.: 2020-211/000-038
2-conductor female connector; 1.5 mm²; 11-pole







www.wago.com/2020-211/000-038



Item no.: 2020-211/000-039
2-conductor female connector; 1.5 mm²; 11-pole

www.wago.com/2020-211/000-039

Item no.: 2020-211/125-000
2-conductor female connector; Locking lever; 1.5 mm²; 11-pole

www.wago.com/2020-211/125-000

	<p>Item no.: 2020-211/135-000 2-conductor female connector; Strain relief plate; 1.5 mm²; 11-pole</p>	<p>www.wago.com/2020-211/135-000</p>
	<p>Item no.: 2020-211/145-000 2-conductor female connector; Strain relief plate; 1.5 mm²; 11-pole</p>	<p>www.wago.com/2020-211/145-000</p>
	<p>Item no.: 2020-212 2-conductor female connector; 1.5 mm²; 12-pole</p>	<p>www.wago.com/2020-212</p>
	<p>Item no.: 2020-212/000-036 2-conductor female connector; 1.5 mm²; 12-pole</p>	<p>www.wago.com/2020-212/000-036</p>
	<p>Item no.: 2020-212/000-037 2-conductor female connector; 1.5 mm²; 12-pole</p>	<p>www.wago.com/2020-212/000-037</p>
	<p>Item no.: 2020-212/000-038 2-conductor female connector; 1.5 mm²; 12-pole</p>	<p>www.wago.com/2020-212/000-038</p>
	<p>Item no.: 2020-212/000-039 2-conductor female connector; 1.5 mm²; 12-pole</p>	<p>www.wago.com/2020-212/000-039</p>
	<p>Item no.: 2020-212/125-000 2-conductor female connector; Locking lever; 1.5 mm²; 12-pole</p>	<p>www.wago.com/2020-212/125-000</p>
	<p>Item no.: 2020-212/135-000 2-conductor female connector; Strain relief plate; 1.5 mm²; 12-pole</p>	<p>www.wago.com/2020-212/135-000</p>
	<p>Item no.: 2020-212/145-000 2-conductor female connector; Strain relief plate; 1.5 mm²; 12-pole</p>	<p>www.wago.com/2020-212/145-000</p>
	<p>Item no.: 2020-213 2-conductor female connector; 1.5 mm²; 13-pole</p>	<p>www.wago.com/2020-213</p>
	<p>Item no.: 2020-213/000-036 2-conductor female connector; 1.5 mm²; 13-pole</p>	<p>www.wago.com/2020-213/000-036</p>
	<p>Item no.: 2020-213/000-037 2-conductor female connector; 1.5 mm²; 13-pole</p>	<p>www.wago.com/2020-213/000-037</p>
	<p>Item no.: 2020-213/000-038 2-conductor female connector; 1.5 mm²; 13-pole</p>	<p>www.wago.com/2020-213/000-038</p>
	<p>Item no.: 2020-213/000-039 2-conductor female connector; 1.5 mm²; 13-pole</p>	<p>www.wago.com/2020-213/000-039</p>

	Item no.: 2020-213/125-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 13-pole	www.wago.com/2020-213/125-000
	Item no.: 2020-213/135-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 13-pole	www.wago.com/2020-213/135-000
	Item no.: 2020-213/145-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 13-pole	www.wago.com/2020-213/145-000
	Item no.: 2020-214 2-conductor female connector; 1.5 mm ² ; 14-pole	www.wago.com/2020-214
	Item no.: 2020-214/000-036 2-conductor female connector; 1.5 mm ² ; 14-pole	www.wago.com/2020-214/000-036
	Item no.: 2020-214/000-037 2-conductor female connector; 1.5 mm ² ; 14-pole	www.wago.com/2020-214/000-037
	Item no.: 2020-214/000-038 2-conductor female connector; 1.5 mm ² ; 14-pole	www.wago.com/2020-214/000-038
	Item no.: 2020-214/000-039 2-conductor female connector; 1.5 mm ² ; 14-pole	www.wago.com/2020-214/000-039
	Item no.: 2020-214/125-000 2-conductor female connector; Locking lever; 1.5 mm ² ; 14-pole	www.wago.com/2020-214/125-000
	Item no.: 2020-214/135-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 14-pole	www.wago.com/2020-214/135-000
	Item no.: 2020-214/145-000 2-conductor female connector; Strain relief plate; 1.5 mm ² ; 14-pole	www.wago.com/2020-214/145-000
	Item no.: 2020-215 2-conductor female connector; 1.5 mm ² ; 15-pole	www.wago.com/2020-215
	Item no.: 2020-215/000-036 2-conductor female connector; 1.5 mm ² ; 15-pole	www.wago.com/2020-215/000-036
	Item no.: 2020-215/000-037 2-conductor female connector; 1.5 mm ² ; 15-pole	www.wago.com/2020-215/000-037
	Item no.: 2020-215/000-038 2-conductor female connector; 1.5 mm ² ; 15-pole	www.wago.com/2020-215/000-038

Item no.: 2020-215/000-039
2-conductor female connector; 1.5 mm²; 15-pole www.wago.com/2020-215/000-039

Item no.: 2020-215/125-000
2-conductor female connector; Locking lever; 1.5 mm²; 15-pole www.wago.com/2020-215/125-000

Item no.: 2020-215/135-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 15-pole www.wago.com/2020-215/135-000



Item no.: 2020-215/145-000
2-conductor female connector; Strain relief plate; 1.5 mm²; 15-pole www.wago.com/2020-215/145-000

General accessories



Item no.: 2020-161
Start module for 1-conductor female connector; with integrated end plate; 1.5 mm²; 1-pole www.wago.com/2020-161



Item no.: 2020-164
Start module for 1-conductor female connector; with integrated end plate; 1.5 mm²; 1-pole www.wago.com/2020-164



Item no.: 2020-167
Start module for 1-conductor female connector; 1.5 mm²; 1-pole www.wago.com/2020-167



Item no.: 2020-181
End module for 1-conductor female connector; 1.5 mm²; 1-pole www.wago.com/2020-181



Item no.: 2020-184
End module for 1-conductor female connector; 1.5 mm²; 1-pole www.wago.com/2020-184



Item no.: 2020-187
End module for 1-conductor female connector; 1.5 mm²; 1-pole www.wago.com/2020-187



Item no.: 2020-261
Start module for 2-conductor female connector; with integrated end plate; 1.5 mm²; 1-pole www.wago.com/2020-261



Item no.: 2020-264
Start module for 2-conductor female connector; with integrated end plate; 1.5 mm²; 1-pole www.wago.com/2020-264



Item no.: 2020-267
Start module for 2-conductor female connector; 1.5 mm²; 1-pole www.wago.com/2020-267



Item no.: 2020-281
End module for 2-conductor female connector; 1.5 mm²; 1-pole www.wago.com/2020-281



Item no.: 2020-284
End module for 2-conductor female connector; 1.5 mm²; 1-pole www.wago.com/2020-284






Item no.: 2020-287
End module for 2-conductor female connector; 1.5 mm²; 1-pole www.wago.com/2020-287

Coding





 





 



















Item no.: 2020-100
Carrier with 6 coding pins; for coding of female plugs; for carrier terminal blocks www.wago.com/2020-100















 


tools

	Item no.: 210-647 Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short	www.wago.com/210-647
	Item no.: 210-648 Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short; angled	www.wago.com/210-648
	Item no.: 210-719 Operating tool with partially insulated shaft; Type 1, blade (2.5 x 0.4) mm	www.wago.com/210-719

Jumper
















	Item no.: 2000-402 Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	www.wago.com/2000-402
	Item no.: 2000-402/000-005 Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	www.wago.com/2000-402/000-005
	Item no.: 2000-402/000-006 Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	www.wago.com/2000-402/000-006
	Item no.: 2000-402/000-018 Push-in type jumper bar; insulated; 2-way; Nominal current 14 A	www.wago.com/2000-402/000-018
	Item no.: 2000-403 Push-in type jumper bar; insulated; 3-way; Nominal current 14 A	www.wago.com/2000-403
	Item no.: 2000-403/000-005 Push-in type jumper bar; insulated; 3-way; Nominal current 14 A	www.wago.com/2000-403/000-005
	Item no.: 2000-403/000-006 Push-in type jumper bar; insulated; 3-way; Nominal current 14 A	www.wago.com/2000-403/000-006
	Item no.: 2000-404 Push-in type jumper bar; insulated; 4-way; Nominal current 14 A	www.wago.com/2000-404
	Item no.: 2000-404/000-005 Push-in type jumper bar; insulated; 4-way; Nominal current 14 A	www.wago.com/2000-404/000-005
	Item no.: 2000-404/000-006 Push-in type jumper bar; insulated; 4-way; Nominal current 14 A	www.wago.com/2000-404/000-006
	Item no.: 2000-405 Push-in type jumper bar; insulated; 5-way; Nominal current 14 A	www.wago.com/2000-405
	Item no.: 2000-405/000-005 Push-in type jumper bar; insulated; 5-way; Nominal current 14 A	www.wago.com/2000-405/000-005

	Item no.: 2000-405/000-006 Push-in type jumper bar; insulated; 5-way; Nominal current 14 A	www.wago.com/2000-405/000-006
	Item no.: 2000-405/011-000 Star point jumper; insulated; 3-way (1-3-5); IN = IN terminal block	www.wago.com/2000-405/011-000
	Item no.: 2000-406 Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	www.wago.com/2000-406
	Item no.: 2000-406/000-005 Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	www.wago.com/2000-406/000-005
	Item no.: 2000-406/000-006 Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	www.wago.com/2000-406/000-006
	Item no.: 2000-406/020-000 Delta jumper; insulated; 1-2 3-4 5-6; IN = IN terminal block	www.wago.com/2000-406/020-000
	Item no.: 2000-407 Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	www.wago.com/2000-407
	Item no.: 2000-407/000-005 Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	www.wago.com/2000-407/000-005
	Item no.: 2000-407/000-006 Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	www.wago.com/2000-407/000-006
	Item no.: 2000-408 Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	www.wago.com/2000-408
	Item no.: 2000-408/000-005 Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	www.wago.com/2000-408/000-005
	Item no.: 2000-408/000-006 Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	www.wago.com/2000-408/000-006
	Item no.: 2000-409 Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	www.wago.com/2000-409
	Item no.: 2000-409/000-005 Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	www.wago.com/2000-409/000-005
	Item no.: 2000-409/000-006 Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	www.wago.com/2000-409/000-006
	Item no.: 2000-410 Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	www.wago.com/2000-410


 



 


	Item no.: 2000-410/000-005 Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	www.wago.com/2000-410/000-005
	Item no.: 2000-410/000-006 Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	www.wago.com/2000-410/000-006
	Item no.: 2000-433 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	www.wago.com/2000-433
	Item no.: 2000-433/000-005 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	www.wago.com/2000-433/000-005
	Item no.: 2000-433/000-006 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	www.wago.com/2000-433/000-006
	Item no.: 2000-434 Push-in type jumper bar; insulated; from 1 to 4; Nominal current 14 A	www.wago.com/2000-434
	Item no.: 2000-435 Push-in type jumper bar; insulated; from 1 to 5; Nominal current 14 A	www.wago.com/2000-435
	Item no.: 2000-436 Push-in type jumper bar; insulated; from 1 to 6; Nominal current 14 A	www.wago.com/2000-436
	Item no.: 2000-437 Push-in type jumper bar; insulated; from 1 to 7; Nominal current 14 A	www.wago.com/2000-437
	Item no.: 2000-438 Push-in type jumper bar; insulated; from 1 to 8; Nominal current 14 A	www.wago.com/2000-438
	Item no.: 2000-439 Push-in type jumper bar; insulated; from 1 to 9; Nominal current 14 A	www.wago.com/2000-439
	Item no.: 2000-440 Push-in type jumper bar; insulated; from 1 to 10; Nominal current 14 A	www.wago.com/2000-440
	Item no.: 2009-402 Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm ² ; suitable for 2000 and 2020 Series rail-mounted terminal blocks	www.wago.com/2009-402
	Item no.: 2009-404 Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm ² ; suitable for 2000 and 2020 Series rail-mounted terminal blocks	www.wago.com/2009-404
	Item no.: 2009-406 Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm ² ; suitable for 2000 and 2020 Series rail-mounted terminal blocks	www.wago.com/2009-406
	Item no.: 210-103 Wire commoning chain; insulated; 50 connections	www.wago.com/210-103
	Item no.: 210-123 Wire commoning chain; insulated; 50 connections	www.wago.com/210-123

check

Item no.: 2009-174

	Test plug adapter; for 4 mm Ø test plugs; for testing TOPJOB®S rail-mounted terminal blocks	www.wago.com/2009-174
	Item no.: 2009-182 Testing tap; for max. 2.5 mm ² ; tool-free connection for individual test wires 0.08 - 2.5 mm	www.wago.com/2009-182
	Item no.: 859-500 Test pin; 1 mm Ø; with solder connection for test wire	www.wago.com/859-500
Protective Warning Marker		
	Item no.: 2000-115 Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks	www.wago.com/2000-115
Marking accessories		
	Item no.: 2009-110 Marking strips; on reel; not stretchable; plain; snap-on type	www.wago.com/2009-110
	Item no.: 2009-113 WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	www.wago.com/2009-113
	Item no.: 2009-113/000-002 WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	www.wago.com/2009-113/000-002
	Item no.: 2009-113/000-005 WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	www.wago.com/2009-113/000-005
	Item no.: 2009-113/000-006 WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	www.wago.com/2009-113/000-006
	Item no.: 2009-113/000-007 WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	www.wago.com/2009-113/000-007
	Item no.: 2009-113/000-012 WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	www.wago.com/2009-113/000-012
	Item no.: 2009-113/000-017 WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	www.wago.com/2009-113/000-017
	Item no.: 2009-113/000-023 WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	www.wago.com/2009-113/000-023
	Item no.: 2009-113/000-024 WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	www.wago.com/2009-113/000-024
	Item no.: 793-3501 WMB marking card; as card; plain; snap-on type	www.wago.com/793-3501




Carrier rail

	Item no.: 210-112 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm	www.wago.com/210-112
	Item no.: 210-113 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715	www.wago.com/210-113
	Item no.: 210-114 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715	www.wago.com/210-114
	Item no.: 210-115 Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm	www.wago.com/210-115
	Item no.: 210-118 Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	www.wago.com/210-118
	Item no.: 210-196 Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715	www.wago.com/210-196
	Item no.: 210-197 Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715	www.wago.com/210-197
	Item no.: 210-198 Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	www.wago.com/210-198

End plate

	Item no.: 2020-1391 End and intermediate plate	www.wago.com/2020-1391
	Item no.: 2020-1392 End and intermediate plate	www.wago.com/2020-1392

ferrule

	Item no.: 216-241 Ferrule; Sleeve for 0.5 mm ² / AWG 22; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-241
	Item no.: 216-242 Ferrule; Sleeve for 0.75 mm ² / AWG 20; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-242
	Item no.: 216-243 Ferrule; Sleeve for 1 mm ² / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	www.wago.com/216-243

Downloads

Documentation

Bid Text

2020-1304	14-Aug-2018	DOCX 15.5 kB	Download
-----------	-------------	-----------------	----------



smartDATA

CAD data

3D Download 2020-1304

URL

Download

Product family

X-COM S-Mini

[Show all products from the family](#)

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.