


## Data sheet | Item number: 2020-1307

2-conductor/1-pin ground carrier terminal block; for DIN-rail 35 x 15 and 35 x 7.5; Push-in CAGE CLAMP®

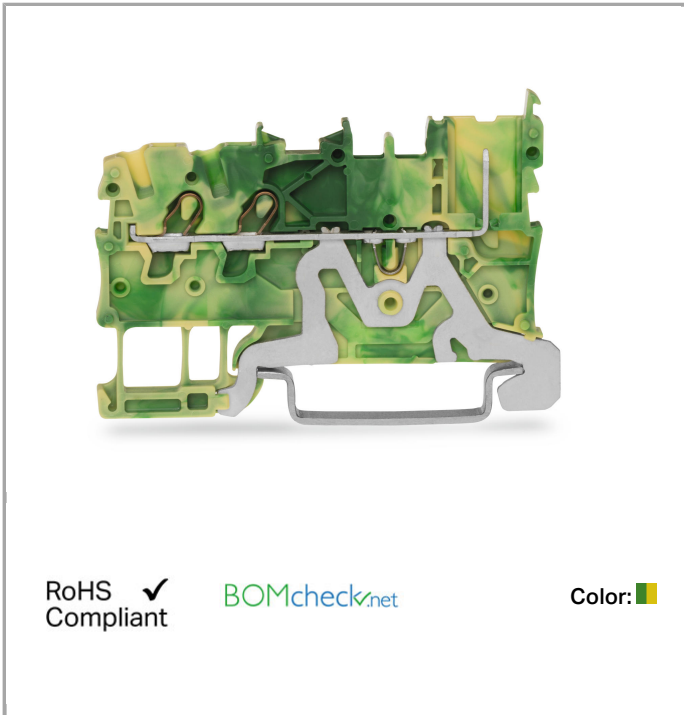

[www.wago.com/2020-1307](http://www.wago.com/2020-1307)



RoHS  Compliant

BOMcheck.net

Color: ■

### Data

#### Connection data

Connection technology	Push-in CAGE CLAMP®
Number of connection points (connection type)	2
Actuation type	Open Tool Slot Push-in
Connectable conductor materials	Copper
Nominal cross section	1 mm <sup>2</sup>
Solid conductor	0.14 ... 1.5 mm <sup>2</sup> / 24 ... 16 AWG
Solid conductor, push-in termination	0.5 ... 1.5 mm <sup>2</sup> / 20 ... 16 AWG
Fine-stranded conductor	0.14 ... 1.5 mm <sup>2</sup> / 24 ... 16 AWG
Fine-stranded conductor with ferrule, push-in termination, from	0.5 mm <sup>2</sup> / 20 AWG
Strip length	9 ... 11 mm / 0.35 ... 0.43 Inch
Number of connection points	1
Total number of connection points	2
Total number of potentials	1
Number of levels	1
Type of wiring	Front-entry wiring

## Geometrical Data

Width	3.5 mm / 0.138 inch
Height from upper-edge of DIN-35 rail	32.5 mm / 1.28 inch
Depth	60.5 mm / 2.382 inch

## Mechanical data

Design	horizontal
Type of mounting	DIN-35 rail
Marking level	Center/side marking

## Material Data




Color	green-yellow
Insulating material	Polyamide 66 (PA 66)
Weight	6.57 g

## Commercial data


Packaging type	BOX
Country of origin	DE
GTIN	4055143288118
Customs Tariff No.	85366990990

## Approvals / Certificates

### Country specific Approvals

Logo	Approval	Certificate name
	CCA	NTR NL 7617
	CSA DEKRA Certification B.V.	2516073
	KEMA/KEUR DEKRA Certification B.V.	71-100670

### UL-Approvals

Logo	Approval	Certificate name
	UL UL International Germany GmbH	E45172






UL  
Underwriters Laboratories Inc.






 


E45172

## Compatible products




### tools









	<b>Item no.: 210-647</b> Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short	<a href="http://www.wago.com/210-647">www.wago.com/210-647</a>
	<b>Item no.: 210-648</b> Operating tool with partially insulated shaft; Blade (2.5 x 0.4) mm; short; angled	<a href="http://www.wago.com/210-648">www.wago.com/210-648</a>
	<b>Item no.: 210-719</b> Operating tool with partially insulated shaft; Type 1, blade (2.5 x 0.4) mm	<a href="http://www.wago.com/210-719">www.wago.com/210-719</a>

### Carrier rail

	<b>Item no.: 210-112</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 25 mm	<a href="http://www.wago.com/210-112">www.wago.com/210-112</a>
	<b>Item no.: 210-113</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; unslotted; according to EN 60715	<a href="http://www.wago.com/210-113">www.wago.com/210-113</a>
	<b>Item no.: 210-114</b> Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715	<a href="http://www.wago.com/210-114">www.wago.com/210-114</a>
	<b>Item no.: 210-115</b> Steel carrier rail; 35 x 7.5 mm; 1 mm thick; 2 m long; slotted; according to EN 60715; "Hole width 18 mm	<a href="http://www.wago.com/210-115">www.wago.com/210-115</a>
	<b>Item no.: 210-118</b> Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	<a href="http://www.wago.com/210-118">www.wago.com/210-118</a>
	<b>Item no.: 210-196</b> Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715	<a href="http://www.wago.com/210-196">www.wago.com/210-196</a>
	<b>Item no.: 210-197</b> Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715	<a href="http://www.wago.com/210-197">www.wago.com/210-197</a>
	<b>Item no.: 210-198</b> Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715	<a href="http://www.wago.com/210-198">www.wago.com/210-198</a>

### Marking accessories


	<b>Item no.: 2009-110</b> Marking strips; on reel; not stretchable; plain; snap-on type	<a href="http://www.wago.com/2009-110">www.wago.com/2009-110</a>
	<b>Item no.: 2009-113</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113">www.wago.com/2009-113</a>
	<b>Item no.: 2009-113/000-002</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type	<a href="http://www.wago.com/2009-113/000-002">www.wago.com/2009-113/000-002</a>










	<p><b>Item no.: 2009-113/000-005</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type</p>	<a href="http://www.wago.com/2009-113/000-005">www.wago.com/2009-113/000-005</a>
	<p><b>Item no.: 2009-113/000-006</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type</p>	<a href="http://www.wago.com/2009-113/000-006">www.wago.com/2009-113/000-006</a>
	<p><b>Item no.: 2009-113/000-007</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type</p>	<a href="http://www.wago.com/2009-113/000-007">www.wago.com/2009-113/000-007</a>
	<p><b>Item no.: 2009-113/000-012</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type</p>	<a href="http://www.wago.com/2009-113/000-012">www.wago.com/2009-113/000-012</a>
	<p><b>Item no.: 2009-113/000-017</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type</p>	<a href="http://www.wago.com/2009-113/000-017">www.wago.com/2009-113/000-017</a>
	<p><b>Item no.: 2009-113/000-023</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type</p>	<a href="http://www.wago.com/2009-113/000-023">www.wago.com/2009-113/000-023</a>
	<p><b>Item no.: 2009-113/000-024</b> WMB-Inline; for smartPRINTER; on reel; plain; snap-on type</p>	<a href="http://www.wago.com/2009-113/000-024">www.wago.com/2009-113/000-024</a>
	<p><b>Item no.: 793-3501</b> WMB marking card; as card; plain; snap-on type</p>	<a href="http://www.wago.com/793-3501">www.wago.com/793-3501</a>











 
**End plate**





	<p><b>Item no.: 2020-1391</b> End and intermediate plate</p>	<a href="http://www.wago.com/2020-1391">www.wago.com/2020-1391</a>
	<p><b>Item no.: 2020-1392</b> End and intermediate plate</p>	<a href="http://www.wago.com/2020-1392">www.wago.com/2020-1392</a>





**Female plug**

	<p><b>Item no.: 2020-102</b> 1-conductor female plug; 1.5 mm<sup>2</sup>; 2-pole</p>	<a href="http://www.wago.com/2020-102">www.wago.com/2020-102</a>
	<p><b>Item no.: 2020-102/122-000</b> 1-conductor female plug; Locking lever; 1.5 mm<sup>2</sup>; 2-pole</p>	<a href="http://www.wago.com/2020-102/122-000">www.wago.com/2020-102/122-000</a>
	<p><b>Item no.: 2020-102/132-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 2-pole</p>	<a href="http://www.wago.com/2020-102/132-000">www.wago.com/2020-102/132-000</a>
	<p><b>Item no.: 2020-102/142-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 2-pole</p>	<a href="http://www.wago.com/2020-102/142-000">www.wago.com/2020-102/142-000</a>



	<b>Item no.: 2020-103</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103">www.wago.com/2020-103</a>
	<b>Item no.: 2020-103/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/000-036">www.wago.com/2020-103/000-036</a>
	<b>Item no.: 2020-103/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/000-037">www.wago.com/2020-103/000-037</a>
	<b>Item no.: 2020-103/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/000-038">www.wago.com/2020-103/000-038</a>
	<b>Item no.: 2020-103/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/000-039">www.wago.com/2020-103/000-039</a>
	<b>Item no.: 2020-103/122-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/122-000">www.wago.com/2020-103/122-000</a>
	<b>Item no.: 2020-103/132-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/132-000">www.wago.com/2020-103/132-000</a>
	<b>Item no.: 2020-103/142-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-103/142-000">www.wago.com/2020-103/142-000</a>
	<b>Item no.: 2020-104</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104">www.wago.com/2020-104</a>
	<b>Item no.: 2020-104/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/000-036">www.wago.com/2020-104/000-036</a>
	<b>Item no.: 2020-104/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/000-037">www.wago.com/2020-104/000-037</a>
	<b>Item no.: 2020-104/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/000-038">www.wago.com/2020-104/000-038</a>
	<b>Item no.: 2020-104/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/000-039">www.wago.com/2020-104/000-039</a>
	<b>Item no.: 2020-104/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/124-000">www.wago.com/2020-104/124-000</a>
	<b>Item no.: 2020-104/133-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/133-000">www.wago.com/2020-104/133-000</a>

	<b>Item no.: 2020-104/143-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-104/143-000">www.wago.com/2020-104/143-000</a>
	<b>Item no.: 2020-105</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105">www.wago.com/2020-105</a>
	<b>Item no.: 2020-105/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/000-036">www.wago.com/2020-105/000-036</a>
	<b>Item no.: 2020-105/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/000-037">www.wago.com/2020-105/000-037</a>
	<b>Item no.: 2020-105/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/000-038">www.wago.com/2020-105/000-038</a>
	<b>Item no.: 2020-105/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/000-039">www.wago.com/2020-105/000-039</a>
	<b>Item no.: 2020-105/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/124-000">www.wago.com/2020-105/124-000</a>
	<b>Item no.: 2020-105/133-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/133-000">www.wago.com/2020-105/133-000</a>
	<b>Item no.: 2020-105/143-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 5-pole	<a href="http://www.wago.com/2020-105/143-000">www.wago.com/2020-105/143-000</a>
	<b>Item no.: 2020-106</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106">www.wago.com/2020-106</a>
	<b>Item no.: 2020-106/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/000-036">www.wago.com/2020-106/000-036</a>
	<b>Item no.: 2020-106/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/000-037">www.wago.com/2020-106/000-037</a>
	<b>Item no.: 2020-106/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/000-038">www.wago.com/2020-106/000-038</a>
	<b>Item no.: 2020-106/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/000-039">www.wago.com/2020-106/000-039</a>
	<b>Item no.: 2020-106/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/124-000">www.wago.com/2020-106/124-000</a>

	<b>Item no.: 2020-106/133-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/133-000">www.wago.com/2020-106/133-000</a>
	<b>Item no.: 2020-106/143-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 6-pole	<a href="http://www.wago.com/2020-106/143-000">www.wago.com/2020-106/143-000</a>
	<b>Item no.: 2020-107</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107">www.wago.com/2020-107</a>
	<b>Item no.: 2020-107/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/000-036">www.wago.com/2020-107/000-036</a>
	<b>Item no.: 2020-107/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/000-037">www.wago.com/2020-107/000-037</a>
	<b>Item no.: 2020-107/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/000-038">www.wago.com/2020-107/000-038</a>
	<b>Item no.: 2020-107/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/000-039">www.wago.com/2020-107/000-039</a>
	<b>Item no.: 2020-107/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/124-000">www.wago.com/2020-107/124-000</a>
	<b>Item no.: 2020-107/134-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/134-000">www.wago.com/2020-107/134-000</a>
	<b>Item no.: 2020-107/144-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 7-pole	<a href="http://www.wago.com/2020-107/144-000">www.wago.com/2020-107/144-000</a>
	<b>Item no.: 2020-108</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108">www.wago.com/2020-108</a>
	<b>Item no.: 2020-108/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/000-036">www.wago.com/2020-108/000-036</a>
	<b>Item no.: 2020-108/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/000-037">www.wago.com/2020-108/000-037</a>
	<b>Item no.: 2020-108/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/000-038">www.wago.com/2020-108/000-038</a>
	<b>Item no.: 2020-108/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/000-039">www.wago.com/2020-108/000-039</a>

	<b>Item no.: 2020-108/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/124-000">www.wago.com/2020-108/124-000</a>
	<b>Item no.: 2020-108/134-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/134-000">www.wago.com/2020-108/134-000</a>
	<b>Item no.: 2020-108/144-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-108/144-000">www.wago.com/2020-108/144-000</a>
	<b>Item no.: 2020-109</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109">www.wago.com/2020-109</a>
	<b>Item no.: 2020-109/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/000-036">www.wago.com/2020-109/000-036</a>
	<b>Item no.: 2020-109/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/000-037">www.wago.com/2020-109/000-037</a>
	<b>Item no.: 2020-109/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/000-038">www.wago.com/2020-109/000-038</a>
	<b>Item no.: 2020-109/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/000-039">www.wago.com/2020-109/000-039</a>
	<b>Item no.: 2020-109/124-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/124-000">www.wago.com/2020-109/124-000</a>
	<b>Item no.: 2020-109/134-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/134-000">www.wago.com/2020-109/134-000</a>
	<b>Item no.: 2020-109/144-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-109/144-000">www.wago.com/2020-109/144-000</a>
	<b>Item no.: 2020-110</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-110">www.wago.com/2020-110</a>
	<b>Item no.: 2020-110/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-110/000-036">www.wago.com/2020-110/000-036</a>
	<b>Item no.: 2020-110/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-110/000-037">www.wago.com/2020-110/000-037</a>
	<b>Item no.: 2020-110/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-110/000-038">www.wago.com/2020-110/000-038</a>



<b>Item no.: 2020-110/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-110/000-039">www.wago.com/2020-110/000-039</a>	
<b>Item no.: 2020-110/125-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-110/125-000">www.wago.com/2020-110/125-000</a>	
<b>Item no.: 2020-110/135-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-110/135-000">www.wago.com/2020-110/135-000</a>	
<b>Item no.: 2020-110/145-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-110/145-000">www.wago.com/2020-110/145-000</a>	
<b>Item no.: 2020-111</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111">www.wago.com/2020-111</a>	
<b>Item no.: 2020-111/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/000-036">www.wago.com/2020-111/000-036</a>	
<b>Item no.: 2020-111/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/000-037">www.wago.com/2020-111/000-037</a>	
<b>Item no.: 2020-111/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/000-038">www.wago.com/2020-111/000-038</a>	
<b>Item no.: 2020-111/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/000-039">www.wago.com/2020-111/000-039</a>	
<b>Item no.: 2020-111/125-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/125-000">www.wago.com/2020-111/125-000</a>	
<b>Item no.: 2020-111/135-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/135-000">www.wago.com/2020-111/135-000</a>	
<b>Item no.: 2020-111/145-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-111/145-000">www.wago.com/2020-111/145-000</a>	
<b>Item no.: 2020-112</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112">www.wago.com/2020-112</a>	
	<b>Item no.: 2020-112/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112/000-036">www.wago.com/2020-112/000-036</a>
	<b>Item no.: 2020-112/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-112/000-037">www.wago.com/2020-112/000-037</a>



**Item no.: 2020-112/000-038**  
1-conductor female plug; 1.5 mm<sup>2</sup>; 12-pole

[www.wago.com/2020-112/000-038](http://www.wago.com/2020-112/000-038)



**Item no.: 2020-112/000-039**  
1-conductor female plug; 1.5 mm<sup>2</sup>; 12-pole

[www.wago.com/2020-112/000-039](http://www.wago.com/2020-112/000-039)

**Item no.: 2020-112/125-000**  
1-conductor female plug; Locking lever; 1.5 mm<sup>2</sup>; 12-pole

[www.wago.com/2020-112/125-000](http://www.wago.com/2020-112/125-000)

**Item no.: 2020-112/135-000**  
1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 12-pole

[www.wago.com/2020-112/135-000](http://www.wago.com/2020-112/135-000)

**Item no.: 2020-112/145-000**  
1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 12-pole

[www.wago.com/2020-112/145-000](http://www.wago.com/2020-112/145-000)

**Item no.: 2020-113**  
1-conductor female plug; 1.5 mm<sup>2</sup>; 13-pole

[www.wago.com/2020-113](http://www.wago.com/2020-113)

**Item no.: 2020-113/000-036**  
1-conductor female plug; 1.5 mm<sup>2</sup>; 13-pole

[www.wago.com/2020-113/000-036](http://www.wago.com/2020-113/000-036)

**Item no.: 2020-113/000-037**  
1-conductor female plug; 1.5 mm<sup>2</sup>; 13-pole

[www.wago.com/2020-113/000-037](http://www.wago.com/2020-113/000-037)

**Item no.: 2020-113/000-038**  
1-conductor female plug; 1.5 mm<sup>2</sup>; 13-pole

[www.wago.com/2020-113/000-038](http://www.wago.com/2020-113/000-038)

**Item no.: 2020-113/000-039**  
1-conductor female plug; 1.5 mm<sup>2</sup>; 13-pole

[www.wago.com/2020-113/000-039](http://www.wago.com/2020-113/000-039)

**Item no.: 2020-113/125-000**  
1-conductor female plug; Locking lever; 1.5 mm<sup>2</sup>; 13-pole

[www.wago.com/2020-113/125-000](http://www.wago.com/2020-113/125-000)

**Item no.: 2020-113/135-000**  
1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 13-pole

[www.wago.com/2020-113/135-000](http://www.wago.com/2020-113/135-000)

**Item no.: 2020-113/145-000**  
1-conductor female plug; Strain relief plate; 1.5 mm<sup>2</sup>; 13-pole

[www.wago.com/2020-113/145-000](http://www.wago.com/2020-113/145-000)











**Item no.: 2020-114**  
1-conductor female plug; 1.5 mm<sup>2</sup>; 14-pole

[www.wago.com/2020-114](http://www.wago.com/2020-114)

**Item no.: 2020-114/000-036**  
1-conductor female plug; 1.5 mm<sup>2</sup>; 14-pole

[www.wago.com/2020-114/000-036](http://www.wago.com/2020-114/000-036)

<b>Item no.: 2020-114/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-114/000-037">www.wago.com/2020-114/000-037</a>
<b>Item no.: 2020-114/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-114/000-038">www.wago.com/2020-114/000-038</a>
<b>Item no.: 2020-114/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-114/000-039">www.wago.com/2020-114/000-039</a>
<b>Item no.: 2020-114/125-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-114/125-000">www.wago.com/2020-114/125-000</a>
<b>Item no.: 2020-114/135-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-114/135-000">www.wago.com/2020-114/135-000</a>
<b>Item no.: 2020-114/145-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 14-pole	<a href="http://www.wago.com/2020-114/145-000">www.wago.com/2020-114/145-000</a>
<b>Item no.: 2020-115</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115">www.wago.com/2020-115</a>
<b>Item no.: 2020-115/000-036</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/000-036">www.wago.com/2020-115/000-036</a>
<b>Item no.: 2020-115/000-037</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/000-037">www.wago.com/2020-115/000-037</a>
<b>Item no.: 2020-115/000-038</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/000-038">www.wago.com/2020-115/000-038</a>
<b>Item no.: 2020-115/000-039</b> 1-conductor female plug; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/000-039">www.wago.com/2020-115/000-039</a>
<b>Item no.: 2020-115/125-000</b> 1-conductor female plug; Locking lever; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/125-000">www.wago.com/2020-115/125-000</a>
<b>Item no.: 2020-115/135-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/135-000">www.wago.com/2020-115/135-000</a>
<b>Item no.: 2020-115/145-000</b> 1-conductor female plug; Strain relief plate; 1.5 mm <sup>2</sup> ; 15-pole	<a href="http://www.wago.com/2020-115/145-000">www.wago.com/2020-115/145-000</a>
 <b>Item no.: 2020-202</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-202">www.wago.com/2020-202</a>

	<b>Item no.: 2020-202/122-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-202/122-000">www.wago.com/2020-202/122-000</a>
	<b>Item no.: 2020-202/132-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-202/132-000">www.wago.com/2020-202/132-000</a>
	<b>Item no.: 2020-202/142-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 2-pole	<a href="http://www.wago.com/2020-202/142-000">www.wago.com/2020-202/142-000</a>
	<b>Item no.: 2020-203</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203">www.wago.com/2020-203</a>
	<b>Item no.: 2020-203/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/000-036">www.wago.com/2020-203/000-036</a>
	<b>Item no.: 2020-203/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/000-037">www.wago.com/2020-203/000-037</a>
	<b>Item no.: 2020-203/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/000-038">www.wago.com/2020-203/000-038</a>
	<b>Item no.: 2020-203/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/000-039">www.wago.com/2020-203/000-039</a>
	<b>Item no.: 2020-203/122-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/122-000">www.wago.com/2020-203/122-000</a>
	<b>Item no.: 2020-203/132-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/132-000">www.wago.com/2020-203/132-000</a>
	<b>Item no.: 2020-203/142-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 3-pole	<a href="http://www.wago.com/2020-203/142-000">www.wago.com/2020-203/142-000</a>
	<b>Item no.: 2020-204</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204">www.wago.com/2020-204</a>
	<b>Item no.: 2020-204/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/000-036">www.wago.com/2020-204/000-036</a>
	<b>Item no.: 2020-204/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/000-037">www.wago.com/2020-204/000-037</a>
	<b>Item no.: 2020-204/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 4-pole	<a href="http://www.wago.com/2020-204/000-038">www.wago.com/2020-204/000-038</a>



**Item no.: 2020-204/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 4-pole

[www.wago.com/2020-204/000-039](http://www.wago.com/2020-204/000-039)

**Item no.: 2020-204/124-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 4-pole

[www.wago.com/2020-204/124-000](http://www.wago.com/2020-204/124-000)

**Item no.: 2020-204/133-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 4-pole

[www.wago.com/2020-204/133-000](http://www.wago.com/2020-204/133-000)



**Item no.: 2020-204/143-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 4-pole

[www.wago.com/2020-204/143-000](http://www.wago.com/2020-204/143-000)

**Item no.: 2020-205**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 5-pole

[www.wago.com/2020-205](http://www.wago.com/2020-205)



**Item no.: 2020-205/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 5-pole

[www.wago.com/2020-205/000-036](http://www.wago.com/2020-205/000-036)



**Item no.: 2020-205/000-037**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 5-pole

[www.wago.com/2020-205/000-037](http://www.wago.com/2020-205/000-037)



**Item no.: 2020-205/000-038**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 5-pole

[www.wago.com/2020-205/000-038](http://www.wago.com/2020-205/000-038)



**Item no.: 2020-205/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 5-pole

[www.wago.com/2020-205/000-039](http://www.wago.com/2020-205/000-039)



**Item no.: 2020-205/124-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 5-pole

[www.wago.com/2020-205/124-000](http://www.wago.com/2020-205/124-000)



**Item no.: 2020-205/133-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 5-pole

[www.wago.com/2020-205/133-000](http://www.wago.com/2020-205/133-000)



**Item no.: 2020-205/143-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 5-pole

[www.wago.com/2020-205/143-000](http://www.wago.com/2020-205/143-000)

**Item no.: 2020-206**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 6-pole

[www.wago.com/2020-206](http://www.wago.com/2020-206)



**Item no.: 2020-206/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 6-pole

[www.wago.com/2020-206/000-036](http://www.wago.com/2020-206/000-036)



**Item no.: 2020-206/000-037**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 6-pole

[www.wago.com/2020-206/000-037](http://www.wago.com/2020-206/000-037)



**Item no.: 2020-206/000-038**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 6-pole

[www.wago.com/2020-206/000-038](http://www.wago.com/2020-206/000-038)



**Item no.: 2020-206/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 6-pole

[www.wago.com/2020-206/000-039](http://www.wago.com/2020-206/000-039)

**Item no.: 2020-206/124-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 6-pole

[www.wago.com/2020-206/124-000](http://www.wago.com/2020-206/124-000)

**Item no.: 2020-206/133-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 6-pole

[www.wago.com/2020-206/133-000](http://www.wago.com/2020-206/133-000)



**Item no.: 2020-206/143-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 6-pole

[www.wago.com/2020-206/143-000](http://www.wago.com/2020-206/143-000)

**Item no.: 2020-207**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207](http://www.wago.com/2020-207)



**Item no.: 2020-207/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/000-036](http://www.wago.com/2020-207/000-036)



**Item no.: 2020-207/000-037**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/000-037](http://www.wago.com/2020-207/000-037)



**Item no.: 2020-207/000-038**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/000-038](http://www.wago.com/2020-207/000-038)



**Item no.: 2020-207/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/000-039](http://www.wago.com/2020-207/000-039)

**Item no.: 2020-207/124-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/124-000](http://www.wago.com/2020-207/124-000)

**Item no.: 2020-207/134-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 7-pole

[www.wago.com/2020-207/134-000](http://www.wago.com/2020-207/134-000)



**Item no.: 2020-207/144-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 7-pole





 

[www.wago.com/2020-207/144-000](http://www.wago.com/2020-207/144-000)



**Item no.: 2020-208**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208](http://www.wago.com/2020-208)






**Item no.: 2020-208/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 8-pole

[www.wago.com/2020-208/000-036](http://www.wago.com/2020-208/000-036)

	<b>Item no.: 2020-208/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-208/000-037">www.wago.com/2020-208/000-037</a>
	<b>Item no.: 2020-208/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-208/000-038">www.wago.com/2020-208/000-038</a>
	<b>Item no.: 2020-208/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-208/000-039">www.wago.com/2020-208/000-039</a>
	<b>Item no.: 2020-208/124-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-208/124-000">www.wago.com/2020-208/124-000</a>
	<b>Item no.: 2020-208/134-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-208/134-000">www.wago.com/2020-208/134-000</a>
	<b>Item no.: 2020-208/144-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 8-pole	<a href="http://www.wago.com/2020-208/144-000">www.wago.com/2020-208/144-000</a>
	<b>Item no.: 2020-209</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-209">www.wago.com/2020-209</a>
	<b>Item no.: 2020-209/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-209/000-036">www.wago.com/2020-209/000-036</a>
	<b>Item no.: 2020-209/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-209/000-037">www.wago.com/2020-209/000-037</a>
	<b>Item no.: 2020-209/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-209/000-038">www.wago.com/2020-209/000-038</a>
	<b>Item no.: 2020-209/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-209/000-039">www.wago.com/2020-209/000-039</a>
	<b>Item no.: 2020-209/124-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-209/124-000">www.wago.com/2020-209/124-000</a>
	<b>Item no.: 2020-209/134-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-209/134-000">www.wago.com/2020-209/134-000</a>
	<b>Item no.: 2020-209/144-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 9-pole	<a href="http://www.wago.com/2020-209/144-000">www.wago.com/2020-209/144-000</a>
	<b>Item no.: 2020-210</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-210">www.wago.com/2020-210</a>

<b>Item no.: 2020-210/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-210/000-036">www.wago.com/2020-210/000-036</a>	
<b>Item no.: 2020-210/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-210/000-037">www.wago.com/2020-210/000-037</a>	
<b>Item no.: 2020-210/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-210/000-038">www.wago.com/2020-210/000-038</a>	
<b>Item no.: 2020-210/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-210/000-039">www.wago.com/2020-210/000-039</a>	
<b>Item no.: 2020-210/125-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-210/125-000">www.wago.com/2020-210/125-000</a>	
<b>Item no.: 2020-210/135-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-210/135-000">www.wago.com/2020-210/135-000</a>	
	<b>Item no.: 2020-210/145-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 10-pole	<a href="http://www.wago.com/2020-210/145-000">www.wago.com/2020-210/145-000</a>
<b>Item no.: 2020-211</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211">www.wago.com/2020-211</a>	
<b>Item no.: 2020-211/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/000-036">www.wago.com/2020-211/000-036</a>	
<b>Item no.: 2020-211/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/000-037">www.wago.com/2020-211/000-037</a>	
<b>Item no.: 2020-211/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/000-038">www.wago.com/2020-211/000-038</a>	
<b>Item no.: 2020-211/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/000-039">www.wago.com/2020-211/000-039</a>	
<b>Item no.: 2020-211/125-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/125-000">www.wago.com/2020-211/125-000</a>	
<b>Item no.: 2020-211/135-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/135-000">www.wago.com/2020-211/135-000</a>	
	<b>Item no.: 2020-211/145-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 11-pole	<a href="http://www.wago.com/2020-211/145-000">www.wago.com/2020-211/145-000</a>



	<b>Item no.: 2020-212</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212">www.wago.com/2020-212</a>
	<b>Item no.: 2020-212/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/000-036">www.wago.com/2020-212/000-036</a>
	<b>Item no.: 2020-212/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/000-037">www.wago.com/2020-212/000-037</a>
	<b>Item no.: 2020-212/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/000-038">www.wago.com/2020-212/000-038</a>
	<b>Item no.: 2020-212/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/000-039">www.wago.com/2020-212/000-039</a>
	<b>Item no.: 2020-212/125-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/125-000">www.wago.com/2020-212/125-000</a>
	<b>Item no.: 2020-212/135-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/135-000">www.wago.com/2020-212/135-000</a>
	<b>Item no.: 2020-212/145-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 12-pole	<a href="http://www.wago.com/2020-212/145-000">www.wago.com/2020-212/145-000</a>
	<b>Item no.: 2020-213</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213">www.wago.com/2020-213</a>
	<b>Item no.: 2020-213/000-036</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/000-036">www.wago.com/2020-213/000-036</a>
	<b>Item no.: 2020-213/000-037</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/000-037">www.wago.com/2020-213/000-037</a>
	<b>Item no.: 2020-213/000-038</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/000-038">www.wago.com/2020-213/000-038</a>
	<b>Item no.: 2020-213/000-039</b> 2-conductor female connector; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/000-039">www.wago.com/2020-213/000-039</a>
	<b>Item no.: 2020-213/125-000</b> 2-conductor female connector; Locking lever; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/125-000">www.wago.com/2020-213/125-000</a>
	<b>Item no.: 2020-213/135-000</b> 2-conductor female connector; Strain relief plate; 1.5 mm <sup>2</sup> ; 13-pole	<a href="http://www.wago.com/2020-213/135-000">www.wago.com/2020-213/135-000</a>



**Item no.: 2020-213/145-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 13-pole [www.wago.com/2020-213/145-000](http://www.wago.com/2020-213/145-000)

**Item no.: 2020-214**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 14-pole [www.wago.com/2020-214](http://www.wago.com/2020-214)

**Item no.: 2020-214/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 14-pole [www.wago.com/2020-214/000-036](http://www.wago.com/2020-214/000-036)

**Item no.: 2020-214/000-037**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 14-pole [www.wago.com/2020-214/000-037](http://www.wago.com/2020-214/000-037)

**Item no.: 2020-214/000-038**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 14-pole [www.wago.com/2020-214/000-038](http://www.wago.com/2020-214/000-038)

**Item no.: 2020-214/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 14-pole [www.wago.com/2020-214/000-039](http://www.wago.com/2020-214/000-039)

**Item no.: 2020-214/125-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 14-pole [www.wago.com/2020-214/125-000](http://www.wago.com/2020-214/125-000)

**Item no.: 2020-214/135-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 14-pole [www.wago.com/2020-214/135-000](http://www.wago.com/2020-214/135-000)



**Item no.: 2020-214/145-000**  
2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 14-pole [www.wago.com/2020-214/145-000](http://www.wago.com/2020-214/145-000)

**Item no.: 2020-215**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 15-pole [www.wago.com/2020-215](http://www.wago.com/2020-215)

**Item no.: 2020-215/000-036**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 15-pole [www.wago.com/2020-215/000-036](http://www.wago.com/2020-215/000-036)

**Item no.: 2020-215/000-037**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 15-pole [www.wago.com/2020-215/000-037](http://www.wago.com/2020-215/000-037)

**Item no.: 2020-215/000-038**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 15-pole [www.wago.com/2020-215/000-038](http://www.wago.com/2020-215/000-038)

**Item no.: 2020-215/000-039**  
2-conductor female connector; 1.5 mm<sup>2</sup>; 15-pole [www.wago.com/2020-215/000-039](http://www.wago.com/2020-215/000-039)

**Item no.: 2020-215/125-000**  
2-conductor female connector; Locking lever; 1.5 mm<sup>2</sup>; 15-pole [www.wago.com/2020-215/125-000](http://www.wago.com/2020-215/125-000)

Item no.: 2020-215/135-000

2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 15-pole[www.wago.com/2020-215/135-000](http://www.wago.com/2020-215/135-000)

Item no.: 2020-215/145-000

2-conductor female connector; Strain relief plate; 1.5 mm<sup>2</sup>; 15-pole[www.wago.com/2020-215/145-000](http://www.wago.com/2020-215/145-000)

## Coding



Item no.: 2020-100

Carrier with 6 coding pins; for coding of female plugs; for carrier terminal blocks

[www.wago.com/2020-100](http://www.wago.com/2020-100)

## Jumper



Item no.: 2000-402

Push-in type jumper bar; insulated; 2-way; Nominal current 14 A

[www.wago.com/2000-402](http://www.wago.com/2000-402)

Item no.: 2000-402/000-005

Push-in type jumper bar; insulated; 2-way; Nominal current 14 A

[www.wago.com/2000-402/000-005](http://www.wago.com/2000-402/000-005)

Item no.: 2000-402/000-006

Push-in type jumper bar; insulated; 2-way; Nominal current 14 A

[www.wago.com/2000-402/000-006](http://www.wago.com/2000-402/000-006)

Item no.: 2000-402/000-018

Push-in type jumper bar; insulated; 2-way; Nominal current 14 A

[www.wago.com/2000-402/000-018](http://www.wago.com/2000-402/000-018)

Item no.: 2000-403

Push-in type jumper bar; insulated; 3-way; Nominal current 14 A

[www.wago.com/2000-403](http://www.wago.com/2000-403)

Item no.: 2000-403/000-005

Push-in type jumper bar; insulated; 3-way; Nominal current 14 A

[www.wago.com/2000-403/000-005](http://www.wago.com/2000-403/000-005)

Item no.: 2000-403/000-006

Push-in type jumper bar; insulated; 3-way; Nominal current 14 A

[www.wago.com/2000-403/000-006](http://www.wago.com/2000-403/000-006)

Item no.: 2000-404

Push-in type jumper bar; insulated; 4-way; Nominal current 14 A

[www.wago.com/2000-404](http://www.wago.com/2000-404)

Item no.: 2000-404/000-005

Push-in type jumper bar; insulated; 4-way; Nominal current 14 A

[www.wago.com/2000-404/000-005](http://www.wago.com/2000-404/000-005)

Item no.: 2000-404/000-006

Push-in type jumper bar; insulated; 4-way; Nominal current 14 A

[www.wago.com/2000-404/000-006](http://www.wago.com/2000-404/000-006)

Item no.: 2000-405

















Push-in type jumper bar; insulated; 5-way; Nominal current 14 A

















 
[www.wago.com/2000-405](http://www.wago.com/2000-405)

Item no.: 2000-405/000-005

Push-in type jumper bar; insulated; 5-way; Nominal current 14 A




[www.wago.com/2000-405/000-005](http://www.wago.com/2000-405/000-005)

	<b>Item no.:</b> 2000-405/000-006 Push-in type jumper bar; insulated; 5-way; Nominal current 14 A	<a href="http://www.wago.com/2000-405/000-006">www.wago.com/2000-405/000-006</a>
	<b>Item no.:</b> 2000-405/011-000 Star point jumper; insulated; 3-way (1-3-5); IN = IN terminal block	<a href="http://www.wago.com/2000-405/011-000">www.wago.com/2000-405/011-000</a>
	<b>Item no.:</b> 2000-406 Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	<a href="http://www.wago.com/2000-406">www.wago.com/2000-406</a>
	<b>Item no.:</b> 2000-406/000-005 Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	<a href="http://www.wago.com/2000-406/000-005">www.wago.com/2000-406/000-005</a>
	<b>Item no.:</b> 2000-406/000-006 Push-in type jumper bar; insulated; 6-way; Nominal current 14 A	<a href="http://www.wago.com/2000-406/000-006">www.wago.com/2000-406/000-006</a>
	<b>Item no.:</b> 2000-406/020-000 Delta jumper; insulated; 1-2 3-4 5-6; IN = IN terminal block	<a href="http://www.wago.com/2000-406/020-000">www.wago.com/2000-406/020-000</a>
	<b>Item no.:</b> 2000-407 Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	<a href="http://www.wago.com/2000-407">www.wago.com/2000-407</a>
	<b>Item no.:</b> 2000-407/000-005 Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	<a href="http://www.wago.com/2000-407/000-005">www.wago.com/2000-407/000-005</a>
	<b>Item no.:</b> 2000-407/000-006 Push-in type jumper bar; insulated; 7-way; Nominal current 14 A	<a href="http://www.wago.com/2000-407/000-006">www.wago.com/2000-407/000-006</a>
	<b>Item no.:</b> 2000-408 Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	<a href="http://www.wago.com/2000-408">www.wago.com/2000-408</a>
	<b>Item no.:</b> 2000-408/000-005 Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	<a href="http://www.wago.com/2000-408/000-005">www.wago.com/2000-408/000-005</a>
	<b>Item no.:</b> 2000-408/000-006 Push-in type jumper bar; insulated; 8-way; Nominal current 14 A	<a href="http://www.wago.com/2000-408/000-006">www.wago.com/2000-408/000-006</a>
	<b>Item no.:</b> 2000-409 Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	<a href="http://www.wago.com/2000-409">www.wago.com/2000-409</a>
	<b>Item no.:</b> 2000-409/000-005 Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	<a href="http://www.wago.com/2000-409/000-005">www.wago.com/2000-409/000-005</a>
	<b>Item no.:</b> 2000-409/000-006 Push-in type jumper bar; insulated; 9-way; Nominal current 14 A	<a href="http://www.wago.com/2000-409/000-006">www.wago.com/2000-409/000-006</a>
	<b>Item no.:</b> 2000-410 Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	<a href="http://www.wago.com/2000-410">www.wago.com/2000-410</a>


	<b>Item no.:</b> 2000-410/000-005 Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	<a href="http://www.wago.com/2000-410/000-005">www.wago.com/2000-410/000-005</a>
	<b>Item no.:</b> 2000-410/000-006 Push-in type jumper bar; insulated; 10-way; Nominal current 14 A	<a href="http://www.wago.com/2000-410/000-006">www.wago.com/2000-410/000-006</a>
	<b>Item no.:</b> 2000-433 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	<a href="http://www.wago.com/2000-433">www.wago.com/2000-433</a>
	<b>Item no.:</b> 2000-433/000-005 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	<a href="http://www.wago.com/2000-433/000-005">www.wago.com/2000-433/000-005</a>
	<b>Item no.:</b> 2000-433/000-006 Push-in type jumper bar; insulated; from 1 to 3; Nominal current 14 A	<a href="http://www.wago.com/2000-433/000-006">www.wago.com/2000-433/000-006</a>
	<b>Item no.:</b> 2000-434 Push-in type jumper bar; insulated; from 1 to 4; Nominal current 14 A	<a href="http://www.wago.com/2000-434">www.wago.com/2000-434</a>
	<b>Item no.:</b> 2000-435 Push-in type jumper bar; insulated; from 1 to 5; Nominal current 14 A	<a href="http://www.wago.com/2000-435">www.wago.com/2000-435</a>
	<b>Item no.:</b> 2000-436 Push-in type jumper bar; insulated; from 1 to 6; Nominal current 14 A	<a href="http://www.wago.com/2000-436">www.wago.com/2000-436</a>
	<b>Item no.:</b> 2000-437 Push-in type jumper bar; insulated; from 1 to 7; Nominal current 14 A	<a href="http://www.wago.com/2000-437">www.wago.com/2000-437</a>
	<b>Item no.:</b> 2000-438 Push-in type jumper bar; insulated; from 1 to 8; Nominal current 14 A	<a href="http://www.wago.com/2000-438">www.wago.com/2000-438</a>
	<b>Item no.:</b> 2000-439 Push-in type jumper bar; insulated; from 1 to 9; Nominal current 14 A	<a href="http://www.wago.com/2000-439">www.wago.com/2000-439</a>
	<b>Item no.:</b> 2000-440 Push-in type jumper bar; insulated; from 1 to 10; Nominal current 14 A	<a href="http://www.wago.com/2000-440">www.wago.com/2000-440</a>
	<b>Item no.:</b> 2009-402 Push-in type wire jumper; insulated; wire length 60 mm; Conductor cross section 0.75 mm <sup>2</sup> ; suitable for 2000 and 2020 Series rail-mounted terminal blocks	<a href="http://www.wago.com/2009-402">www.wago.com/2009-402</a>
	<b>Item no.:</b> 2009-404 Push-in type wire jumper; insulated; wire length 110 mm; Conductor cross section 0.75 mm <sup>2</sup> ; suitable for 2000 and 2020 Series rail-mounted terminal blocks	<a href="http://www.wago.com/2009-404">www.wago.com/2009-404</a>
	<b>Item no.:</b> 2009-406 Push-in type wire jumper; insulated; wire length 250 mm; Conductor cross section 0.75 mm <sup>2</sup> ; suitable for 2000 and 2020 Series rail-mounted terminal blocks	<a href="http://www.wago.com/2009-406">www.wago.com/2009-406</a>
	<b>Item no.:</b> 210-103 Wire commoning chain; insulated; 50 connections	<a href="http://www.wago.com/210-103">www.wago.com/210-103</a>
	<b>Item no.:</b> 210-123 Wire commoning chain; insulated; 50 connections	<a href="http://www.wago.com/210-123">www.wago.com/210-123</a>

## ferrule

**Item no.:** 216-241

	Ferrule; Sleeve for 0.5 mm <sup>2</sup> / AWG 22; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	<a href="http://www.wago.com/216-241">www.wago.com/216-241</a>
	<b>Item no.: 216-242</b> Ferrule; Sleeve for 0.75 mm <sup>2</sup> / AWG 20; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	<a href="http://www.wago.com/216-242">www.wago.com/216-242</a>
	<b>Item no.: 216-243</b> Ferrule; Sleeve for 1 mm <sup>2</sup> / AWG 18; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90	<a href="http://www.wago.com/216-243">www.wago.com/216-243</a>


### Protective Warning Marker

	<b>Item no.: 2000-115</b> Protective warning marker; with high-voltage symbol, black; for 5 terminal blocks	<a href="http://www.wago.com/2000-115">www.wago.com/2000-115</a>
--	--	--

### General accessories

	<b>Item no.: 2020-161</b> Start module for 1-conductor female connector; with integrated end plate; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-161">www.wago.com/2020-161</a>
	<b>Item no.: 2020-164</b> Start module for 1-conductor female connector; with integrated end plate; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-164">www.wago.com/2020-164</a>
	<b>Item no.: 2020-167</b> Start module for 1-conductor female connector; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-167">www.wago.com/2020-167</a>
	<b>Item no.: 2020-181</b> End module for 1-conductor female connector; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-181">www.wago.com/2020-181</a>
	<b>Item no.: 2020-184</b> End module for 1-conductor female connector; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-184">www.wago.com/2020-184</a>
	<b>Item no.: 2020-187</b> End module for 1-conductor female connector; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-187">www.wago.com/2020-187</a>
	<b>Item no.: 2020-261</b> Start module for 2-conductor female connector; with integrated end plate; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-261">www.wago.com/2020-261</a>
	<b>Item no.: 2020-264</b> Start module for 2-conductor female connector; with integrated end plate; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-264">www.wago.com/2020-264</a>
	<b>Item no.: 2020-267</b> Start module for 2-conductor female connector; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-267">www.wago.com/2020-267</a>
	<b>Item no.: 2020-281</b> End module for 2-conductor female connector; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-281">www.wago.com/2020-281</a>
	<b>Item no.: 2020-284</b> End module for 2-conductor female connector; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-284">www.wago.com/2020-284</a>
	<b>Item no.: 2020-287</b> End module for 2-conductor female connector; 1.5 mm <sup>2</sup> ; 1-pole	<a href="http://www.wago.com/2020-287">www.wago.com/2020-287</a>

### check

	<b>Item no.: 2009-174</b> Test plug adapter; for 4 mm Ø test plugs; for testing TOPJOB®S rail-mounted terminal blocks	<a href="http://www.wago.com/2009-174">www.wago.com/2009-174</a>
---	--	--



Item no.: 2009-182

Testing tap; for max. 2.5 mm<sup>2</sup>; tool-free connection for individual test wires 0.08 - 2.5 mm

[www.wago.com/2009-182](http://www.wago.com/2009-182)



Item no.: 859-500

Test pin; 1 mm Ø; with solder connection for test wire

[www.wago.com/859-500](http://www.wago.com/859-500)

## Downloads

### Documentation

#### Bid Text

2020-1307

14-Aug-2018

DOCX  
15.3 kB

Download

## Product family

### X-COM S

[Show all products from the family](#)

Subject to changes.