

Product information

37 21 125

Flat Nose Pliers

For precision mechanics


DIN ISO 9655

- Precision pliers for fine assembly work, e.g. in electronics and fine mechanics
- For gripping, holding, bending and adjusting
- Tips precision-ground
- Smooth gripping surfaces
- Edges carefully deburred
- Lap joint
- Flat, concave and pointed jaws
- High-grade special tool steel, forged, oil-hardened



General	
Article No.	37 21 125
EAN	4003773035138
Pliers	black atramentized
Head	polished
Handles	plastic coated
weight	74 g
Dimensions	125 x 56 x 13 mm
Standard	DIN ISO 9655
Reach	no
RohS	no

Technical details	
Style	2
	7.0 mm
Tips width (E)	2.0 mm
Tips thickness (F)	2.0 mm
	27.0 mm
Head width (A)	12.5 mm

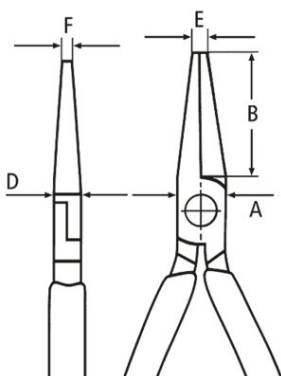



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

technical change and errors excepted