

Product information

37 31 125

Flat Nose Pliers

For precision mechanics

DIN ISO 9655

- Precision pliers for fine assembly work, e.g. in electronics and fine mechanics
- For gripping, holding, bending and adjusting
- Tips precision-ground
- Smooth gripping surfaces
- Edges carefully deburred
- Lap joint
- Half-round jaws
- High-grade special tool steel, forged, oil-hardened




General

Article No.	37 31 125
EAN	4003773035145
Pliers	black atramentized
Head	polished
Handles	plastic coated
weight	74 g
Dimensions	125 x 50 x 11 mm
Standard	DIN ISO 9655
Reach	no
RohS	no

Technical details

Style	3
	7.0 mm
Tips width (E)	2.0 mm
Tips thickness (F)	1.6 mm
	27.0 mm
Head width (A)	12.5 mm

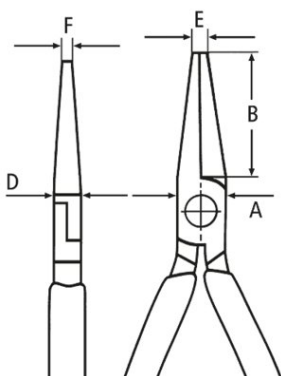



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

technical change and errors excepted