

Product information

37 41 125

Flat Nose Pliers

For precision mechanics

DIN ISO 9655

- Precision pliers for fine assembly work, e.g. in electronics and fine mechanics
- For gripping, holding, bending and adjusting
- Tips precision-ground
- Smooth gripping surfaces
- Edges carefully deburred
- Lap joint
- Round, pointed jaws to bend wire loops
- High-grade special tool steel, forged, oil-hardened




General

| | |
|-------------|--------------------|
| Article No. | 37 41 125 |
| EAN | 4003773035152 |
| Pliers | black atramentized |
| Head | polished |
| Handles | plastic coated |
| weight | 76 g |
| Dimensions | 125 x 50 x 12 mm |
| Standard | DIN ISO 9655 |
| Reach | no |
| RohS | no |

Technical details

| | |
|--------------------|---------|
| Style | 4 |
| | 8.0 mm |
| Tips width (E) | 2.0 mm |
| Tips thickness (F) | 1.0 mm |
| | 27.0 mm |
| Head width (A) | 14.5 mm |

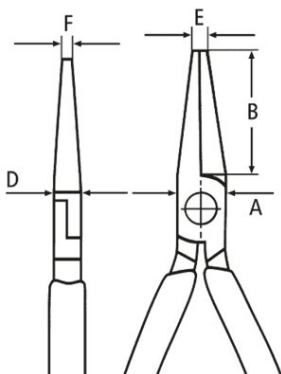



| Classification | |
|-----------------------|------------|
| eCl@ss 5.1.4 | 21040301 |
| proficl@ss 6.0 | AAA004c004 |
| UNSPSC 13.1 | 27112104 |

technical change and errors excepted