

Product information

29 25 160

- Gripping surfaces cross-hatched, knurled
- Half-round jaws
- Chrome vanadium electric steel, forged, oil-hardened

Telephone Pliers

DIN ISO 5745




General

Article No.	29 25 160
EAN	4003773043478
Pliers	chrome plated
Head	chrome plated
Handles	with multi-component grips
weight	139 g
Dimensions	160 x 59 x 18 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Style	2
	9.0 mm
Tips width (W4)	2.0 mm
Tips thickness (T2)	2.0 mm
	54.0 mm
Head width (W3)	14.0 mm

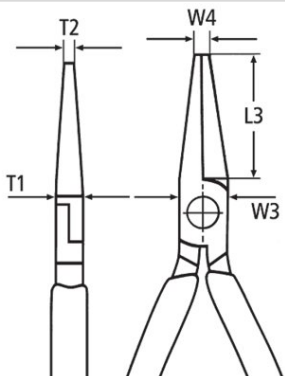



Classification

eCl@ss 5.1.4	21040301
proficl@ss 6.0	EAC010c041
UNSPSC 13.1	27112134

technical change and errors excepted