

Product information

22 01 140


- For bending wire loops
- Round, short jaws; finely ground
- Smooth tips
- Special tool steel, forged, oil-hardened

Round Nose Pliers

DIN ISO 5745



General	
Article No.	22 01 140
EAN	4003773022800
Pliers	black atramentized
Head	polished
Handles	plastic coated
weight	100 g
Dimensions	140 x 51 x 12 mm
Standard	DIN ISO 5745
Reach	no
RohS	no
Technical details	
	9.5 mm
Tips thickness (T2)	2.5 mm
	28.0 mm
Head width (W3)	16.5 mm

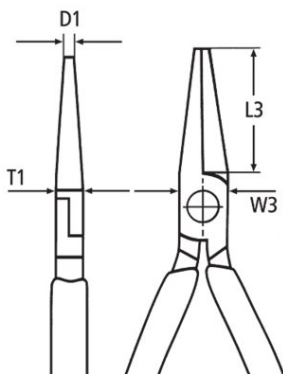

Classification	
eCl@ss 5.1.4	21040301
ETIM 5.0	EC000834
ETIM 6.0	EC000834
proficl@ss 6.0	AAA005c004
UNSPSC 13.1	27112125

technical change and errors excepted

