

## Product information

**22 02 140**

### Round Nose Pliers

DIN ISO 5745

- For bending wire loops
- Round, short jaws; finely ground
- Smooth tips
- Special tool steel, forged, oil-hardened




#### General

Article No.	22 02 140
EAN	4003773043430
Pliers	black atramentized
Head	polished
Handles	with multi-component grips
weight	129 g
Dimensions	140 x 57 x 18 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

#### Technical details

	9.5 mm
Tips thickness (T2)	2.5 mm
	28.0 mm
Head width (W3)	16.5 mm

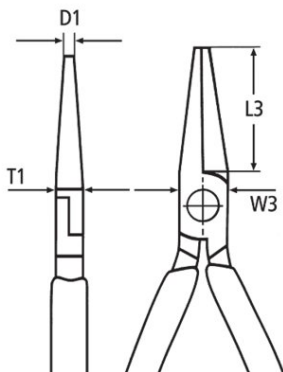

**Classification**

eCl@ss 5.1.4	21040301
ETIM 5.0	EC000834
ETIM 6.0	EC000834
proficl@ss 6.0	AAA005c004
UNSPSC 13.1	27112125

*technical change and errors excepted*

