

Product information

22 06 160

Round Nose Pliers

DIN ISO 5745 IEC 60900 DIN EN 60900

- For bending wire loops
- Round, short jaws; finely ground
- Smooth tips
- Special tool steel, forged, oil-hardened




⚡ 1000V 

General

Article No.	22 06 160
EAN	4003773033790
Pliers	chrome plated
Head	chrome plated
Handles	insulated with multi-component grips, VDE-tested
weight	175 g
Dimensions	160 x 48 x 19 mm
Standard	DIN ISO 5745 DIN EN 60900 IEC 60900
Reach	no
RohS	no

Technical details

	9.5 mm
Tips thickness (T2)	3.0 mm
	30.0 mm
Head width (W3)	18 mm
VDE tested	yes

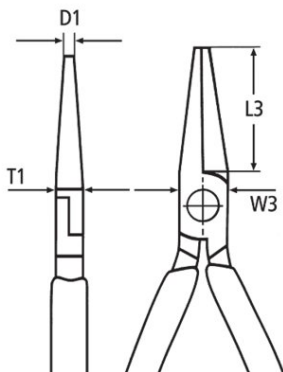

Classification	
eCl@ss 5.1.4	21040301
ETIM 5.0	EC000834
ETIM 6.0	EC000834
proficl@ss 6.0	AAA005c004
UNSPSC 13.1	27112125

technical change and errors excepted

