

Product information

38 21 200

- High bending strength of the pliers tips
- 40° bent, half-round jaws
- Vanadium electric steel; forged, oil-hardened


Mechanics' Pliers

DIN ISO 5745



General	
Article No.	38 21 200
EAN	4003773035176
Pliers	black atramentized
Head	polished
Handles	plastic coated
weight	175 g
Dimensions	200 x 47 x 13 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details	
Style	2
	9.5
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.5 mm
	73.0 mm
Head width (W3)	17.5 mm
Head angle	40

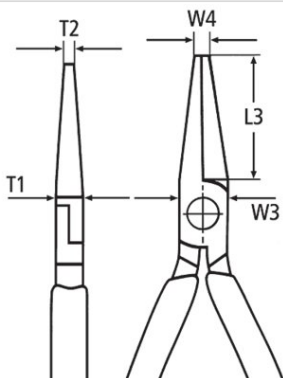



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

technical change and errors excepted