

## Product information

# 38 35 200

- High bending strength of the pliers tips
- Cranked, half-round jaws
- Vanadium electric steel; forged, oil-hardened

## Mechanics' Pliers

DIN ISO 5745




### General

Article No.	38 35 200
EAN	4003773017134
Pliers	chrome plated
Head	chrome plated
Handles	with multi-component grips
weight	205 g
Dimensions	200 x 51 x 13 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

### Technical details

Style	3
	9.5
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.5 mm
	73.0 mm
Head width (W3)	17.5 mm

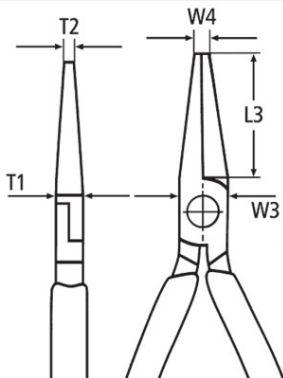



<b>Classification</b>	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

*technical change and errors excepted*