

 
Product information

38 91 200

Mechanics' Pliers


DIN ISO 5745

- High bending strength of the pliers tips
- Gripping surfaces cross-hatched, knurled
- 45° angled, half-round, long jaws, also suitable for gripping spark plugs and round components (spark plug cover "grabber")
- Vanadium electric steel; forged, oil-hardened



| General | |
|-------------|--------------------|
| Article No. | 38 91 200 |
| EAN | 4003773017219 |
| Pliers | black atramentized |
| Head | polished |
| Handles | plastic coated |
| weight | 177 g |
| Dimensions | 200 x 51 x 13 mm |
| Standard | DIN ISO 5745 |
| Reach | no |
| RohS | no |

| Technical details | |
|---------------------|---------|
| Style | 9 |
| | 9.5 |
| Tips thickness (T2) | 2.5 mm |
| | 73.0 mm |
| Head width (W3) | 17.5 mm |
| Head angle | 45 |

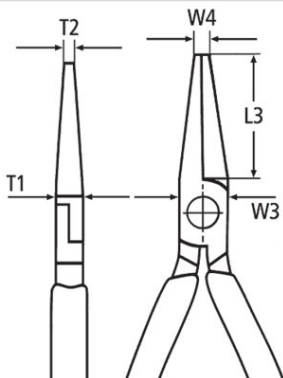

| Classification | |
|-----------------------|------------|
| eCl@ss 5.1.4 | 21040301 |
| proficl@ss 6.0 | AAA004c004 |
| UNSPSC 13.1 | 27112104 |

technical change and errors excepted

