

 
Product information

38 95 200


- High bending strength of the pliers tips
- 45° angled, half-round, long jaws, also suitable for gripping spark plugs and round components (spark plug cover "grabber")
- Vanadium electric steel; forged, oil-hardened

Mechanics' Pliers

DIN ISO 5745



General	
Article No.	38 95 200
EAN	4003773017233
Pliers	chrome plated
Head	chrome plated
Handles	with multi-component grips
weight	207 g
Dimensions	200 x 55 x 19 mm
Standard	DIN ISO 5745
Reach	no
RohS	no
Technical details	
Style	9
	9.5
Tips thickness (T2)	2.5 mm
	73.0 mm
Head width (W3)	17.5 mm
Head angle	45

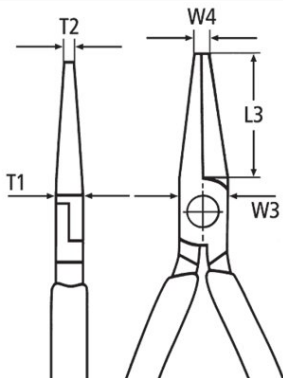

Classification

eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112104

technical change and errors excepted

