

Product information

30 11 140

Long Nose Pliers

DIN ISO 5745

- Heavy duty and wear resisting
- Different jaw styles
- Long, trapezoidal jaws
- Knurled gripping surfaces
- Chrome vanadium electric steel, forged, oil-hardened




General

Article No.	30 11 140
EAN	4003773033936
Pliers	black atramentized
Head	polished
Handles	plastic coated
weight	86 g
Dimensions	140 x 51 x 12 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Style	1
	8.0 mm
Tips width (W4)	2.5 mm
Tips thickness (T2)	4.0 mm
	42.0 mm
Head width (W3)	15.0 mm

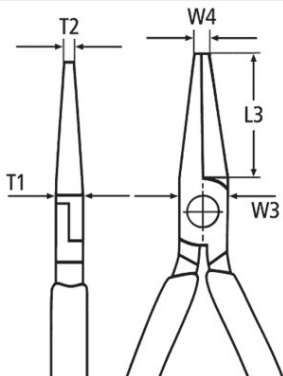



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

technical change and errors excepted