

Product information

30 15 140

Long Nose Pliers

DIN ISO 5745

- Heavy duty and wear resisting
- Different jaw styles
- Long, trapezoidal jaws
- Chrome vanadium electric steel, forged, oil-hardened




General

Article No.	30 15 140
EAN	4003773042914
Pliers	chrome plated
Head	chrome plated
Handles	with multi-component grips
weight	106 g
Dimensions	140 x 54 x 17 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Style	1
	8.0 mm
Tips width (W4)	2.5 mm
Tips thickness (T2)	4.0 mm
	42.0 mm
Head width (W3)	15.0 mm

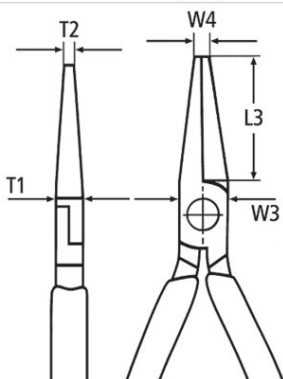



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

technical change and errors excepted