

## Product information

# 30 15 160

## Long Nose Pliers

DIN ISO 5745

- Heavy duty and wear resisting
- Different jaw styles
- Long, trapezoidal jaws
- Chrome vanadium electric steel, forged, oil-hardened




### General

Article No.	30 15 160
EAN	4003773035046
Pliers	chrome plated
Head	chrome plated
Handles	with multi-component grips
weight	149 g
Dimensions	160 x 57 x 18 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

### Technical details

Style	1
	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	5.0 mm
	46.5 mm
Head width (W3)	16.5 mm

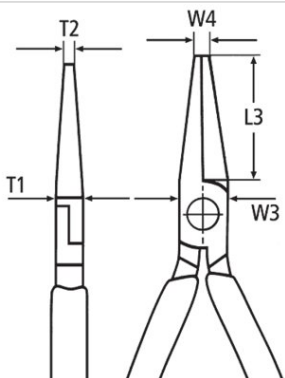



**Classification**

eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

*technical change and errors excepted*