

Product information

30 25 160

- Heavy duty and wear resisting
- Different jaw styles
- Long, half-round jaws
- Chrome vanadium electric steel, forged, oil-hardened

Long Nose Pliers

DIN ISO 5745




General

Article No.	30 25 160
EAN	4003773035060
Pliers	chrome plated
Head	chrome plated
Handles	with multi-component grips
weight	151 g
Dimensions	160 x 54 x 18 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

Technical details

Style	2
	9.5 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.5 mm
	50.0 mm
Head width (W3)	16.5 mm

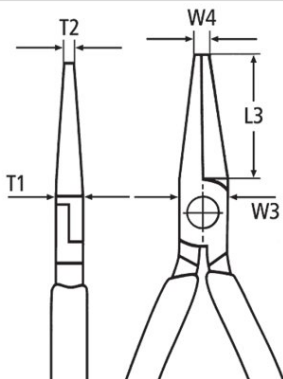



Classification	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

technical change and errors excepted