

## Product information

# 30 25 190

- Heavy duty and wear resisting
- Different jaw styles
- Long, half-round jaws
- Chrome vanadium electric steel, forged, oil-hardened

## Long Nose Pliers

DIN ISO 5745




### General

Article No.	30 25 190
EAN	4003773043515
Pliers	chrome plated
Head	chrome plated
Handles	with multi-component grips
weight	168 g
Dimensions	190 x 56 x 18 mm
Standard	DIN ISO 5745
Reach	no
RohS	no

### Technical details

Style	2
	8.0 mm
Tips width (W4)	3.0 mm
Tips thickness (T2)	2.4 mm
	50.0 mm
Head width (W3)	18.5 mm

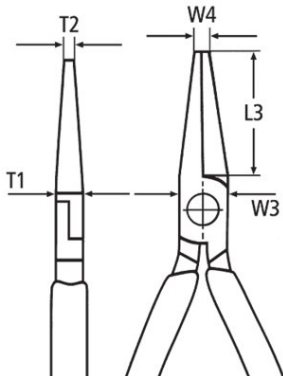



<b>Classification</b>	
eCl@ss 5.1.4	21040301
proficl@ss 6.0	AAA004c004
UNSPSC 13.1	27112134

*technical change and errors excepted*