

## Product information

# 13 02 160

## Electricians' Pliers



- The ideal pliers for cable work
- For gripping and bending wire
- For cutting medium hard and hard wire
- Precision cutting edges additionally induction-hardened, cutting edge hardness approx. 60 HRC
- With precision stripping holes
- For crimping wire ferrules
- Vanadium electric steel, forged, multi stage oil-hardened



### General

|             |                            |
|-------------|----------------------------|
| Article No. | 13 02 160                  |
| EAN         | 4003773010470              |
| Pliers      | black atramentized         |
| Head        | polished                   |
| Handles     | with multi-component grips |
| weight      | 139 g                      |
| Dimensions  | 160 x 59 x 19 mm           |
| Reach       | no                         |
| RohS        | no                         |



### Technical details

|  |  |
|--|--|
| Cutting capacities medium hard wire (diameter) | Ø 2.5                                  |
| Cutting capacities hard wire (diameter)        | Ø 1.6                                  |
| Stripping capacities in square millimetres     | 0.5 — 0.75 / 1.5 / 2.5 mm <sup>2</sup> |


### Classification

|                |            |
|----------------|------------|
| eCl@ss 5.1.4   | 21040302   |
| ETIM 5.0       | EC000163   |
| ETIM 6.0       | EC000163   |
| proficl@ss 6.0 | AAA002c003 |
| UNSPSC 13.1    | 27112148   |


*technical change and errors excepted*

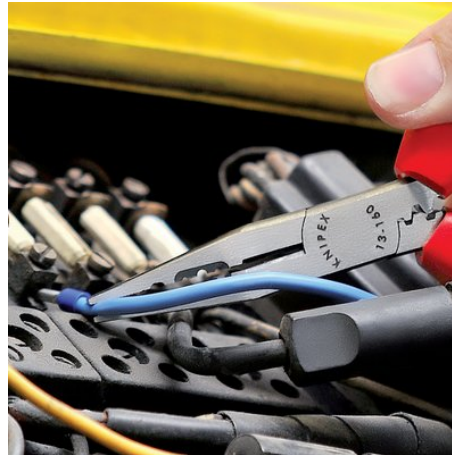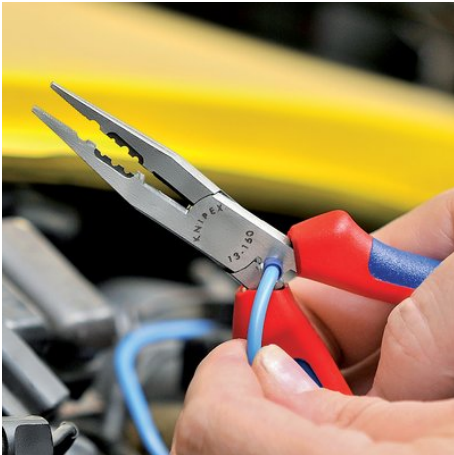


Stripping

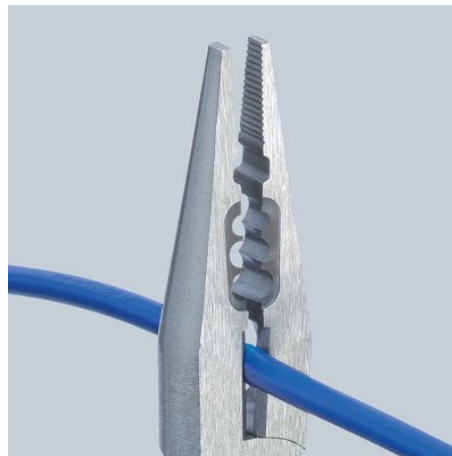

Cutting Edges

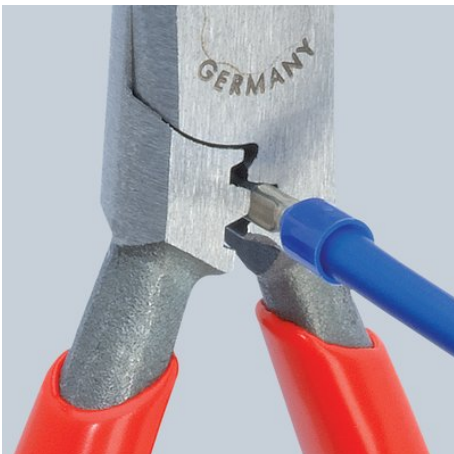

Crimping 0.5 to 2.5 mm<sup>2</sup>

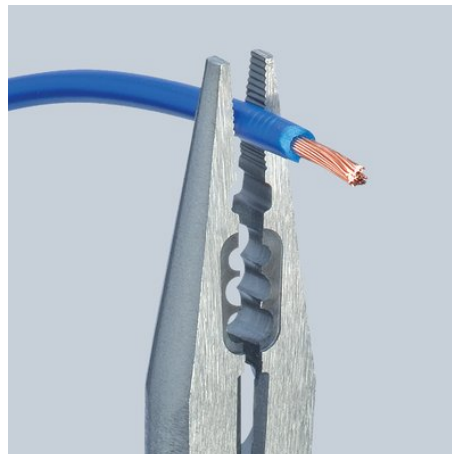

Gripping