



4-conductor miniature through terminal block; suitable for Ex i applications

Item No.: 264-734



4-conductor miniature through terminal block; suitable for Ex i applications

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	264-734
GTIN / EAN	4044918414944
Content	1

Notes

Technical data


Miscellaneous

Rated voltage (III / 3) [V]	800 [V]
Rated impulse voltage (III / 3) [kV]	8 [kV]
Rated current [A]	24 [A]
Legend (ratings)	(III / 3) Overvoltage category III / Pollution degree 3
Type of wiring	Front-entry wiring

Technical data	
Total number of connection points	4
Total number of potentials	1
Number of levels	1
Connection technology	CAGE CLAMP®
Actuation type	Operating tool
Connectable conductor materials	Copper
Solid conductor	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Strip length	8 ... 9 mm / 0.31 ... 0.35 Inch
Note (conductor cross-section)	12 AWG: THHN, THWN
Width	10 mm / 0.394 Inch
Height from upper-edge of DIN-35 rail	24.5 mm / 0.965 Inch
Depth	38 mm / 1.496 Inch
Design	horizontal
Type of mounting	Carrier rail 35 x 15
Marking level	Center marking
Color	blue
Fire load [MJ]	0.108 [MJ]
Weight [g]	6.208 [g]
Main product function	Through term. block
Product type	Miniature rail-mount terminal blocks

Images & drawings



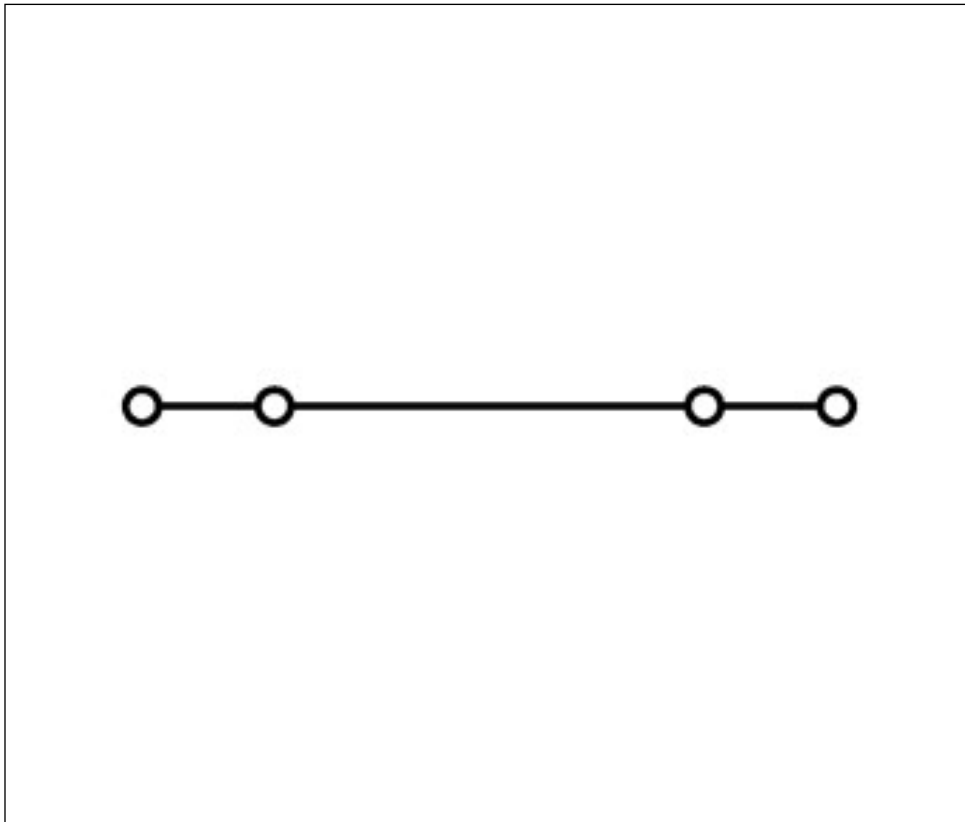

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.