



4-conductor miniature ground terminal block; suitable for Ex e II applications

Item No.: 264-737



4-conductor miniature ground terminal block; suitable for Ex e II applications

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	264-737
GTIN / EAN	4044918451956
Content	1

Notes

Technical data



Miscellaneous

Type of wiring	Front-entry wiring
Total number of connection points	4
Total number of potentials	1
Number of levels	1
Connection technology	CAGE CLAMP®

Technical data	
<i>Actuation type</i>	<i>Operating tool</i>
<i>Connectable conductor materials</i>	<i>Copper</i>
<i>Solid conductor</i>	<i>0.08 ... 2.5 mm² / 28 ... 12 AWG</i>
<i>Fine-stranded conductor</i>	<i>0.08 ... 2.5 mm² / 28 ... 12 AWG</i>
<i>Strip length</i>	<i>8 ... 9 mm / 0.31 ... 0.35 Inch</i>
<i>Note (conductor cross-section)</i>	<i>12 AWG: THHN, THWN</i>
<i>Width</i>	<i>10 mm / 0.394 Inch</i>
<i>Height from upper-edge of DIN-35 rail</i>	<i>24.5 mm / 0.965 Inch</i>
<i>Depth</i>	<i>46.5 mm / 1.831 Inch</i>
<i>Design</i>	<i>horizontal</i>
<i>Type of mounting</i>	<i>Carrier rail 35 x 15</i>
<i>Marking level</i>	<i>Center marking</i>
<i>Color</i>	<i>green-yellow</i>
<i>Fire load [MJ]</i>	<i>0.119 [MJ]</i>
<i>Weight [g]</i>	<i>8.86 [g]</i>
<i>Main product function</i>	<i>GND cond. term. block</i>
<i>Product type</i>	<i>Miniature rail-mount terminal blocks</i>

Images & drawings



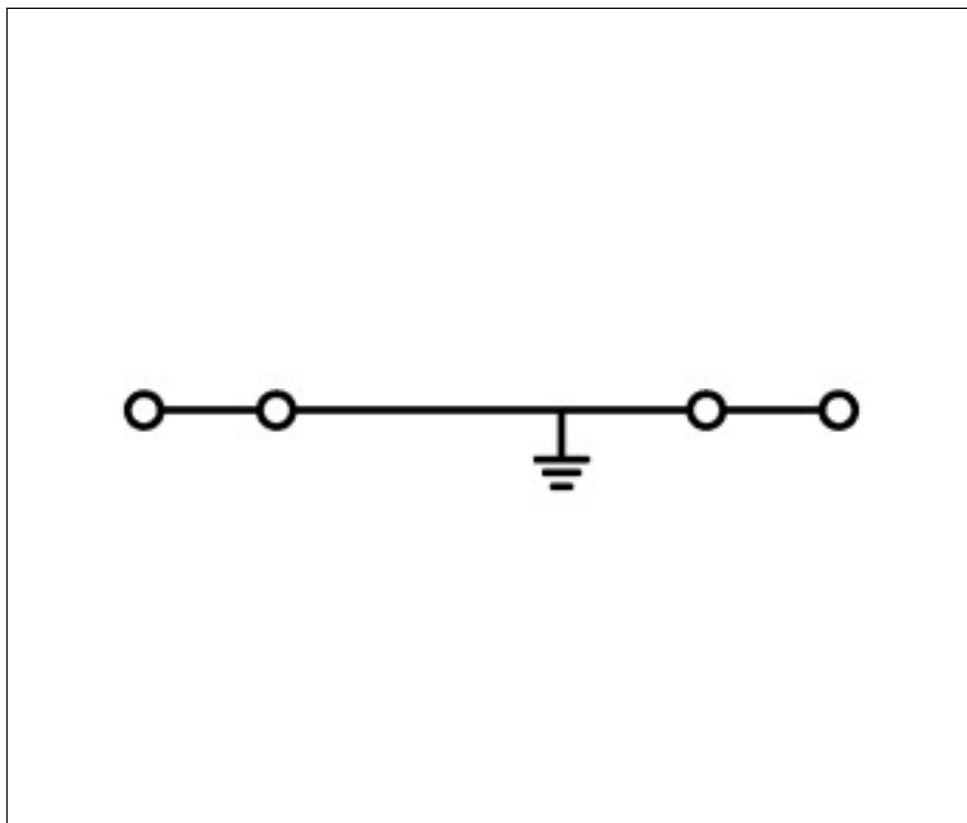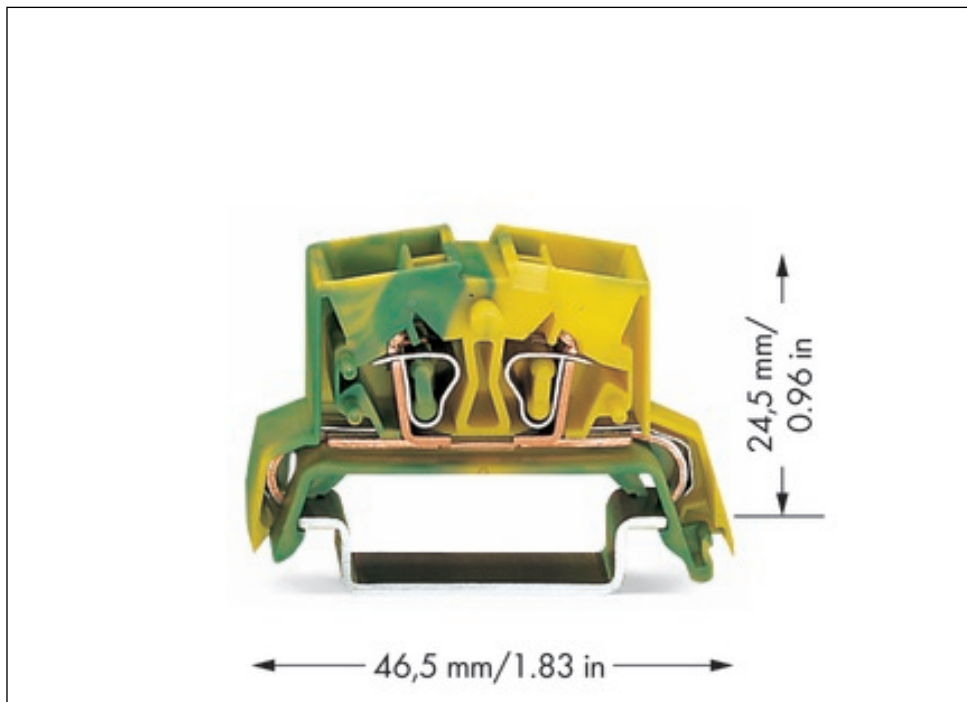

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.