

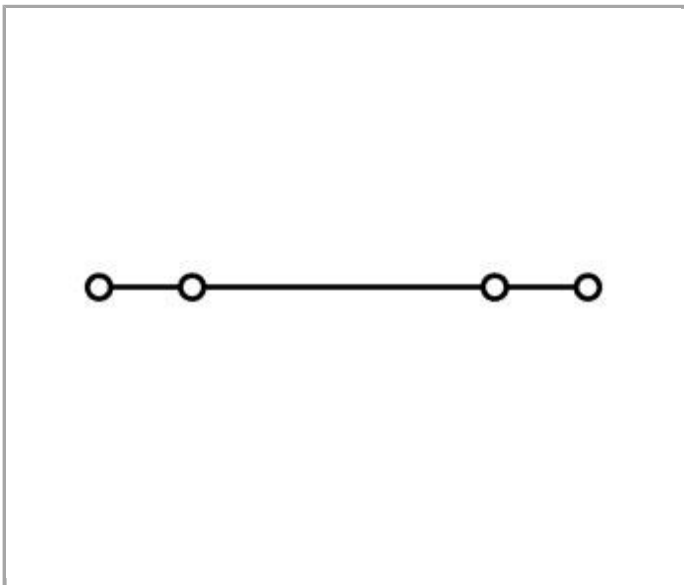


Data sheet | Item number: 264-721

4-conductor miniature through terminal block; 2.5 mm<sup>2</sup>; with test option; center marking; for DIN-15 rail; CAGE CLAMP®

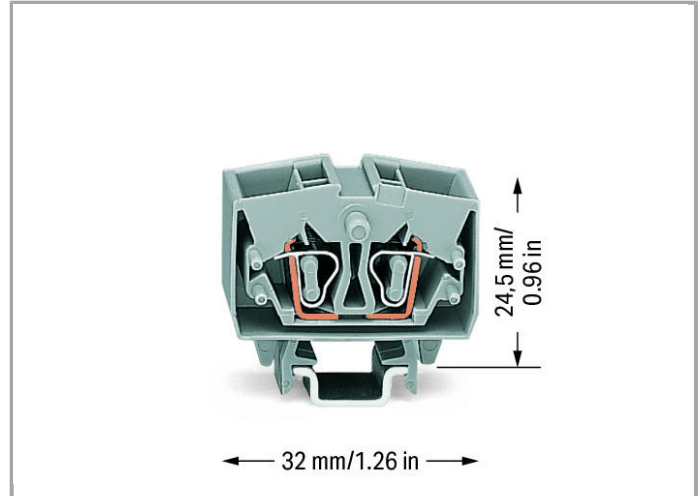

[www.wago.com/264-721](http://www.wago.com/264-721)

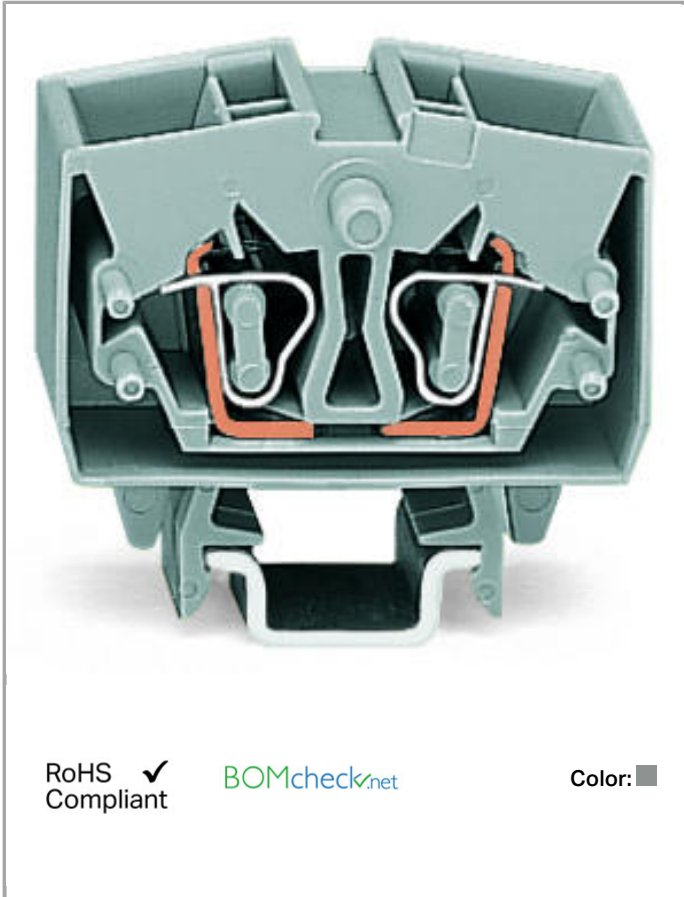

## Data

### Electrical data

#### Ratings per IEC/EN 60664-1

Rated voltage (III / 3)	800 V
Rated impulse voltage (III / 3)	8 kV
Rated current	24 A
Legend (ratings)	(III / 3) $\triangleq$ Overvoltage category III / Pollution degree 3

### Connection data

Connection technology	CAGE CLAMP <sup>®</sup>
Actuation type	Operating tool
Connectable conductor materials	Copper
Solid conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Fine-stranded conductor	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
Strip length	8 ... 9 mm / 0.31 ... 0.35 Inch
Total number of connection points	4
Total number of potentials	1
Number of levels	1
Type of wiring	Front-entry wiring

### Geometrical Data

Width	10 mm / 0.394 inch
Height from upper-edge of DIN-35 rail	24.5 mm / 0.965 inch
Depth	32 mm / 1.26 inch

### Mechanical data

Design	horizontal
Type of mounting	DIN-15 rail
Marking level	Center marking

### Material Data

Color	gray
Fire load	0.104 MJ
Weight	6.087 g

### Approvals / Certificates

#### Country specific Approvals

Logo	Approval	Certificate name
------	----------	------------------



CCA  
DEKRA Certification B.V.

NTR NL-7077



CSA  
DEKRA Certification B.V.





70010891



ENEC  
DEKRA Certification B.V.

2160584.02

#### Ship Approvals

Logo	Approval	Certificate name
	<b>ABS</b> American Bureau of Shipping	14-HG1241539-PDA
	<b>BV</b> Bureau Veritas S.A.	07436/E0 BV
	<b>DNV GL</b> Det Norske Veritas, Germanischer Lloyd	TAE00001V2
	<b>LR</b> Lloyds Register	91/20242 (E7)

#### UL-Approvals

Logo	Approval	Certificate name
	<b>UR</b> Underwriters Laboratories Inc.	E45172, sec. 6

Subject to changes.